

# DLMULTI-024-30W

## Description

Diffusion DLMULTI-024-30W is a Dimmable LED Driver that works with Forward / Reverse phase, ELV, Triac or 0-10V Dimmers.

## Features

- Protection from short circuit, over current and over voltage
- Internal self reset mini breakers
- Compatible with virtually every style dimmer
- Flicker-free ~ 20,000 Hz
- Indoor/Outdoor
- High Efficiency
- Working Temp : -40 ~ +85° C
- Wet location rated

## Specifications

- Input Voltage : 100-277 VAC
- Output Voltage : 24 VDC
- Output Current : 1.25A
- Dimming Range : 0-100%
- Wattage : 30W

\*0% with select dimmers only\*

## Driver Dimensions :


6.0" L x 3.6" W x 1.0" H  
150mm L x 93mm W x 25mm H

## KO (I.D.) :

6 x 0.5" (Sides)  
\*Standard 1/2" connectors won't fit  
2 x 0.8" (Back)



## Connector

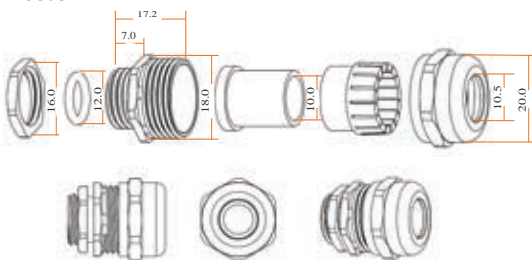

Comes with two Connectors

\*Only takes up to 14/2 loomex or 14/3 sjoow\*

30W and 60W only

