



5" UNIVERSAL IC HOUSING

INCANDESCENT LAMPS IC20 SERIES

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

IC Air-Loc® Housing • Energy efficient, sealed housing • Can be completely covered with insulation • When used with Air-Loc Gasket accessory or pre-installed gasket, stops infiltration and exfiltration of air, reducing heating and cooling costs • Trims shown with Air-Loc symbol **Air-Loc** do not require a gasket.

PRODUCT SPECIFICATIONS

Lamp Lamp ratings based on trim selected—see page 2.

Socket Medium base porcelain with nickel-plated copper screw shell • Drop socket with spring to accommodate certain trim installation.

Trims Trim selection shown on reverse.

Labels UL listed for through-branch wiring, damp locations and IP • Product thermally protected against improper use of lamps • Union made • UL Listed/CSA certified • Trims 210N, 211 and 212N are wet location approved for covered ceiling applications • Trims 215 and 216 are wet location approved for covered ceiling applications, **when used with outdoor rated lamps.**

Testing All reports are based on published industry procedures; field performance may differ from laboratory performance.

Specifications subject to change without notice.

INSTALLATION

Real Nail® Bar Hangers Telescoping, Patented (US Patent D552,969) Real Nail 3 and Real Nail 2 systems permits quick placement of housing anywhere within 24" O.C. joists or suspended ceilings • Bars scored in two locations for fast, clean breaking, allowing housing installation in tight applications • Bars captive to mounting frame • Edge-mounted for extra strength • Quick-LoC slot (location identified on the mounting frame) and oversized locking set screw lock fixture in position • May be installed either perpendicular or parallel to junction box.

Real Nail 3 Bar Hanger Integral T-bar notch and clip secures housing in suspended ceiling grid – no accessory clips required • 24" expansion stop allows quick placement of fixture in standard grid spacing • Captive bugle-headed ring shank nail for quick one-step installation and easy removal with claw hammer for fixture relocation • Bar hanger foot contoured to align to bottom of construction joist • Alternate mounting holes included.

Real Nail 2 Bar Hanger (S options) Small bar hanger foot designed to install directly on strapping construction material • Features Real Nail captive nail system for quick one-step installation • G2405 accessory clips required for suspended ceiling installation.

Junction Box Pre-wired junction box provided with (5) ½" and (1) ¾" knockouts, (4) Non-metallic sheathed cable connectors and ground wire, UL listed/CSA certified for through-branch wiring, maximum 8 No. 12 AWG 90° C branch circuit conductors (4 in, 4 out) • Junction box provided with removable access plates • Knockouts equipped with pryout slots • **W options** are supplied with **push-in electrical connectors** for fast installation.

Mounting Frame 22-gauge die-formed galvanized steel mounting frame • Rough-in section (junction box, mounting frame, housing and bar hangers) fully assembled for ease of installation • Sight lines embossed on mounting frame to allow for easy viewing when aligning fixtures • Pre-installed Air-Loc gasket for **G options.**


Housing IC housing, .032" aluminum sealed for Air-Loc Compliance • Housing is vertically adjustable to accommodate up to a 1" ceiling thickness.

PRODUCT CODES

Catalog Number	Input Voltage	Lamp Rating
IC20	5" Incandescent New Construction IC Housing	120V A19/BR30/PAR20/PAR30/PAR30L/R20/R30 (See page 2 for max. trim rating)
IC20 G	5" Incandescent New Construction IC Housing with pre-installed Air-Loc gasket	120V A19/BR30/PAR20/PAR30/PAR30L/R20/R30 (See page 2 for max. trim rating)
IC20 S	5" Incandescent New Construction IC Housing with smaller footprint bar hanger (Real Nail 2)	120V A19/BR30/PAR20/PAR30/PAR30L/R20/R30 (See page 2 for max. trim rating)
IC20 S G	5" Incandescent New Construction IC Housing with smaller footprint bar hanger (Real Nail 2) and pre-installed Air-Loc gasket	120V A19/BR30/PAR20/PAR30/PAR30L/R20/R30 (See page 2 for max. trim rating)
IC20 W	5" Incandescent New Construction IC Housing with push-in electrical connectors for fast, secure installation	120V A19/BR30/PAR20/PAR30/PAR30L/R20/R30 (See page 2 for max. trim rating)
IC20 W G	5" Incandescent New Construction IC Housing with push-in electrical connectors and pre-installed Air-Loc gasket	120V A19/BR30/PAR20/PAR30/PAR30L/R20/R30 (See page 2 for max. trim rating)

Housing and trim can be ordered together or separate, but will always ship separately.

DIMENSIONS

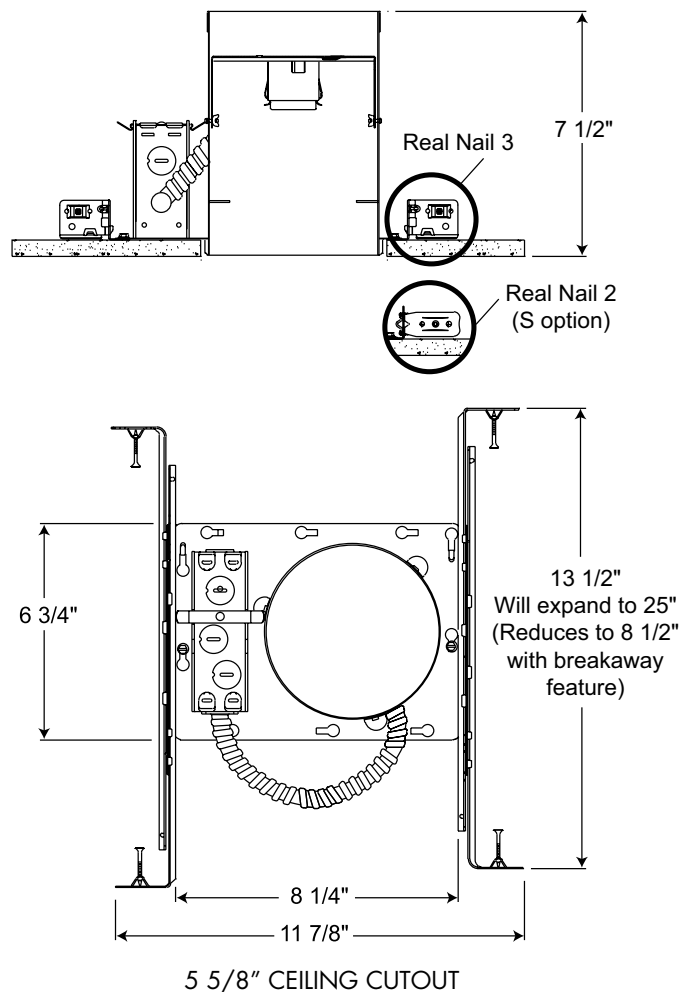

Accessories

Catalog Number	Description
ALG5	Air-Loc Gasket
G2405	T-Bar Clips (Set of 4), for S option only

To order, specify catalog number.

5" UNIVERSAL IC HOUSING

INCANDESCENT LAMPS

IC20 SERIES

TRIMS/LAMPS

	Catalog Number	Description	Max. Lamp Rating	
	201N WH	Open Frame Trim, White	65W BR30	
	205 BWH	Black Baffle, White Trim Ring	50W PAR30	
**	205 WWH	White Baffle, White Trim Ring		
	205 BSC	Black Baffle, Satin Chrome Trim Ring		
	205 BBRZ	Black Baffle, Bronze Trim Ring		
	204 CWH	Clear Alzak® Cone, White Trim Ring	50W PAR30	
	204 GWH	Gold Alzak® Cone, White Trim Ring		
	204 BWH	Black Alzak® Cone, White Trim Ring		
**	204 PTSC	Pewter Alzak® Cone, Satin Chrome Trim Ring		
	204 HZWH	Haze Cone, White Trim Ring		
	204 WWH	Gloss White Cone, White Trim Ring		
	204 WHZWH	Wheat Haze Cone, White Trim Ring		
	204 WHZBRZ	Wheat Haze Cone, Bronze Trim Ring		
	206 CWH	Clear Alzak® Cone, White Trim Ring	50W PAR30	
	206 GWH	Gold Cone, White Trim Ring		
	206 BWH	Black Cone, White Trim Ring		
**	206 PTSC	Pewter Cone, Satin Chrome Trim Ring		
	206 HZWH	Haze Cone, White Trim Ring		
	206 WHZWH	Wheat Haze Cone, White Trim Ring		
	206 WHZBRZ	Wheat Haze Cone, Bronze Trim Ring		
	207 CWH	Clear Alzak® Cone, White Trim Ring	50W PAR20/R20	
	207 GWH	Gold Cone, White Trim Ring		
	207 BWH	Black Cone, White Trim Ring		
**	207 WWH	White Cone, White Trim Ring		
	207 HZWH	Haze Cone, White Trim Ring		
	207 WHZWH	Wheat Haze Cone, White Trim Ring		
AIR-LOC	215 BWH ◆◆	Black Baffle, White Trim Ring	65W BR30, 75W PAR30L, 75W PAR30 w/Socket Extender	
	215 WWH ◆◆	White Baffle, White Trim Ring		
	216 CWH ◆◆	Clear Alzak® Cone, White Trim Ring	65W BR30, 75W PAR30L, 75W PAR30 w/Socket Extender	
	216 GWH ◆◆	Gold Cone, White Trim Ring		
AIR-LOC	216 WWH ◆◆	White Cone, White Trim Ring		
	216 HZWH ◆◆	Haze Cone, White Trim Ring		
	216 WHZWH ◆◆	Wheat Haze Cone, White Trim Ring		
	208N BWH	Eyeball with Black Baffle, White Trim Ring	50W PAR20/R20	
	208N WWH	Eyeball with White Baffle, White Trim Ring		
	529 WH	Eyeball Trim, White	75W PAR30	
	529 SC	Eyeball Trim, Satin Chrome		
	529 BRZ	Eyeball Trim, Bronze		
	209N WH	Gimbal Ring with Flat Trim, White	75W PAR30	
	688 BWH	Black Baffle, White Trim Ring	50W PAR30	
	688 WWH	White Baffle, White Trim Ring		
	689 CWH	Clear Alzak® Cone, White Trim Ring	50W PAR30	
	689 GWH	Gold Cone, White Trim Ring		
	689 WWH	White Cone, White Trim Ring		
	689 HZWH	Haze Cone, White Trim Ring		
	689 WHZWH	Wheat Haze Cone, White Trim Ring		
AIR-LOC	210N WH ◆	Lensed Flat Glass Shower Trim, White	40W A19	
	210N SC ◆	Lensed Flat Glass Shower Trim, Satin Chrome		
	210N BRZ ◆	Lensed Flat Glass Shower Trim, Bronze		
AIR-LOC	211 PW ◆	Lensed Dome Glass Shower Trim, Plastic White	40W A19	
	212N WH ◆	Frosted Lens with Clear Center Trim, White	40W A15, 50W PAR30	
	212N SC ◆	Frosted Lens with Clear Center Trim, Satin Chrome		
AIR-LOC	212N BRZ ◆	Frosted Lens with Clear Center Trim, Bronze		

Trim Size: 6¼" O.D. (except Cat No. 529 - 6½" O.D.)
Alzak is a registered trademark of Alcoa Corp.
Note: In Canada when insulation is present,
Type IC fixtures must be used.

AIR-LOC JUNO IC housings meet IECC Energy Code requirements per ASTM E283.

Air-Loc® rated trims are pre-gasketed for minimum air leakage with IC housings.

◆ UL Listed for use in wet location.

◆◆ UL Listed for use in wet location with outdoor rated lamp.

** NOTE: TR5 Trim Ring compatible with 204, 205, 206, 207 trims.

Housing and trim can be ordered together or separate, but will always ship separately.