




CORNICE HOOKS

Clear zinc plated finish.


Part#	A	B	C	D	Pkg. Qty.
65040	9/32"	1-3/4"	1"	3-1/16"	10
65041	3/16"	1-5/8"	7/8"	2-5/8"	10
65042	5/32"	1-3/8"	13/16"	2-1/4"	10
65043	1/8"	1-1/8"	11/16"	1-13/16"	10
65044	3/32"	3/4"	1/2"	1-3/8"	10

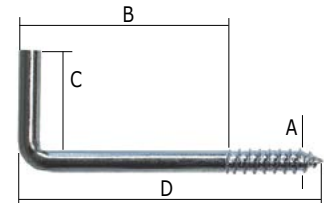

SCREW HOOKS

Clear zinc plated finish.


Part#	A	A (decimal)	B	C	C (mm)	D	Pkg. Qty.
65070	1/4"	.25	3-1/16"	1-1/32"	1.03	4-5/16"	10
65071	7/32"	.21	3-3/16"	1"	25.40	4-7/16"	10
65072	3/16"	.19	2-5/8"	27/32"	84.38	3-7/8"	10
65073	5/32"	.158	2-1/8"	11/16"	17.44	3-3/8"	10
65074	3/16"	.138	2-9/16"	1/2"	13.20	2-9/16"	10
65075	7/64"	.112	2-1/16"	13/32"	.41	2-1/16"	10
65076	3/32"	.086	1-1/16"	9/32"	.28	1-11/16"	10
65077	5/64"	.073	3/4"	15/16"	.94	1-5/16"	10

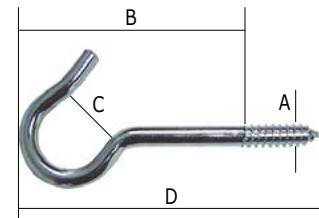

SCREW EYES

Clear zinc plated.


Part#	A	B	C	D	E	Pkg. Qty.
65000	0.281"	1-9/16"	1-5/16"	2-7/8"	13/16"	10
65006	0.216"	15/16"	1"	1-15/16"	17/32"	10
65014	0.112"	1/2"	3/8"	1-1/16"	11/32"	10
65017	0.190"	13/16"	5/8"	1-9/16"	25/64"	10
65018	0.158"	11/16"	5/8"	1-5/16"	21/64"	10
65019	0.138"	35/64"	15/32"	1-1/8"	19/64"	10
65020	0.112"	1/2"	13/32"	15/16"	1/4"	10
65024	0.250"	1-1/8"	7/8"	1-15/16"	19/64"	10
65030	0.138"	35/64"	7/16"	15/16"	3/16"	10
65031	0.112"	1/2"	3/8"	13/16"	5/32"	10

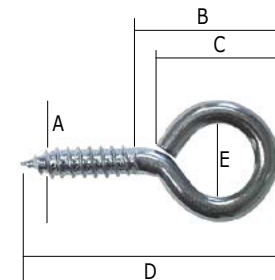

LAGSCREW EYEBOLTS

Clear zinc plated finish.


Part#	A	B	C	D	E	Pkg. Qty.	Available!	Qty.
65161	1/4"	1-5/16"	2-3/4"	3-3/4"	1/2"	10	65161B	25
65162	1/4"	1-7/8"	4"	5"	1/2"	10	65162B	25
65163	5/16"	1-7/8"	2-3/4"	4"	5/8"	10	65163B	25
65164	5/16"	1-7/8"	4-3/4"	6"	5/8"	10	65164B	25
65165	3/8"	1-15/16"	3"	4"	3/4"	10	65165B	25
65166	3/8"	2-7/8"	6-1/2"	8"	3/4"	10	65166B	25

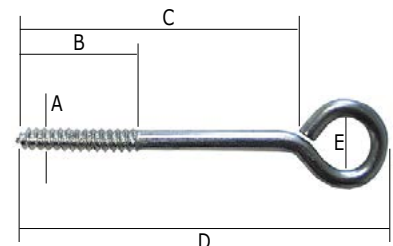

EYEBOLTS

Wire Formed. Supplied with Nut. Zinc plated finish.

Part#	A	B	C	D	E	Pkg. Qty.	Available!	Qty.
65102	3/16"	1"	1-3/8"	2"	3/8"	10	65102B	20
65104	3/16"	1-5/8"	1-3/4"	2-1/2"	3/8"	10	65104B	20
65106	1/4"	1"	1"	2"	9/16"	10	65106B	20
65107	1/4"	1-3/8"	1-1/2"	2-1/2"	9/16"	10	65107B	20
65108	1/4"	1-3/4"	2"	3"	9/16"	10	65108B	20
65109	1/4"	2-3/4"	3"	4"	9/16"	10	65109B	20
65110	1/4"	3"	4"	5"	9/16"	10	65110B	20
65111	1/4"	3"	5"	6"	9/16"	10	65111B	20
65112	5/16"	1-3/4"	2"	3-1/4"	3/4"	10	65112B	20
65113	5/16"	2-3/16"	2-1/2"	4"	3/4"	10	65113B	20
65114	5/16"	3"	3-1/2"	5"	3/4"	10	65114B	20
65115	5/16"	3"	4-1/2"	6"	3/4"	10	65115B	20
65117	3/8"	2"	2-1/4"	4"	1"	10	65117B	20
65118	3/8"	3"	3-1/4"	5"	1"	10	65118B	20
65119	3/8"	3"	4-1/4"	6"	1"	10	65119B	20
65120	3/8"	3"	6-1/4"	8"	1"	10	65120B	20
65123	1/2"	3"	3-3/4"	6"	1-1/4"	10	65123B	20
65124	1/2"	3"	5-3/4"	8"	1-1/4"	10	65124B	20

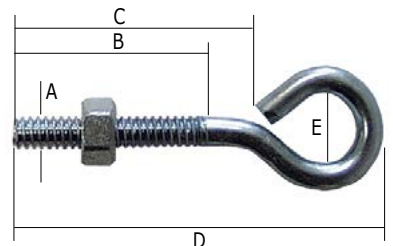

Sizes are approximate. Specifications subject to change without notice.