



Type IC, Wet Location & Air-Tight

DESCRIPTION


4" Round Recessed Gimbal LED fixture
 Regressed optics with low glare
 Adjustable 20° each direction and with 360° rotation

FEATURES & BENEFITS

3 light options - 3000K, 5CCT selectable, Dim to Warm 3000K-1800K
CRI 90+ for true color rendering
2 1/2" Deep - fits in limited ceiling space
Type IC Rated - no housing required
Fast & Easy to install - save on labor
Driver Inside Connection Box - no junction box needed

DIMENSIONS

ID 4" OD 5" Cut Out 4 1/4" to 4 1/2"

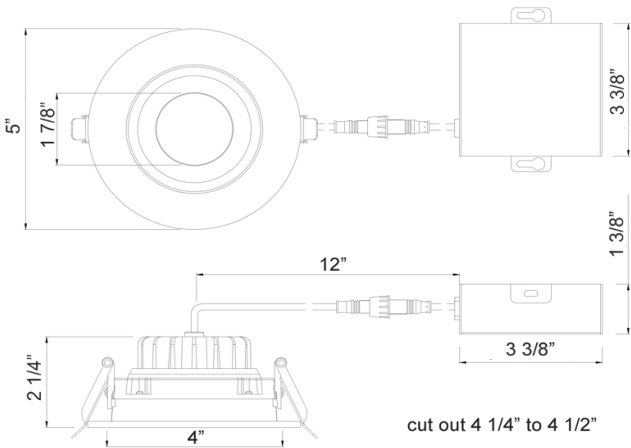

ORDERING GUIDE

Stock Options

light color	trim color	model
3000K	White	AD-LED-4-S12W-3K-WH-LREY
5CCT selectable	White	AD-LED-4-S12W-5CCT-WH-LREY
5CCT selectable	Black	AD-LED-4-S12W-5CCT-BK-LREY
Dim to Warm	White	AD-LED-4-S12W-DTW-WH-LREY
Dim to Warm	Black	AD-LED-4-S12W-DTW-BK-LREY

Single light color in stock 3000K round white trim
 Other options available by custom order MOQ 500 pcs

Dim to Warm is 3000K to 1800K

Optional Driver: Lutron Hi-lume EcoSystem 0.1% PEQ01UVN-2ABLK

Project: _____
 Location: _____
 Trim: _____ Qty: _____
 Notes: _____

SPECIFICATION	
Applications	Commercial & Residential Recessed
Energy Used	12 W
Color Temperature (K)	3000 5CCT 27K-30K-35K-40K-50K Dim to Warm
Light Output (lm)	880 780-820-890-920-910 700
Halogen Equivalent	90 W
Beam Angle	38° wide beam with 20° tilt and 360° rotation
CRI	90 +
Driver Input	120V AC 50/60 Hz
Dimming	TRIAC Dimmers 5% - 100%
Approved Location	Insulated Ceiling & Wet Locations
Air Tight	Yes
Ambient Temperature	-4° F (-20° C) to +104° F (+40° C)
Projected Life	70% Light Output at 50,000 Hours
Certification	cETLus, Energy Star, T24
Warranty	5 Year

Trim Options



White



Black

Other Trim Colors Available By Custom Order, MOQ 500 pcs

ACCESSORIES

Sold Separately



26" Flat Rough-In Plate cat # RIP4



13" Flat Mounting Plate cat # MP4-2



13" Flanged Mounting Plate cat # MP4



Flanged Plate with Hanger Bars cat # FRP4



Jumper Cable 10 ft cat # JC-10



Goof Ring OD 5 3/4"

White cat # GR4

Black cat # GR4-BK

COMPLIANCE



Type IC
Air-Tight