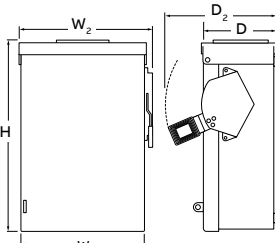
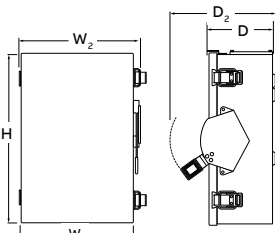


Safety switch enclosure dimensions

Heavy duty, NEMA type 3R

Heavy duty, NEMA type 3R
Approximate dimensions in inches

Diagrams	Product number	Dimension	Dimension	Dimension	Dimension	Dimension	Weight	Drawing #	KO
		H	W (box)	W2 (w/handle)	D (box)	D2 (w/handle)	(lbs.)		figure number
	TH2261RDC	13.1	8.2	8.9	4.0	7.9	11	10103091SH101	19
	TH2261RDCVW	13.1	8.2	8.9	4.5	7.9	11	15QC920057D0201	19
	TH2262RDC	22.0	9.2	9.7	4.8	7.9	19	10103091SH101	10
	TH2262RDCVW	22.0	9.2	9.7	5.3	7.9	19	15QC920057D0201	10
	TH2263RDC	22.1	9.3	10.2	4.9	9.8	20	10103091SH106	10
	TH2263RDCVW	22.1	9.3	10.2	5.4	9.8	20	15QC920058D0201	10
	TH3221R	10.5	6.2	6.6	3.1	7.7	7	10103091SH101	8
	TH3221RVW	10.5	6.2	6.6	3.6	7.7	7	15QC920057D0201	8
	TH3222R	17.2	9.2	9.7	4.8	7.9	16	10103091SH101	10
	TH3222RVW	17.2	9.2	9.7	5.3	7.9	16	15QC920057D0201	10
	TH3223R	22.1	9.3	10.2	4.9	9.8	18	10103091SH106	10
	TH3223RVW	22.1	9.3	10.2	5.4	9.8	18	15QC920058D0201	10
	TH3224R	31.7	13.4	14.3	5.4	9.5	34	10103091SH182	11
	TH3224RVW	31.7	13.4	14.3	5.9	9.5	34	15QC920059D0201	11
	TH3224RC	31.7	13.4	14.3	5.4	9.5	34	10103091SH182	11
	TH3224RCVW	31.7	13.4	14.3	5.9	9.5	34	15QC920059D0201	11
	TH3225R	49.5	23.0	24.1	8.5	13.9	128	10103091SH140	18
	TH3225RC	49.5	23.0	24.1	8.5	13.9	128	10103091SH140	18
	TH3226R	53.5	23.0	24.1	8.5	13.9	134	10103091SH140	18
	TH3226RC	53.5	23.0	24.1	8.5	13.9	134	10103091SH140	18
	TH3267RC	61.5	40.8	44.0	11.9	18.5	500	10103091SH118	No KO
	TH3268RC	76.6	46.6	45.8	12.9	18.9	490	10103091SH118	No KO
	TH3325R	49.5	23.0	24.1	8.5	13.9	127	10103091SH140	18
	TH3326R	53.5	23.0	24.1	8.5	13.9	139	10103091SH140	18
	TH3361R	13.1	8.2	8.9	4.0	7.9	11	10103091SH101	19
	TH3361RVW	13.1	8.2	8.9	4.5	7.9	11	15QC920057D0201	19
	TH3361RF	14.9	10.3	10.9	3.9	8.0	11	10103091SH133	No KO
	TH3361RF2	22.4	13.3	14.0	4.8	9.9	23	10103091SH134	No KO
	TH3362R	22.0	9.2	9.7	4.8	7.9	18	10103091SH101	10
	TH3362RVW	22.0	9.2	9.7	5.3	7.9	18	15QC920057D0201	10
	TH3362RF	22.4	13.3	14.0	4.8	9.9	18	10103091SH134	No KO
	TH3363R	22.1	9.3	10.2	4.9	9.8	19	10103091SH106	10
	TH3363RVW	22.1	9.3	10.2	5.4	9.8	19	15QC920058D0201	10
	TH3364R	31.7	13.4	14.3	5.4	9.5	33	10103091SH182	11
	TH3364RVW	31.7	13.4	14.3	5.9	9.5	33	15QC920059D0201	11
	TH3365R	53.5	23.0	24.1	8.5	13.9	132	10103091SH140	18
	TH3366R	53.5	23.0	24.1	8.5	13.9	136	10103091SH140	18
	TH4321R	10.5	6.2	6.6	3.1	7.7	7	10103091SH101	8
	TH4321RVW	10.5	6.2	6.6	3.6	7.7	7	15QC920057D0201	8
	TH4322R	17.2	9.2	9.7	4.8	7.9	16	10103091SH101	10
	TH4322RVW	17.2	9.2	9.7	4.8	7.9	16	15QC920057D0201	10
	TH4323R	22.1	9.3	10.2	4.9	9.8	18	10103091SH106	10
	TH4323RVW	22.1	9.3	10.2	5.4	9.8	18	15QC920058D0201	10
	TH4324R	31.7	13.4	14.3	5.4	9.5	34	10103091SH182	11
	TH4324RVW	31.7	13.4	14.3	5.9	9.5	34	15QC920059D0201	11
	TH4324RC	31.7	13.4	14.3	5.4	9.5	34	10103091SH182	11
	TH4324RCVW	31.7	13.4	14.3	5.9	9.5	34	15QC920059D0201	11
	TH4325RC	49.5	23.0	24.1	8.5	13.9	125	10103091SH140	No KO

(table continued on next page)