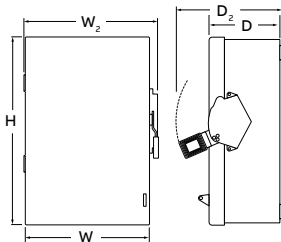


Safety switch enclosure dimensions

Heavy duty, NEMA Type 1

Heavy duty, NEMA Type 1

Approximate dimensions in inches

Diagram	Product number	Dimension H	Dimension W (box)	Dimension W2 (w/handle)	Dimension D (box)	Dimension D2 (w/handle)	Weight (lbs.)	Drawing #	KO figure number
	TH2261DC	12.6	8.3	9.5	5.4	7.6	11	10103091SH102	15
	TH2261DCVW	12.6	8.3	9.5	5.9	7.6	11	15QC920055D0201	15
	TH2262DC	21.3	9.1	9.4	5.0	8.6	18	10103091SH102	3
	TH2262DCVW	21.3	9.1	9.4	5.5	8.6	18	15QC920055D0201	3
	TH2263DC	22.3	9.3	10.1	4.8	9.8	19	10103091SH105	14
	TH2263DCVW	22.3	9.3	10.1	5.3	9.8	19	15QC920055D0201	14
	TH3221	10.3	6.3	7.1	3.3	6.1	6	10103091SH102	1
	TH3222	17.6	9.4	10.1	5.0	9.0	15	10103091SH102	3
	TH3222VW	17.6	9.4	10.1	5.5	9.0	15	15QC920055D0201	3
	TH3223	21.3	9.3	10.1	4.8	9.8	17	10103091SH105	3
	TH3223VW	21.3	9.3	10.1	5.3	9.8	17	15QC920055D0201	3
	TH3224	31.5	13.3	14.1	5.1	10.5	33	10103091SH105	4
	TH3224VW	31.5	13.3	14.1	5.6	10.5	33	15QC920055D0201	4
	TH3224B	31.5	13.3	14.1	5.1	10.5	33	10103091SH105	4
	TH3224C	31.5	13.3	14.1	5.1	10.5	33	10103091SH105	4
	TH3224CVW	31.5	13.3	14.1	5.6	10.5	33	15QC920056D0201	4
	TH3225	50.9	22.9	23.6	8.3	14.4	120	10103091SH112	6
	TH3225B	50.9	22.9	23.6	8.3	14.4	120	10103091SH112	6
	TH3225C	50.9	22.9	23.6	8.3	14.4	135	10103091SH112	6
	TH3226	50.9	22.9	23.6	8.3	14.4	134	10103091SH112	6
	TH3226B	50.9	22.9	23.6	8.3	14.4	134	10103091SH112	6
	TH3226C	50.9	22.9	23.6	8.3	14.4	134	10103091SH112	6
	TH3267C	61.5	40.8	44.0	11.9	18.5	500	10103091SH112	6
	TH3268C	76.6	46.6	45.8	12.9	18.9	480	10103091SH112	6
	TH3325	50.9	22.9	23.6	8.3	14.4	126	10103091SH112	6
	TH3325B	50.9	22.9	23.6	8.3	14.4	126	10103091SH112	6
	TH3326	50.9	22.9	23.6	8.3	14.4	138	10103091SH112	6
	TH3326B	50.9	22.9	23.6	8.3	14.4	138	10103091SH112	6
	TH3361	12.6	8.3	9.5	4.0	7.6	11	10103091SH102	15
	TH3361VW	12.6	8.3	9.5	4.5	7.6	11	15QC920055D0201	15
	TH3362	21.3	9.1	9.4	5.0	8.6	18	10103091SH102	3
	TH3362VW	21.3	9.1	9.4	5.0	8.6	18	15QC920055D0201	3
	TH3363	22.3	9.3	10.1	4.8	9.8	18	10103091SH105	14
	TH3363VW	22.3	9.3	10.1	5.3	9.8	18	15QC920055D0201	14
	TH3364	31.5	13.3	14.1	5.1	10.5	33	10103091SH105	4
	TH3364VW	31.5	13.3	14.1	5.6	10.5	33	15QC920055D0201	4
	TH3364B	31.5	13.3	14.1	5.1	10.5	34	10103091SH105	4
	TH3365	53.9	22.9	23.6	8.3	14.4	126	10103091SH112	6
	TH3365B	53.9	22.9	23.6	8.3	14.4	122	10103091SH112	6
	TH3366	53.9	22.9	23.6	8.3	14.4	139	10103091SH112	6
	TH3366B	53.9	22.9	23.6	8.3	14.4	139	10103091SH112	6
	TH4321	10.3	6.3	7.1	3.3	6.1	6	10103091SH102	1


(table continued on next page)

Safety switch enclosure dimensions

Heavy duty, NEMA type 1

Heavy duty, NEMA type 1

Approximate dimensions in inches

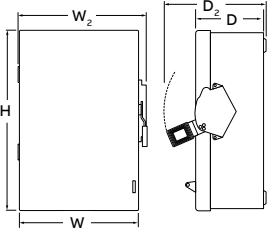Diagram	Product number	Dimension H	Dimension W (box)	Dimension W2 (w/handle)	Dimension D (box)	Dimension D2 (w/handle)	Weight (lbs.)	Drawing #	KO figure number
	TH4322	17.6	9.4	10.1	5.0	9.0	16	10103091SH102	3
	TH4322VW	17.6	9.4	10.1	5.5	9.0	16	1SQC920055D0201	3
	TH4323	21.3	9.3	10.1	4.8	9.8	17	10103091SH105	3
	TH4323VW	21.3	9.3	10.1	5.3	9.8	17	1SQC920056D0201	3
	TH4324	31.5	13.3	14.1	5.1	10.5	33	10103091SH105	4
	TH4324VW	31.5	13.3	14.1	5.6	10.5	33	1SQC920056D0201	4
	TH4324B	31.5	13.3	14.1	5.1	10.5	32	10103091SH105	4
	TH4324C	31.5	13.3	14.1	5.1	10.5	32	10103091SH105	4
	TH4324CVW	31.5	13.3	14.1	5.6	10.5	32	1SQC920056D0201	4
	TH4325	50.9	22.9	23.6	8.3	14.4	128	10103091SH112	6
	TH4325B	50.9	22.9	23.6	8.3	14.4	128	10103091SH112	6
	TH4325C	50.9	22.9	23.6	8.3	14.4	128	10103091SH112	6
	TH4326	50.9	22.9	23.6	8.3	14.4	139	10103091SH112	6
	TH4326B	50.9	22.9	23.6	8.3	14.4	139	10103091SH112	6
	TH4326C	50.9	22.9	23.6	8.3	14.4	80	10103091SH112	6
	TH4361	12.6	8.3	9.5	4.0	7.6	11	10103091SH102	15
	TH4361VW	12.6	8.3	9.5	4.5	7.6	11	1SQC920055D0201	15
	TH4362	21.3	9.1	9.4	5.0	8.6	18	10103091SH102	3
	TH4362VW	21.3	9.1	9.4	5.5	8.6	18	1SQC920055D0201	3
	TH4363	22.3	9.3	10.1	4.8	9.8	18	10103091SH105	14
	TH4363VW	22.3	9.3	10.1	5.3	9.8	18	1SQC920056D0201	14
	TH4364	31.5	13.3	14.1	5.1	10.5	33	10103091SH105	4
	TH4364VW	31.5	13.3	14.1	5.6	10.5	33	1SQC920056D0201	4
	TH4364C	31.5	13.3	14.1	5.1	10.5	32	10103091SH105	4
	TH4364CVW	31.5	13.3	14.1	5.6	10.5	32	1SQC920056D0201	4
	TH4365C	53.9	22.9	23.6	8.3	14.4	132	10103091SH112	6
	TH4366C	53.9	22.9	23.6	8.3	14.4	132	10103091SH112	6
	TH4367C	61.5	40.8	44.0	11.9	18.5	331	10103091SH118	No KO
	TH4368C	76.6	46.6	45.8	12.9	18.9	377	10103091SH118	No KO
	TH6621	14.4	18.7	19.9	5.9	12.3	33	10103091SH121	20
	TH6622	23.9	18.7	19.9	5.9	12.7	40	10103091SH121	20
	TH6623	23.9	18.7	19.8	5.8	10.9	45	10103091SH127	20
	TH6624	35.1	26.0	26.8	5.7	10.4	45	10103091SH127	20
	TH6661	14.4	18.7	19.9	5.9	12.3	33	10103091SH121	20
	TH6662	23.9	18.7	19.9	5.9	12.7	46	10103091SH121	20
	TH6663	23.9	18.7	19.8	5.8	10.9	46	10103091SH127	20
	TH6664	35.1	26.0	26.8	5.7	10.4	45	10103091SH127	20
	THN2261DC	10.3	8.3	9.3	4.0	7.7	9	10103091SH102	15
	THN2261DCVW	12.6	8.3	9.3	4.5	7.7	9	1SQC920055D0201	15
	THN2262DC	23.4	13.4	15.3	5.0	10.1	15	10103091SH102	3
	THN2262DCVW	23.4	13.4	15.3	5.5	10.1	15	1SQC920055D0201	3
	THN2263DC	17.6	9.3	10.1	4.8	9.8	23	10103091SH105	3
	THN2263DCVW	17.6	9.3	10.1	5.3	9.8	23	1SQC920056D0201	3
	THN3321	10.3	6.3	7.1	3.3	6.1	6	10103091SH102	1
	THN3361	10.3	8.3	9.3	4.0	7.7	9	10103091SH102	15
	THN3361VW	12.6	8.3	9.3	4.5	7.7	9	1SQC920055D0201	15
	THN3361CL	10.3	8.3	9.3	4.0	7.7	9	10103091SH102	15

(table continued on next page)