

Molded Case Circuit Breakers

Q-Line Circuit Breakers

Plug-in Circuit Breakers
240V Class

Section 6

THHQL 120 Vac


| # of Poles | Ampere Rating | Wire Range ¹ | 120 Vac Interrupting Rating | Product Number |
|------------|---------------|-------------------------|-----------------------------|------------------------|
| 1 | 15 | 14-8 Cu/12-8 Al | 22kA | THHQL1115 ² |
| 1 | 20 | 14-8 Cu/12-8 Al | 22kA | THHQL1120 ² |
| 1 | 25 | 14-8 Cu/12-8 Al | 22kA | THHQL1125 |
| 1 | 30 | 8-3 Cu/8-3 Al | 22kA | THHQL1130 |
| 1 | 35 | 8-3 Cu/8-3 Al | 22kA | THHQL1135 |
| 1 | 40 | 8-3 Cu/8-3 Al | 22kA | THHQL1140 |
| 1 | 45 | 8-3 Cu/8-3 Al | 22kA | THHQL1145 |
| 1 | 50 | 8-3 Cu/8-3 Al | 22kA | THHQL1150 |
| 1 | 60 | 8-3 Cu/8-3 Al | 22kA | THHQL1160 |
| 1 | 70 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL1170 |



THHQL1120

THHQL 120/240 Vac, Internal Common Trip

| # of Poles | Ampere Rating | Wire Range ¹ | 120/240 Vac Interrupting Rating | Product Number |
|------------|---------------|-------------------------|---------------------------------|----------------|
| 2 | 15 | 14-8 Cu/12-8 Al | 22kA | THHQL2115 |
| 2 | 20 | 14-8 Cu/12-8 Al | 22kA | THHQL2120 |
| 2 | 25 | 14-8 Cu/12-8 Al | 22kA | THHQL2125 |
| 2 | 30 | 8-3 Cu/8-3 Al | 22kA | THHQL2130 |
| 2 | 35 | 8-3 Cu/8-3 Al | 22kA | THHQL2135 |
| 2 | 40 | 8-3 Cu/8-3 Al | 22kA | THHQL2140 |
| 2 | 45 | 8-3 Cu/8-3 Al | 22kA | THHQL2145 |
| 2 | 50 | 8-3 Cu/8-3 Al | 22kA | THHQL2150 |
| 2 | 60 | 8-3 Cu/8-3 Al | 22kA | THHQL2160 |
| 2 | 70 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL2170 |
| 2 | 80 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL2180 |
| 2 | 90 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL2190 |
| 2 | 100 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL21100 |
| 2 | 110 | 2-2/0 Cu/2-2/0 Al | 22kA | THHQL21110 |
| 2 | 125 | 2-2/0 Cu/2-2/0 Al | 22kA | THHQL21125 |

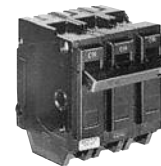

THHQL32015

THHQL 240 Vac, Internal Common Trip

| # of Poles | Ampere Rating | Wire Range ¹ | 240 Vac Interrupting Rating | Product Number |
|------------|---------------|-------------------------|-----------------------------|----------------|
| 2 | 15 | 14-8 Cu/12-8 Al | 22kA | THHQL22015 |
| 2 | 20 | 14-8 Cu/12-8 Al | 22kA | THHQL22020 |
| 2 | 25 | 14-8 Cu/12-8 Al | 22kA | THHQL22025 |
| 2 | 30 | 8-3 Cu/8-3 Al | 22kA | THHQL22030 |
| 2 | 35 | 8-3 Cu/8-3 Al | 22kA | THHQL22035 |
| 2 | 40 | 8-3 Cu/8-3 Al | 22kA | THHQL22040 |
| 2 | 45 | 8-3 Cu/8-3 Al | 22kA | THHQL22045 |
| 2 | 50 | 8-3 Cu/8-3 Al | 22kA | THHQL22050 |
| 2 | 60 | 8-3 Cu/8-3 Al | 22kA | THHQL22060 |
| 2 | 70 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL22070 |
| 2 | 80 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL22080 |
| 2 | 90 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL22090 |
| 2 | 100 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL22100 |
| 3 | 15 | 14-8 Cu/12-8 Al | 22kA | THHQL32015 |
| 3 | 20 | 14-8 Cu/12-8 Al | 22kA | THHQL32020 |
| 3 | 25 | 14-8 Cu/12-8 Al | 22kA | THHQL32025 |
| 3 | 30 | 8-3 Cu/8-3 Al | 22kA | THHQL32030 |
| 3 | 35 | 8-3 Cu/8-3 Al | 22kA | THHQL32035 |
| 3 | 40 | 8-3 Cu/8-3 Al | 22kA | THHQL32040 |
| 3 | 45 | 8-3 Cu/8-3 Al | 22kA | THHQL32045 |
| 3 | 50 | 8-3 Cu/8-3 Al | 22kA | THHQL32050 |
| 3 | 60 | 8-3 Cu/8-3 Al | 22kA | THHQL32060 |
| 3 | 70 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL32070 |
| 3 | 80 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL32080 |
| 3 | 90 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL32090 |
| 3 | 100 | 6-1/0 Cu/4-1/0 Al | 22kA | THHQL32100 |

¹Solid or stranded for 14-10 AWG.

²UL listed as SWD (switching duty) rated. Suitable for switching 120 Vac fluorescent lighting loads.

UL listed HACR (heating, air conditioning and refrigeration).

