



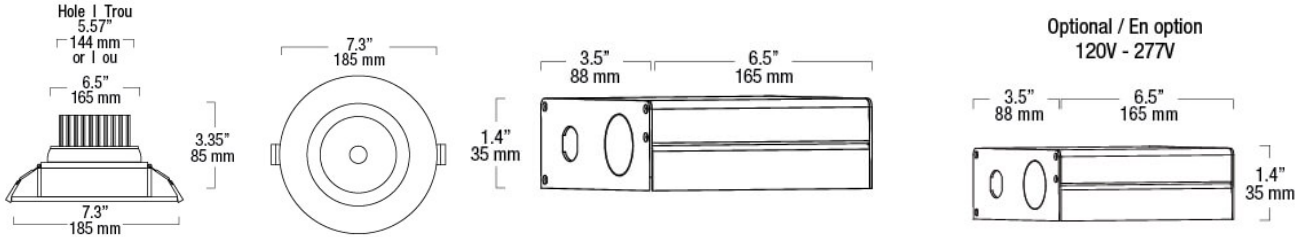
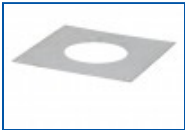
NAME:	
TYPE:	
DATE:	
NOTES:	

SPECIFICATIONS

LIGHT UNIT:	Aluminum Die cast with powder paint coat preventing discoloring and rusting.	CUTTING HOLE:	5" = 5.63" (142.8mm) / 6" = 6.33" (160.8mm)
WIRING:	Plenum rated cable used to connect light unit and junction box.	MOUNTING PLATE:	5" = MP / AMP / MPHB 500 / 6" = AMP / MPHB 600
JUNCTION BOX:	Aluminum extrusion, with knockouts located at each end. Wiring compartment allows for (6) 14 gauge (AWG) insulated conductors. Connection to one (1) downstream unit is permitted within the junction box compartment. The compartment satisfies junction box volume requirements of CSA C22.2 No. 250.0/UL 1598	BEAM ANGLE:	36°
INSTALLATION:	Ideal for ceiling installations with no housing required. Steel spring clip for easy installation. Suitable for installation in t-grid and drop ceiling applications. The flange is designed to accommodate either a 5" or 6" hole size, in a retrofit or new construction application.	GIMBAL ANGLE / HEAD ROTATION:	27° / 360
OPTICS:	COB (Chip on Board) LED technology uses light guided reflector to distribute light and optimize high level of delivered lumens. The deep regressed Gimbal design offers an anti-glare feature.	COLOR TEMPERATURE:	3K - 4K all finishes 5K white only
ELECTRICAL & PHASE CONTROL:	Easily connected to a 120V power supply via provided UL recognized driver. Optional 120-277V, 0-10V dimming driver available. Dimming down to 10% with most standard LED dimmers (see list of approved dimmers). Ambient operating temperature: -40°C (-40°F) to +40°C (+104°F). IC, WET Location and AIR-TIGHT rated. Phase Control: Forward Phase. Certifications: This product is ETL listed in USA & Canada, certified to UL standard 1598 and CSA standard C22.2 No. 250.0-08	CRI*:	80
		LUMEN OUTPUT:	1700 lumens
		DIMMABLE:	Yes
		WATTS:	19 watts
		LED LIFE:	50,000 hours
		WARRANTY:	5 years
		WIRE CABLE:	FT6 rated
		DRIVER (SPECIAL ORDER):	120-277V, 0-10V Dimming

APPLICATIONS

The ORBIT DEEP Regressed series offers a high-performance LED (COB) recessed downlight with a pressure-fit spring clip application for an easy install. Whether it is a Remodel or New Construction installation, this unit is well suited for indoor / outdoor residential, hospitality, commercial and multifamily applications. It does not require a recessed housing for installation.

DIMENSIONS

ACCESSORIES

MOUNTING PLATE

Versatile square mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.


REMODEL VAPOUR BARRIER

The remodel vapour barrier unit may be used with all ndr remodel housings. it is designed to prevent air leakage from your living space into the attic, or any insulated spaces.


ADJUSTABLE MOUNTING PLATE

Versatile adjustable mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.


MOUNTING PLATE WITH ADJUSTABLE HANGER BARS

Versatile adjustable mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.


GOOF RINGS

This goof ring is used when the ceiling hole is wider than the retrofit light unit being installed. refer to our goof ring compatibility chart to ensure the proper goof ring is selected.

RATINGS
AIRTIGHT
RATED

IC
RATED

ORDERING GUIDE

ORBIT 610 Series

Series	Color Temperature	Finish
OB610-1015	3K 3000K/80CRI/10W	WH White
	4K 4000K/80CRI/10W	BK Black
	5K 5000K/80CRI/10W	BRZ Bronze

Notes: Configure product using **BOLD** options: Ex: **OB610-1015-3K-WH**
5K available in white finish only

SPECIAL ORDER: ORBIT 610 SERIES

Series	Multi-Volt 120-277V	Color Temperature	Finish
OBS61	277V	3K 3000K/80CRI/10W	WH White
		4K 4000K/80CRI/10W	BK Black
		5K 5000K/80CRI/10W	BRZ Bronze

Notes: Configure product using **BOLD** options: Ex: **OBS61-277V-3K-WH**