



Long Life BAB 20W GU5.3 12V MR16 36D CL 1CT

Product family description
A range of Long Life low-voltage halogen burner
optically positioned in a glass reflector with front
glass.

Features/Benefits

- Color Consistent coating.
- Dichroic reflector coating is heat-transmitting and light-reflecting.
- UV-Block burner.
- Color temperature 3100K.
- Lifetime 6000 hours.
- Universal burning position.
- Variety of wattages and beam spreads..

Applications

- Ideal for retail stores, hotels, restaurants, museums and art gallery lighting.

Notes


- Rated average life is the length of operation (in hours) at which point an average of 50% of the lamps will still be operational and 50% will not. (93)

Product data	
Product Number	378158
Full product name	Long Life BAB 20W GU5.3 12V MR16 36D CL 1CT
Ordering Code	378158
Pack type	1 Lamp in a Folding Carton
Pieces per Sku	1
Skus/Case	50
Pack UPC	046677378158
EAN2US	
Case Bar Code	50046677378153
Successor Product number	
ANSI Code Halogen	BAB
Base	GU5.3
Bulb	MR16 [MR 16inch/50mm]


Product data	
Bulb Finish	Clear
Operating Position	Universal [Any or Universal (U)]
Packing Type	1CT [1 Lamp in a Folding Carton]
Packing Configuration	10X5F
Ordering Code	20MRC16/FL36 PRO BAB 50PK
Pack UPC	046677378158
Case Bar Code	50046677378153
Watts	20W
Voltage	12V
Dimmable	Yes
Beam Angle	36D
Color Rendering Index	100 Ra8
Color Temperature	3000 K
Overall Length C	46 mm
Diameter D	51 mm
Product Number	378158




DICHRO GU5.3 36D

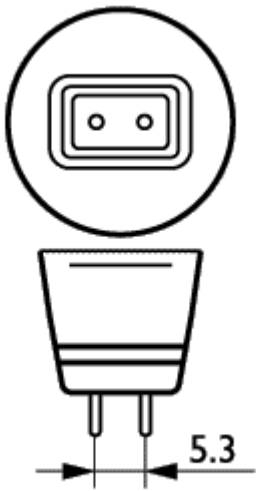

Base GU5.3

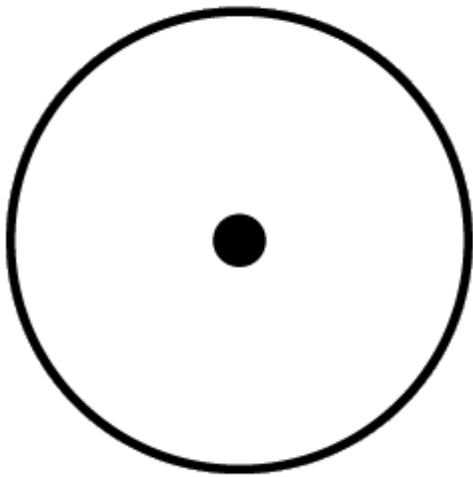


Operating Position Universal

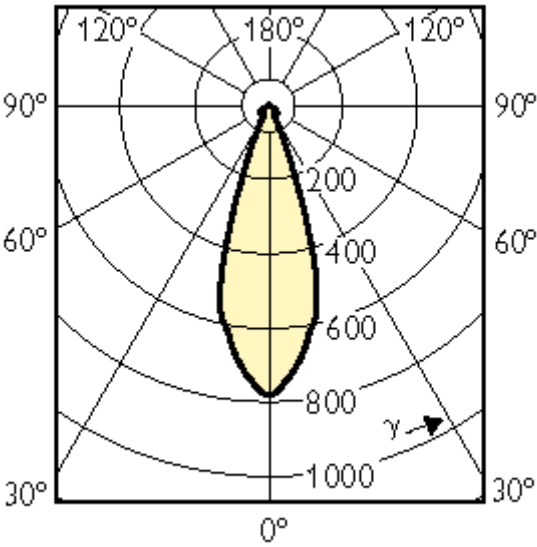


il

DICHRO 20W 36D

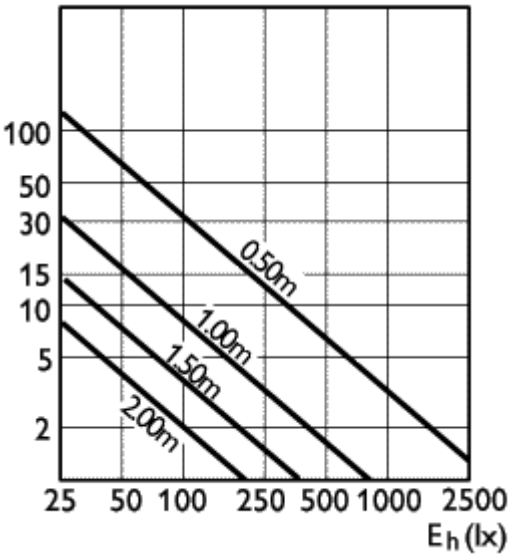

DICHRO 20W 36D

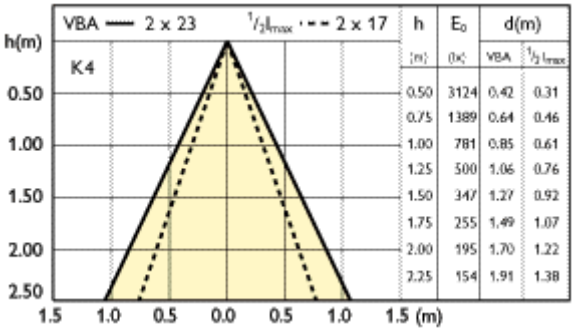

DICHRO 20W 36D

