

PHILIPS Stonco

Special Purpose

Roughlyte

Vaportight, incandescent



Project: _____

Location: _____

Cat.No: _____

Type: _____

Quantity: _____

Notes: _____

Philips Stonco Roughlyte vaportight is available in wattages ranging from 75 to 200. Applications include wall, columns, ceilings and canopys in exterior applications. Roughlyte fixtures guard against moisture and debris in exterior applications (for globe down mounting only). Features include heat and shock resistant glass or polycarbonate globe and cast aluminum bayonet guard with Allen head security screws. Not recommended for hazardous locations.

Ordering guide

Example: VCXL11GC

Series	Wattage	Lens*
<input type="text"/>	<input type="text"/>	<input type="text"/>
VK Surface and ceiling mount	11 100W	GC² Glass globe and cast guard
VCXL Ceiling 4" box mounted	21 200W	K² Glass globe
VW Wall mount	5¹ 60W	A³ Lexan globe
VWXL Wall 4" box mounted	10¹ 75W	
VP Pendant mount		
		*No lens suffix for unit with no globe

1. 60W and 75W only available with VCXL or VWXL and lexan globe option only. Not available in VP, VK, or VW.
2. For use with 100W and 200W units only
3. Lexan globe is for 60W and 75W VCXL and VWXL only. Not available in VP, VK, or VW nor higher wattage VCXL and VWXL.

Product Specifications

- All incandescent Roughlyte ceiling and wall fixtures are not supplied with a lamp. This fixture requires a medium base incandescent A lamp. The lamp can be clear or coated.
- Roughlyte fixtures guard against moisture and debris in exterior applications (for globe down mounting only).
- cULus listed for wet locations.
- **Not recommended for use in hazardous locations.**

VK/VCXL/VW/VWXL/VP Roughlyte vaportight


Incandescent

VK

- 100W fixtures fit all 3-1/2" round and octagon boxes and all 4" round boxes.
- Heat and shock resistant glass globe.
- Sockets are pre-wired with extra long 1/2" stripped leads.
- For 3/4" conduit, use VK series with VXL13 universal box.

Dimensions


Catalog No.	Height (H)	Dia. (D)
VK1	2"	4-1/8"
VK2	2"	5-1/8"
VK1K	7"	4-1/4"
VK2K	8-3/4"	5-1/8"
VK1GC	7-1/2"	4-1/4"
VK2GC	9-1/4"	5-1/4"

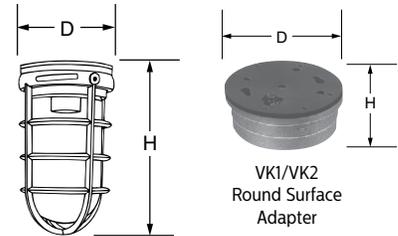


VW

- Fits all 4" round and octagon boxes.
- Order VCA1 mounting plate for all 3-1/2" 4" recessed octagon box mounting.
- Order VCP mounting plate for all 3-1/2" 4" recessed octagon and round boxes for plumb alignment.
- Heat and shock resistant glass globe.
- Sockets are pre-wired with extra long 1/2" stripped leads.
- For 3/4" conduit, use VW series with VXL13 universal box.

VW1	4-1/4"	5-3/8"
VW2	4-1/4"	5-7/8"
VW1K	9-1/4"	5-3/8"
VW2K	11"	5-7/8"
VW1GC	9-3/4"	5-1/2"
VW2GC	11-1/2"	6"

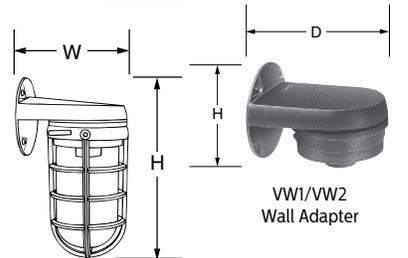


VCXL11	3-3/4"	4-1/4"
VCXL21	3-3/4"	5-1/8"
VCXL11K	8-5/8"	4-1/4"
VCXL21K	10-3/8"	5-1/8"
VCXL11GC	9-1/8"	4-1/4"
VCXL21GC	10-7/8"	5-1/4"
VCXL5A	8-5/8"	4-1/4"
VCXL10A	10-3/8"	5-1/8"

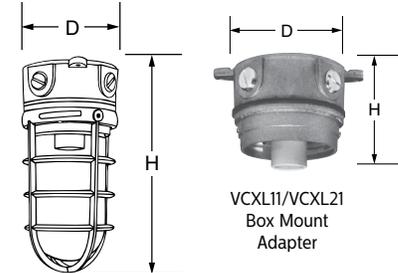

VCXL/VWXL

- Complete with 4" die-cast aluminum box, four side and top hole tapped 1/2" NPT (four plugs included).
- Heat and shock resistant glass or polycarbonate globe.
- Sockets are pre-wired with extra long 1/2" stripped leads.
- To use VCXL units with 3/4" conduit use VK Series with VXL13 universal box.
- To use VWXL units with 3/4" conduit, use VW Series with VXL13 universal box.


VWXL11	4-1/4"	7-1/8"
VWXL21	4-1/4"	7-7/16"
VWXL11K	9-1/4"	7-1/8"
VWXL21K	10-7/8"	7-7/16"
VWXL11GC	9-3/4"	7-1/4"
VWXL21GC	11-3/8"	7-1/2"
VWXL5A	9-1/4"	7-1/8"
VWXL10A	10-7/8"	7-7/16"

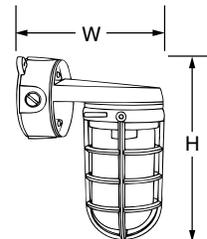

VP

- Top hub tapped 1/2" NPT.
- Heat and shock resistant glass globe.
- Sockets are pre-wired with extra long 1/2" stripped leads.

VP11	4"	4-1/8"
VP21	4"	5-1/8"
VP11K	9-1/4"	4-1/8"
VP21K	10-3/8"	5-1/8"
VP11GC	9-3/4"	4-5/16"
VP21GC	10-7/8"	5-5/16"

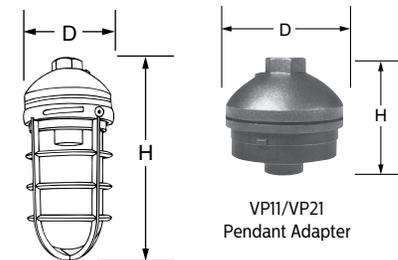

VK /VCXL/VW/VWXL/VP Roughlyte vaportight

Incandescent

Accessories



Roughlyte Round Box



Roughlyte Round Plug

4" Round boxes and plugs

Die-cast aluminum for use with conduit, Philips Stonco ceiling, surface and wall fixtures and flood lights. Four side and one back hole tapped 3/4" or 1/2", as shown. Heavy-duty gasket (except on VXL1), screws, four aluminum five-threaded plugs. No cover.

Catalog No.	Tap Size	Description	Catalog No.	NPT Size	Description
VXL1	1/2"	Mounting Box	V12	1/2"	Plug
VXL13	3/4"	Mounting Box	V13	3/4"	Plug



VGC100
Clear Glass Globe



VGP100
Clear Prismatic Globe



VGR100
Ruby Glass Globe



VPRC10
Prismatic Lexan Globe

Colored and specialty globes

Full molded threads. Fit all Philips Stonco housings. Globes for vertical mounting only.

Catalog No.	Description	Catalog No.	Description
3-1/2" GLOBE DIA. GLASS Height - 6 11/16"		4-3/8" GLOBE DIA. GLASS Height - 8 3/8"	
VGC100	Clear*	VGC200	Clear*
VGCH100	Clear, heat tempered	VGCH200	Clear, heat tempered
VGP100	Clear, prismatic	VGP200	Clear, prismatic
VGA100	Amber	VGA200	Amber
VGB100	Blue	VGB200	Blue
VGG100	Green	VGG200	Green
VGR100	Ruby	VGR200	Ruby
3-1/2" GLOBE DIA. LEXAN		4-3/8" GLOBE DIA. LEXAN	
VPRC5	Clear, prismatic (60W Max.)	VPRC10	Clear, prismatic (75W Max.)

*Standard with all incandescent glass fixtures.

NOTE: Use of colored globes will down-rate wattage.



V127
Plated Wire Guard



V131
Cast Aluminum Guard

Guards

Wire guards are clamp-on type. Cast aluminum guards are twist on/off bayonet type, includes allen head security screws. Shipped with threaded ring adapter for use with standard threaded bases or the new RoughLyte bases.

WIRE GUARD		CAST GUARD	
Catalog No.	Fits Globe Diameter	Catalog No.	Fits Globe Diameter
V127	3-1/2"	V131	3-1/2"



VCN
Adapter



VCA1
Recessed Box Adapter
For use with VW
and HID Series only.

Adapter plates

Permits easy box mounting over various size boxes and plumb alignment. Heavy-gauge aluminum. Complete with gasket, screws.

Catalog No.	Use With	For Mounting On
VCP	VK Series	4" octagon boxes
VCP	VW Series	3-1/2" round boxes
VCN	VK & VW Series	4" octagon boxes
VCA1	VW Series and HID Series	Recessed boxes

© 2016 Philips Lighting Holding B.V. All rights reserved. Philips reserves the right to make changes in specifications and/or to discontinue any product at any time without notice or obligation and will not be liable for any consequences resulting from the use of this publication. philips.com/luminaires



Philips Lighting North America Corporation
200 Franklin Square Drive, Somerset, NJ 08873
Tel. 855-486-2216

Philips Lighting Canada Ltd.
281 Hillmount Rd, Markham, ON, Canada L6C 2S3
Tel. 800-668-9008