



STC Series

200 AMP - 7 JAW Polyphase 3PH - 4 Wire Meter



CATALOGUE #	TYPE	DESCRIPTION	DIMENSIONS (IN.)			WEIGHT
			H	W	D	
STC700PK	O/H	7 Jaw, c/w hub closure plate	21 ¹ / ₂	10 ¹ / ₈	5 ¹ / ₈	21 lbs.
STC703PK	O/H	7 Jaw, c/w insulated neutral	21 ¹ / ₂	10 ¹ / ₈	5 ¹ / ₈	21 lbs.
STC700RK	O/H & U/G	7 Jaw, c/w hub closure plate	21 ¹ / ₂	12	5 ¹ / ₈	22 lbs.
STC703RK	O/H & U/G	7 Jaw, c/w insulated neutral	21 ¹ / ₂	12	5 ¹ / ₈	22 lbs.

- 200 Amp, 600 VOLT
- CSA enclosure 3R
- CSA approved for copper or aluminum
- Conductor range #6 -250 MCM CU/AL

- For overhead installations order **HD** hubs separately
- Field adapted insulated neutral **INK200**



KNOCKOUT CODE	CONDUIT SIZE
AA	1/2"
K	2", 2 1/2", 3"

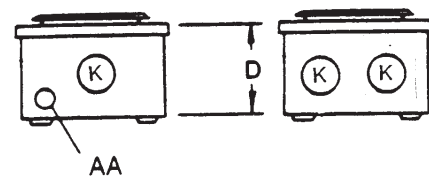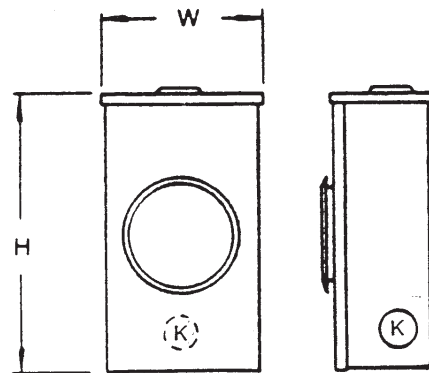

For permanent by-pass
use JC6B jumper cover