



# LED Corn Cobs

## 36CC/LED/850/ND EX39 G2 BB 6/1

Philips Corn Cob LED replacement lamps are perfect LED replacement for a variety of outdoor applications. High intensity illumination, which means you get added visibility for applications like streets, public areas, and much more for a fraction of the energy used by conventional HID.

### Product data


General Information	
Cap-Base	EX39 [ Exclusionary Mogul Screw ]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
Technical Type	36-150W
Light Technical	
Color Code	850 [ CCT of 5000K ]
Luminous Flux (Nom)	5400 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	150.00 lm/W
Color Consistency	ANSI 5000K quadrangle
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	36 W
Lamp Current (Nom)	400 mA
Wattage Equivalent	150 W
Starting Time (Nom)	1 s

Warm Up Time to 60% Light (Nom)	1 s
UL Type	Type B - bypass the ballast
Power Factor (Nom)	0.9
Voltage (Nom)	100-277 V
Temperature	
T-Case Maximum (Nom)	60 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Clear
Bulb Shape	Corncob
Approval and Application	
Energy Consumption kWh/1000 h	36 kWh
Product Data	
Order product name	36CC/LED/850/ND EX39 G2 BB 6/1
EAN/UPC - Product	046677559748
Order code	929002396304
Numerator - Quantity Per Pack	1

# LED Corn Cobs

Numerator - Packs per outer box	6
Material Nr. (12NC)	929002396304
Net Weight (Piece)	0.644 kg



## Dimensional drawing

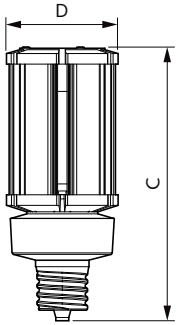

Corn lamp LED Gen2 36W EX39 850 CL


Product	D	C
36CC/LED/850/ND EX39 G2 BB 6/1	85 mm	213 mm

## Photometric data

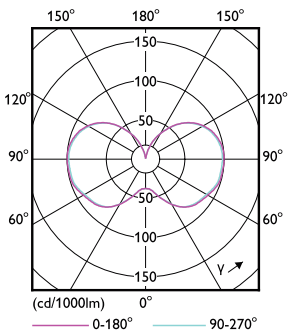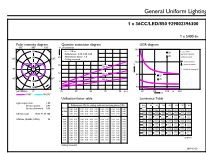

LEDTForce 36W Corncob EX39 850



LEDTForce 36W Corncob E26

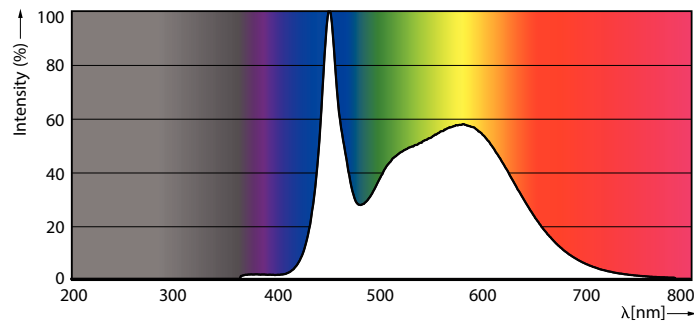

LEDTForce 36W Corncob 850

# LED Corn Cobs

## Lifetime

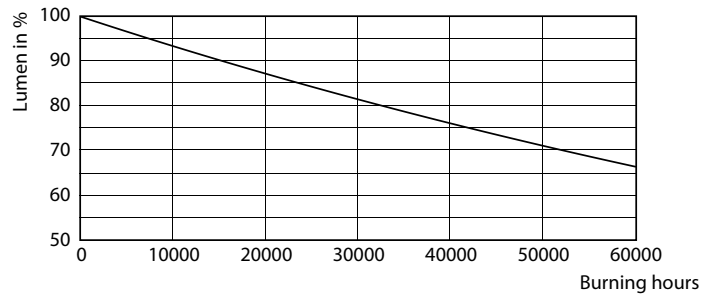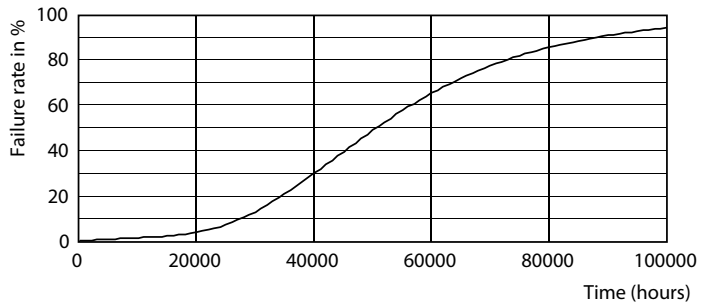

50K

50K

