



LED Corn Cobs

45CC/LED/840/ND EX39 G2 BB 6/1

Philips Corn Cob LED replacement lamps are perfect LED replacement for a variety of outdoor applications. High intensity illumination, which means you get added visibility for applications like streets, public areas, and much more for a fraction of the energy used by conventional HID.


Product data

General Information		Warm Up Time to 60% Light (Nom)	
Cap-Base	EX39 [Exclusionary Mogul Screw]		1 s
EU RoHS compliant	Yes	UL Type	
Nominal Lifetime (Nom)	50000 h		Type B - bypass the ballast
Switching Cycle	50000X	Power Factor (Nom)	
Technical Type	45-175W		0.9
		Voltage (Nom)	
			100-277 V
Light Technical		Temperature	
Color Code	840 [CCT of 4000K]	T-Case Maximum (Nom)	60 °C
Luminous Flux (Nom)	6500 lm	Controls and Dimming	
Color Designation	Cool White (CW)	Dimmable	No
Correlated Color Temperature (Nom)	4000 K	Mechanical and Housing	
Luminous Efficacy (rated) (Nom)	144.00 lm/W	Bulb Finish	Clear
Color Consistency	ANSI 4000K quadrangle	Bulb Shape	Corncob
Color Rendering Index (Nom)	80	Approval and Application	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Energy Consumption kWh/1000 h	45 kWh
Operating and Electrical		Product Data	
Input Frequency	50 to 60 Hz	Order product name	45CC/LED/840/ND EX39 G2 BB 6/1
Power (Nom)	45 W	EAN/UPC - Product	046677559762
Lamp Current (Nom)	500 mA	Order code	929002396504
Wattage Equivalent	175 W	Numerator - Quantity Per Pack	1
Starting Time (Nom)	1 s		

LED Corn Cobs

Numerator - Packs per outer box	6
Material Nr. (12NC)	929002396504
Net Weight (Piece)	0.758 kg



Dimensional drawing

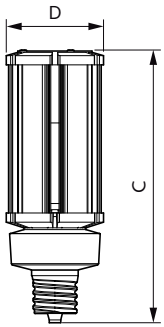

Corn lamp LED Gen2 45W EX39 840 CL


Product	D	C
45CC/LED/840/ND EX39 G2 BB 6/1	85 mm	245 mm

Photometric data

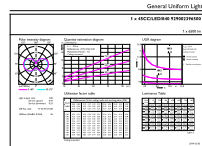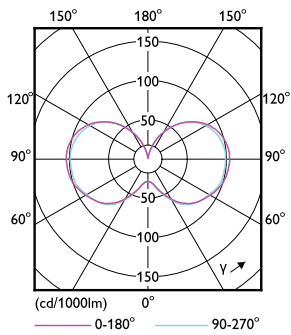

LEDTForce 45W Corncob EX39 840



LEDTForce 45W Corncob EX39

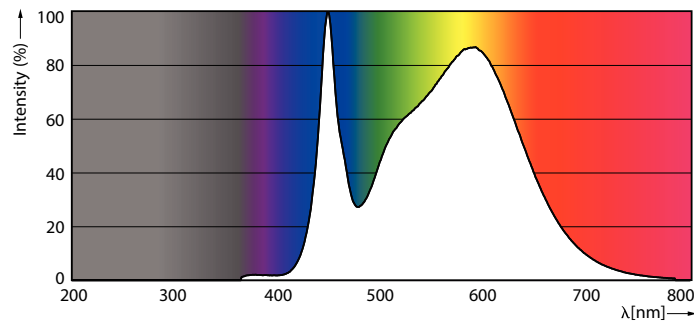

LEDTForce 36W Corncob 840

LED Corn Cobs

Lifetime

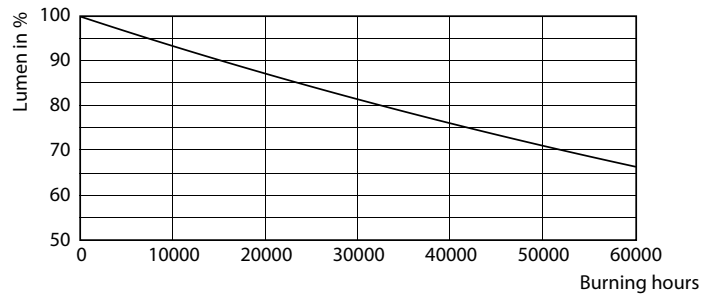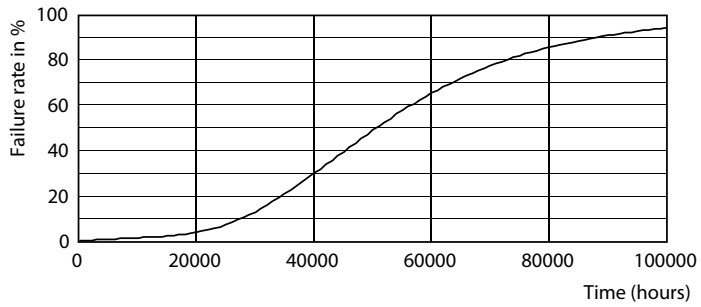

50K

50K

