

SLIMLED

4" & 6", RGB + Tunable White, Wi-Fi, 800-1200 Lumens, 12-16W
Recessed Downlighting

Features

Body

Durable airtight aluminum body with UV stable paint and white PMMA diffuser lens for low glare. Includes silicone gasket for wet location applications. Includes White and Black interchangeable magnetic trims.

LED Characteristics

This general application light fixture features a 12 watt (for 4") and 16 watt (for 6") LED module that maintains uniform intensity producing up to 1200 lumens; with a typical CRI of 90. RGB and Tunable White (2700 K ~ 5000 K).

Dimming

100%-4% Wi-Fi dimming capability. Dimming controlled via the WiZ App and Room Controller.

Beam Spread

The fixture lens provides 110° beam spread.

Mounting

Includes two spring loaded clips to attached to any ceiling material.

LED Driver

Extruded aluminum hardware box with 300mA (for 4") or 370mA (for 6") Wi-Fi dimmable LED driver with 100-135V AC input. Includes an 18" wire with 6-Pin DC connector between driver and fixture.

WiZ App

Can be controlled via the WiZ App (works with iOS and Android) from anywhere. Voice control can also be achieved by integrating the app with most smart speakers. Works with Google Assistant, Siri, Alexa and IFTTT.

Quick Connect push-in terminals

"Quick connect" push-in terminals in hardware box for fast and easy wiring.

Minimum Starting Temperature

-40°C (-40°F)


Environment

- Suitable for wet locations.
- Approved for direct contact with insulation.
- Suitable for indoor/outdoor applications
- Airtight

QuickShip In-Stock


In-Stock products ship within two business days of an order being released.*

SPECIFICATION	
Application	Ceiling Recess Mount
Approved Location	Wet / Insulated Ceilings / Indoor / Outdoor
Beam Angle	110°
CCT	RGB + Tunable White (2700 K - 5000 K)
Certification	cETLus
Class II	Yes
Color	WH
CRI	90
Dimming	Yes
Dimming Tech	Wi-Fi Dimming (via WiZ App)
Hole Cut	4": Ø 4¼" (108mm) 6": Ø 6¼" (159mm)
Input	100-135V AC, 60Hz
Lumens	4": up to 800 6": up to 1200
Lumens per Watt	Up to 76
Power Factor	>0.9
Projected Life	70% @ 50,000 hrs
Warranty	3-Year
Wattage	12W / 16W

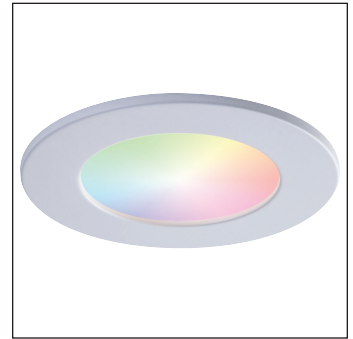

Description

SLIMLED OnCloud is a slim profile high-performance, easy to install residential grade downlight solution that offers good light output, energy-efficiency and streamlined design with interchangeable color trims. Suitable for wet locations.

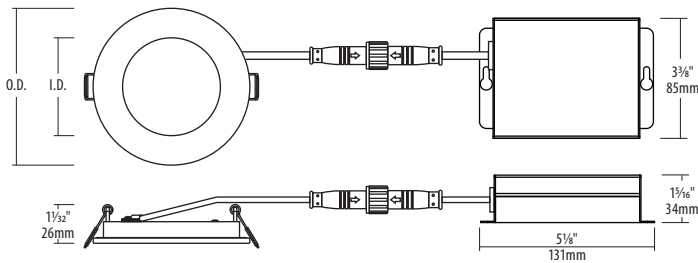

Size	O.D.	I.D.
SLM4	4 1/16" (122mm)	3" (76mm)
SLM6	6 1/16" (173mm)	4 1/16" (123mm)

Ordering Guide

Trim Size

SLM -RGBTW-WZ-WHBK

4 : 4"
6 : 6"



Notes: Accessories are sold separately. For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

* QuickShip lead time may vary for orders greater than 100 pieces. No additional shipment rates apply. Subject to availability.

Accessories



SLM4-12W-RT-BN

Faceplate for SLM4-12W-CCT, round, brushed nickel.



SLM4-12W-RT-OB

Faceplate for SLM4-12W-CCT, round, oil rubbed bronze.



SLM4-12W-RT-SL

Faceplate for SLM4-12W-CCT, round, silver.



SLM4-12W-ST-BK

Faceplate for SLM4S-12W-CCT, square, black.



SLM4-12W-ST-BN

Faceplate for SLM4S-12W-CCT, square, brushed nickel.



SLM4-12W-ST-OB

Faceplate for SLM4S-12W-CCT, square, oil rubbed bronze.



SLM4-12W-ST-SL

Faceplate for SLM4S-12W-CCT, square, silver.



P-4020

4 1/4" Round pre-mounting plate with driver attachment clip, for 4" SlimLED fixtures.



SLM4P-XLRING-BK

Extra large trim ring for 4" round SlimLED PLUS, metal, black.



SLM4P-XLRING-BN

Extra large trim ring for 4" round SlimLED PLUS, metal, brushed nickel.



SLM4P-XLRING-WH

Extra large trim ring for 4" round SlimLED PLUS, metal, white.



SLM6-16W-RT-BN

Faceplate for SLM6-16W-CCT, round, brushed nickel.



SLM6-16W-RT-OB

Faceplate for SLM6-16W-CCT, round, oil rubbed bronze.



SLM6-16W-ST-BK

Faceplate for SLM6S-16W-CCT, square, black.



SLM6-16W-ST-BN

Faceplate for SLM6S-16W-CCT, square, brushed nickel.



SLM6-16W-ST-OB

Faceplate for SLM6S-16W-CCT, square, oil rubbed bronze.



P-6020

6 1/4" Round pre-mounting plate with driver attachment clip, for 6" SlimLED fixtures.



SLM6P-XLRING-BK

Extra large trim ring for 6" round SlimLED PLUS, metal, black.



SLM6P-XLRING-BN

Extra large trim ring for 6" round SlimLED PLUS, metal, brushed nickel.



SLM6P-XLRING-WH

Extra large trim ring for 6" round SlimLED PLUS, metal, white.



P-NCMK-1

Hanger bar kit. Includes hanger bars, brackets and screws.



VBE-1

Vapour barrier extender. For use in new construction applications.



VBE-2

Vapour barrier extender. For use in remodel applications.



VBE-3

Vapour barrier extender. For use in remodel applications.



VBE-5

Vapour barrier extender. For use in new construction applications.



LC-CRTL-SCENE-1

OnCloud Room Controller, Wi-Fi, ON/OFF, CCT, Dimming and favourite scenes.