

RZR-CCT-430

SQUARE DOWNLIGHT WITH SELECTABLE COLOR TEMPERATURE



NAME:	
TYPE:	
DATE:	
NOTES:	

SPECIFICATIONS


LIGHT UNIT:	Aluminum Die cast with powder paint coat preventing discoloring and rusting.
JUNCTION BOX:	Aluminum extrusion, with knockouts located at each end. Wiring compartment allows for (6) 14 gauge (AWG) insulated conductors. Connection to one (1) downstream unit is permitted within the junction box compartment. The compartment satisfies junction box volume requirements of CSA C22.2 No. 250.0/UL 1598.
INSTALLATION:	Ideal for shallow ceiling installations with no housing required. Steel spring clip for easy installation and suitable in t-grid and drop ceiling applications.
WIRING:	Plenum rated cable used to connect light unit and junction box.
OPTICS:	BACK-lit LED technology uses light guided plate to distribute light. A polycarbonate lens is used to provide even illumination throughout the installation. The regressed design offers an anti-glare feature.
ELECTRICAL & PHASE CONTROL:	Easily connected to a 120V power supply via provided UL recognized driver. Dimming down to 10% with most standard LED dimmers (see list of approved dimmers). Ambient operating temperature: -40°C (-40°F) to +40°C (+104°F). IC, WET Location and AIR-TIGHT rated. Phase Control: Forward Phase. Certifications: This product is ETL listed in USA & Canada, certified to UL standard 1598 and CSA standard C22.2 No. 250.0-08

CUTTING HOLE:	4.25" (108mm)
MOUNTING PLATE:	MP / AMP / MPH 425
BEAM ANGLE:	107°
SELECTABLE COLOR TEMPERATURE:	3K - 4K - 5K selectable
CRI:	80
LUMEN OUTPUT:	680 lumens White, 650 lumens Black and Satin Chrome
DIMMABLE:	Yes
WATTS:	10 watts
LED LIFE:	50,000 hours
WARRANTY:	5 years
WIRE CABLE:	FT4 rated
DRIVER (SPECIAL ORDER):	120-277V, 0-10V Dimming


APPLICATIONS

This latest CCT (Correlated Color Temperature) technology is offered in a low-profile design. It features three (3) color temperatures 3K, 4K & 5K to select from. The color temperature selector is located on the light unit, which allows for color selection to be made at final install stage. It is IC and AIR-TIGHT rated and allows installation in almost any location, even directly under a ceiling joist. Whether is is a Remodel or New Construction installation, this unit is well suited for indoor / outdoor residential, hospitality, commercial and multifamily applications. It does not require a recessed housing for installation.


DIMENSIONS

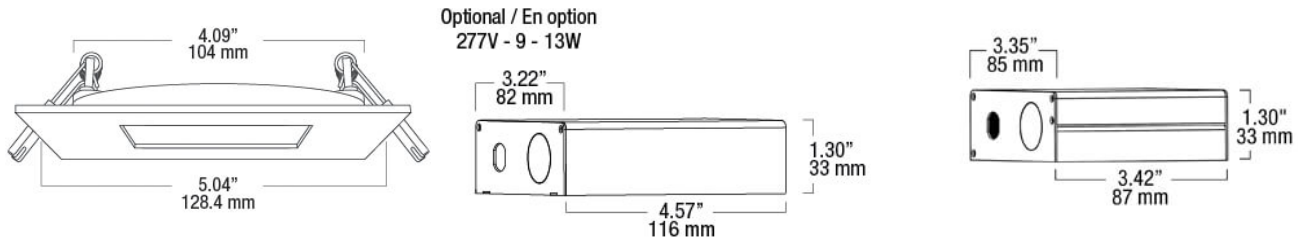


ACCESSORIES




MOUNTING PLATE
Versatile square mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.




RAZOR CABLES
These connecting cables are for use with the ndr electric razor series. these cables allow for greater flexibility in designing custom layout needs.




REMODEL VAPOUR BARRIER
The remodel vapour barrier unit may be used with all ndr remodel housings. it is designed to prevent air leakage from your living space into the attic, or any insulated spaces.




ADJUSTABLE MOUNTING PLATE
Versatile adjustable mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.



MOUNTING PLATE WITH ADJUSTABLE HANGER BARS
Versatile adjustable mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.



VAPOUR BARRIER
This vapour barrier unit may be used with all ndr recessed lighting products. it is designed to prevent air leakage from your living space into the attic, or any insulated spaces.



GOOF RINGS
This goof ring is used when the ceiling hole is wider than the retrofit light unit being installed. refer to our goof ring compatibility chart to ensure the proper goof ring is selected.

RZR-CCT-430

SQUARE DOWNLIGHT WITH SELECTABLE COLOR TEMPERATURE

RATINGS

AIRTIGHT
RATED

 **DIMMABLE**

 **ETL**
Intertek

 **ENERGY STAR**

IC
RATED

 **WET**
LOCATIONS

ORDERING GUIDE

RAZOR 430 CCT SERIES

Series	Color Temperature	Finish
RZR-CCT-430	3000K-4000K-5000K/80CRI/10W	WH White
	3000K-4000K-5000K/80CRI/10W	BLK Black
	3000K-4000K-5000K/80CRI/10W	SC Satin Chrome

Notes: Configure product using **BOLD** options: Ex: **RZR-CCT-430-WH**

SPECIAL ORDER: RAZOR 430 CCT SERIES

Series	Muli-Volt 120-277V	Color Temperature	Finish
RZRS430-CCT	277V	3000K-4000K-5000K/80CRI/10W	WH White
		3000K-4000K-5000K/80CRI/10W	BLK Black
		3000K-4000K-5000K/80CRI/10W	SC Satin Chrome

Notes: Configure product using **BOLD** options: Ex: **RZRS43-CCT-277V-WH**