



Features

- High-impact UV stabilized polycarbonate housing with 3/4" long nipple designed for internal mounting.
- Nipple is 3/8" NPS and fits through a 1/2" NPT hole.
- 6" #18 AWG wire leads rated at 105°C.
- Fail mode ON, contacts normally closed.

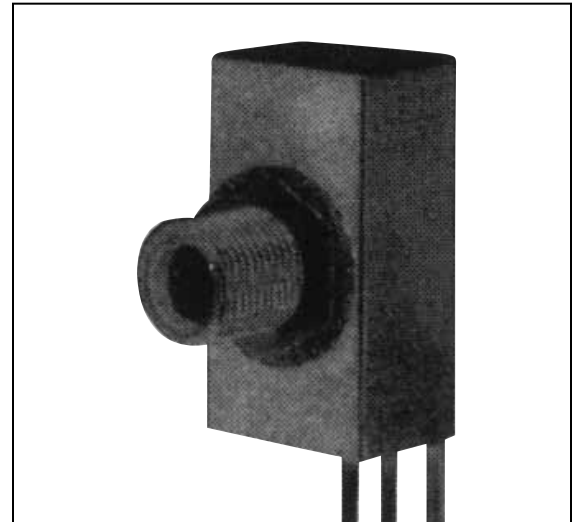

Dimensions

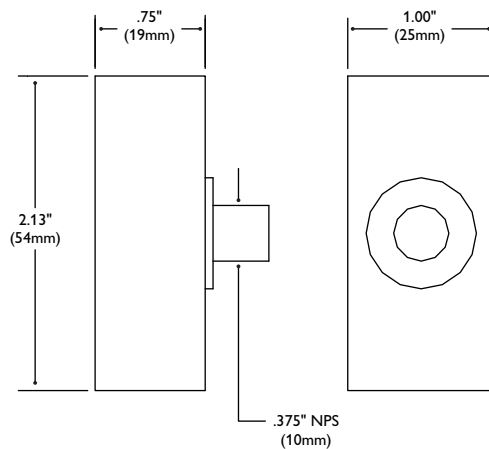

Catalogue No.	Volts	Max. Watts Incandescent	Max. Watts HID	
			HPF	NPF
P105A	120	1800	1000	400
P105M	208/240/277	1200	1000	400



Canlyte
 3015 Louis-Amos, Lachine, Québec H8T 1C4
 canlyte-info@philips.com • (514) 636-0670 • www.canlyte.com
 SD0853 December 17, 2012.
 Specifications are subject to change without notice.
 © Koninklijke Philips Electronics N.V., 2011. All rights reserved.

Job Information	Type:
Job Name:	
Cat. No.:	
Lamp(s):	
Notes:	