



A-Shape LED

14A19/LED/827/FR/P/ND 4/2FB

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	11000 h
Switching Cycle	50000X
Technical Type	14-100W
Light Technical	
Color Code	827 [CCT of 2700K]
Luminous Flux (Nom)	1500 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	107.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	14 W
Lamp Current (Nom)	255 mA
Wattage Equivalent	100 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s

Power Factor (Nom)	0.5
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	95 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Frosted
Bulb Shape	A19 (A19)
Approval and Application	
Energy Consumption kWh/1000 h	14 kWh
Product Data	
Order product name	14A19/LED/827/FR/P/ND 4/2FB
EAN/UPC - Product	50046677461978
Order code	461979
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929002311715
Net Weight (Piece)	0.042 kg

A-Shape LED


Dimensional drawing

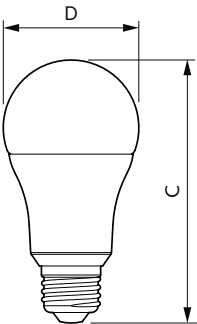


Bulb A60 15-100W 1500lm 2700K E26 ND

Product	D	C
14A19/LED/827/FR/P/ND 4/2FB	60 mm	117 mm


Photometric data

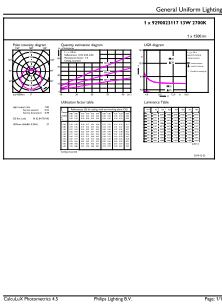

LEDbulb 14W E26 A9 827 FR

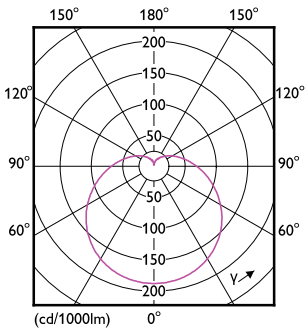

LEDbulb E26 A9 FR 1

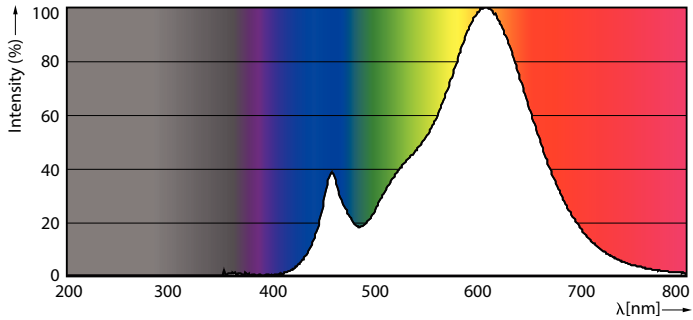


LEDbulb 14W E26 A9 827 FR

A-Shape LED

Lifetime



15K LED

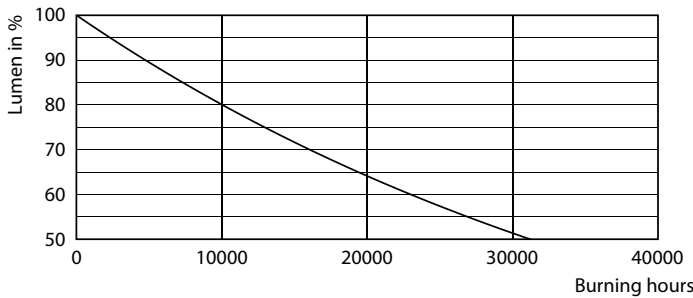

15K LMP

