

## Roughing-In

### Accessories

CI8903 / CI8904 /



CI8910 / CI8912




CI8905



CI8920 (2-1/2 po) / CI8922 (3 po)



CI8930

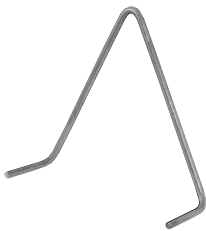

CI8932



CSA not applicable

Cat. No.	Trade Size	Working Load
<b>"Lion" Chain (Zinc-Plated Steel)</b>		
CI8903	#2	115 lb. (52 kg)
CI8904	#3	90 lb. (40 kg)
<b>"Jack" Chain (Zinc-Plated Steel)</b>		
CI8910	#10-T	43 lb. (19 kg)
CI8912	#12	29 lb. (13 kg)
<b>"S" Hooks (Zinc-Plated Steel)</b>		
CI8905	#105	73 lb. (34 kg)
<b>"Screw" Hooks (Zinc-Plated Steel)</b>		
CI8920	#M-10	90 lb. (40 kg)
CI8922	#M-12	115 lb. (52 kg)
<b>Fixture Hooks - 90° (Zinc-Plated Steel)</b>		
CI8930	—	115 lb. (52 kg)
<b>Fixture Hooks - Looped (Zinc-Plated Steel)</b>		
CI8932	—	115 lb. (52 kg)
<b>Tie Wire (Steel - Gauge No. 16)</b>		
CI8960 (300 ft. Coil)	0.06	125 lb. (56 kg)

CI8960



CIDUCT-1 / CIDUCT-5



Cat. No.	Trade Size
<b>Duct Seal Compound (Asbestos Free)</b>	
CIDUCT-1	1 lb.
CIDUCT-5	5 lb.

SEALS IRREGULAR OPENING FROM AIR, DUST OR WATER. Non-hardening sealant that adheres to metal, masonry, wood or plastic. Meets requirement of clause 12.018 CDN ELECTRICAL CODE Part 1. Safe and easy to use. - NON-CORROSIVE - NON-TOXIC - NO ASBESTOS - NO UNPLEASANT ODOR - WILL NOT STAIN OR HARM HANDS. TEMPERATURE Continuous operating range: -34°C to 88°C (-30°F to 190°F). Minimum Temperature for installation: -12°C (10°F)