

Black™ High Temperature


The Marrette® Black™ High Temperature rating makes it the best solution for high wattage lighting fixtures and signs.

External Cap

- Made of rugged, thermoplastic polymer material 150°C rated.
- Large, finely ribbed, “barrel-shaped” cap - makes it easier to grip even when hands are greasy or damp
- Deep, wide throat ensures full insulation coverage.
- Threaded entry helps guide large wire bundles right into the spring.

Inner Spring

- Internal conical spring design multiplies the “twist-on” torque applied by the leverage and wedge action, to firmly crush wires into a solid joint.
- Unique copper-coated spring helps resist corrosion
- Model no. 30 Black™ is approved for circuit and fixture type connections up to 300V only
- Model nos. 31, 33 and 35 Black™ are approved for circuits up to 600V, and lighting fixtures and signs up to 1000V.
- For copper conductor only.
- Convenient packaging - sized right and job-site ready!

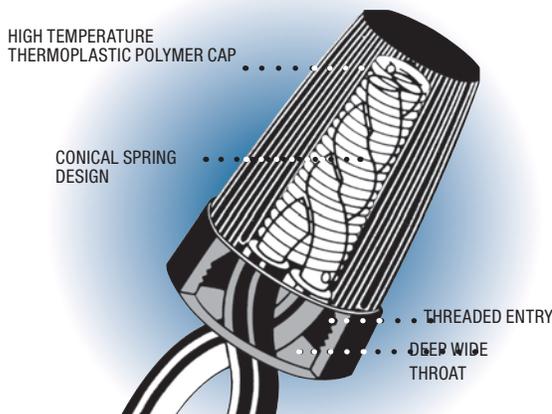

Black™ High Temperature

Ordering Information

Model	Colour	AWG Wire Range							
		22	20	18	16	14	12	10	8
30	black	Min.: 1 #22 + 1 #20 Max.: 3 #16							
31	black			Min.: 2 #18 Max.: 4 #16					
33	black			Min.: 1 #18 + 1 #14 Max.: 4 #14					
35	black			Min.: 2 #14 Max.: 4 #10					

Note: Refer to pages A20 to A23 for related Wire Combination Reference Guides



	Cat. No.	Packaging Format	Quantity per Package	Std. Pkg. (Min./Mult.)
30	30P	Propak	100	1,000 Units
	30BP	Bulk Box		1,000 Units
	30BK	Flip-Pak	15,000	15,000 Units
31	31P	Propak	100	1,000 Units
	31D	Flip-Pak	500	500 Units
	31M	Flip-Pak	1,000	1,000 Units
	31BK	Flip-Pak	10,000	10,000 Units
33	33P	Propak	100	1,000 Units
	33D	Flip-Pak	500	500 Units
	33BK	Flip-Pak	5,000	5,000 Units
35	35P	Propak	100	800 Units
	35Q	Flip-Pak	200	800 Units
	35D	Flip-Pak	500	500 Units
	35BK	Flip-Pak	5,000	5,000 Units