

ACS® Aluminum Wiring (Brown)




The Marrette® ACS® Aluminum Wiring wire connector is a fixed spring, twist-on connector made of special spring wire materials and coatings, to meet the rigorous standards for aluminum wire connections.

External Cap

- Made of sturdy, thermoplastic valox resin 125°C rated.
- Deep, wide throat ensures full insulation coverage.
- Threaded entry helps guide large wire bundles right into the spring.

Inner Spring

- Made of a special bronze alloy and then plated with a thick coating of tin to satisfy the rigorous standards established for aluminum wire connections.
- Round spring design ensures that aluminum conductors and highly stranded copper wires are not scored or severed when joined.
- Approved for circuits up to 600 V, and lighting fixtures and signs up to 1000 V.
- Approved for aluminum-to-aluminum, copper-to-copper, aluminum-to-copper (or highly stranded copper) connections.
- Convenient packaging - sized right and job-site ready!
- Not UL listed.

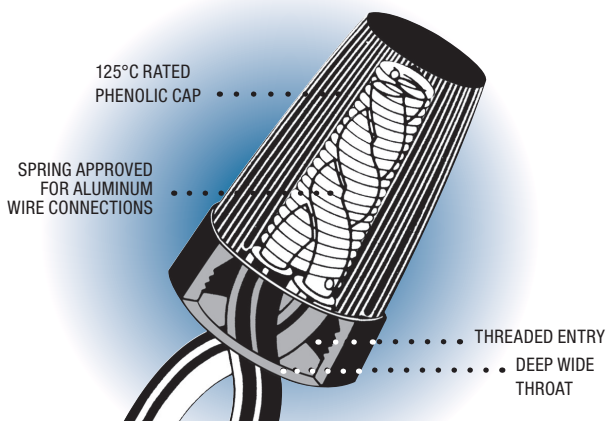

ACS® Aluminum Wiring (Brown)

Ordering Information

| Model | Colour | AWG Wire Range | | | | | | | |
|-------|--------|----------------|----|---------------------------------|----|----|----|----|---|
| | | 22 | 20 | 18 | 16 | 14 | 12 | 10 | 8 |
| 63 | brown | | | Min.: 1 #18 + 1 #14 Max.: 4 #14 | | | | | |
| 65 | brown | | | Min.: 2 #14 Max.: 1 #12 + 2 #10 | | | | | |

Note: Refer to pages A26 to A28 for related Wire Combination Reference Guides



| | Cat. No. | Packaging Format | Quantity per Package | Std. Pkg. (Min./Mult.) |
|----|----------|------------------|----------------------|------------------------|
| 63 | 63P | Propak | 100 | 1,000 Units |
| | 63D | Flip-Pak | 500 | 500 Units |
| 65 | 65P | Propak | 100 | 1,000 Units |
| | 65D | Flip-Pak | 500 | 500 Units |