

Project/Location:
Contractor:
Date:
Prepared by:
Lumacell Model:



RS-WPRB

Weatherproof Remote Fixture Series

FEATURES

- Sealed beam, PAR 36, surface-mounted, rubber coated industrial remote fixture
- For use in high pressure hose down areas
- Available only in black
- CSA certified to C22.2 No. 141




REPLACEMENT LAMPS

MODEL	LAMP TYPE	VAGE-WATTAGE
550.0026-L	Tungsten	12V-12W
550.0027-L	Tungsten	12V-18W
550.0023-L	Tungsten	12V-25W
*580.0030-L	Halogen	12V-55W
*580.0031-L	Halogen	24V-70W

*Lamps for RS10QWPBH. See the complete list p. 144 to 146.

DIMENSIONS

Dimensions are approximate and subject to change.

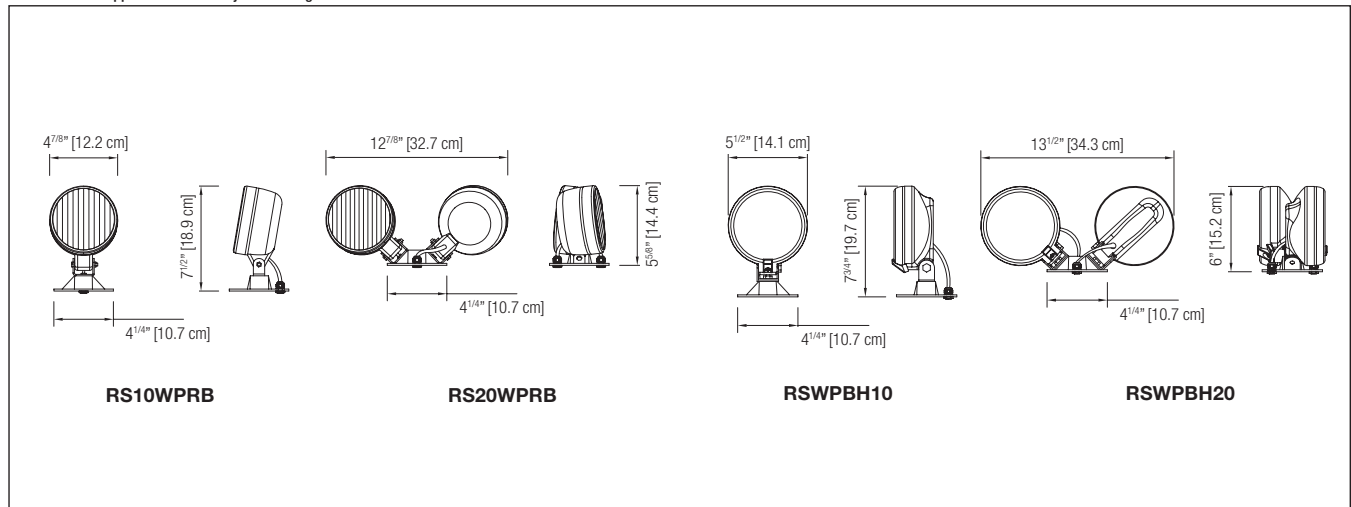

ORDERING INFORMATION

SERIES	NUMBER OF HEADS	VOLTAGE/WATTAGE/LAMP TYPE	OPTIONS
RS= PAR 36	10= single head 20= double head	SBWPRB6V __ W= 6V-9, 12, 18 or 25W, tungsten, sealed beam SBWPRB12V __ W= 12V-12, 18 or 25W, tungsten, sealed beam QSBWPRB6V __ W= 6V-8, 12 or 20W, halogen, quartz, sealed beam QSBWPRB12V __ W= 12V-8, 12 or 37W, halogen, quartz, sealed beam	TC= teflon coated lens (RB only)
RS	10= single head 20= double head	QWPBH24V70W= 24V-70W, halogen, quartz, H3 QWPBH12V55W= 12V-55W, halogen, quartz, H3 NOTE: " __ " insert wattage required	TC= teflon coated lens (RB only)

EXAMPLE: RS10SBWPRB6V9W