

INKZALL™ JOBSITE MARKERS

**WRITES ON
DUST
WET
OILY
SURFACES**



Clog Resistant



Model #	Description
48-22-3150	12 Pc INKZALL™ Ultra Fine Point Black Markers
48-22-3154	4 Pc INKZALL™ Ultra Fine Point Black Markers
48-22-3104	4 Pc INKZALL™ Fine Point Black Marker
48-22-3105	2 Pc INKZALL™ Fine Point Black Markers
48-22-3107	8 Pc INKZALL™ Fine Point Color Marker
48-22-3106	4 Pc INKZALL™ Fine Point Color Marker
48-22-3101	INKZALL™ Stylus and Fine Point Black Marker
48-22-3102	2 Pc INKZALL™ Medium Point Black Marker

Model #	Description
48-22-3103	INKZALL™ Chisel Tip Black Marker
48-22-3109	4 Pc INKZALL™ Chisel Tip Color Marker
48-22-3100	INKZALL™ Fine Point Black Markers (Bulk 36 Pc)
48-22-3130	INKZALL™ Chisel Tip Black Marker (Bulk 36 Pc)
48-22-3170	INKZALL™ Fine Point Red Markers (Bulk 36 Pc)
48-22-3180	INKZALL™ Fine Point Blue Markers (Bulk 36 Pc)
48-22-3190	INKZALL™ Fine Point Green Markers (Bulk 36 Pc)

INKZALL™ METALLIC MARKERS



Visible On Dark Surfaces




Model #	Description
48-22-3121	2 Pc INKZALL™ Fine Point Silver Metallic Marker
48-22-3122	2 Pc INKZALL™ Fine Point Gold Metallic Marker
48-22-3123	2 Pc INKZALL™ Fine Point Silver/Gold Metallic Marker

INKZALL™ LIQUID PAINT MARKERS

**BLEED &
SMEAR
RESISTANT**



Marks on Surfaces up to 300°F

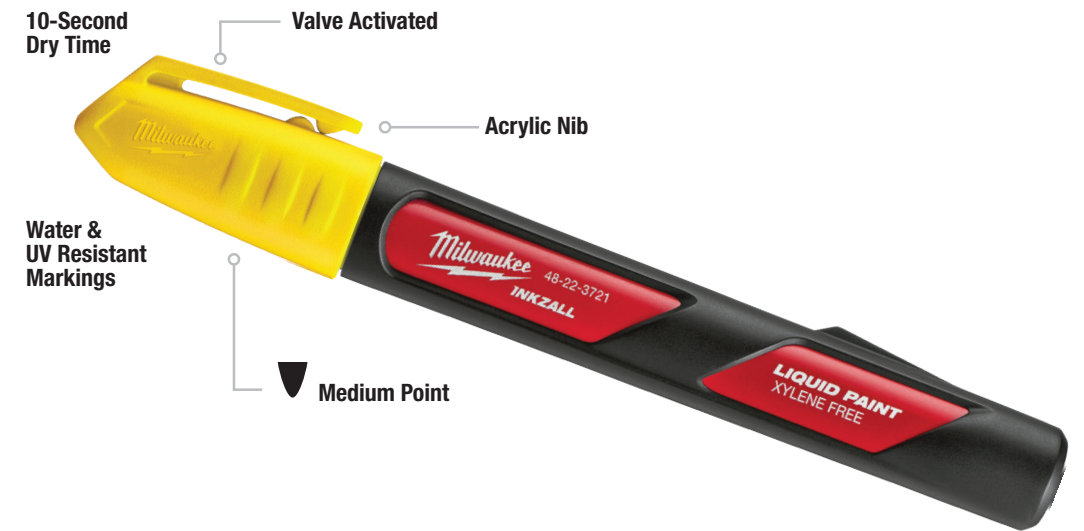


Model #	Description
48-22-3712	INKZALL™ Medium Point White Liquid Paint Marker
48-22-3722	INKZALL™ Medium Point Yellow Liquid Paint Marker
48-22-3711	INKZALL™ Medium Point White Liquid Paint Marker (Bulk 12 Pc)
48-22-3721	INKZALL™ Medium Point Yellow Liquid Paint Marker (Bulk 12 Pc)
48-22-3731	INKZALL™ Medium Point Black Liquid Paint Marker (Bulk 12 Pc)

Model #	Description
48-22-3741	INKZALL™ Medium Point Red Liquid Paint Marker (Bulk 12 Pc)
48-22-3751	INKZALL™ Medium Point Green Liquid Paint Marker (Bulk 12 Pc)
48-22-3761	INKZALL™ Medium Point Blue Liquid Paint Marker (Bulk 12 Pc)
48-22-3771	INKZALL™ Medium Point Orange Liquid Paint Marker (Bulk 12 Pc)

INKZALL™ JOBSITE PENS

**SHARP,
PRECISE
LINES**

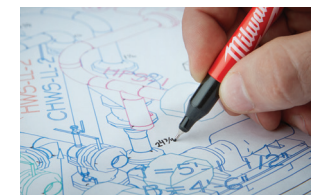

Model #	Description
48-22-3160	12 Pc INKZALL™ Ultra Fine Point Black Pen
48-22-3161	12 Pc INKZALL™ Ultra Fine Point Red Pen
48-22-3162	12 Pc INKZALL™ Ultra Fine Point Blue Pen
48-22-3164	4 Pc INKZALL™ Ultra Fine Point Black Pen
48-22-3165	4 Pc INKZALL™ Ultra Fine Point Color Pen

INKZALL™ JOBSITE HIGHLIGHTERS


UP TO **4X LONGER LIFE**



Model #	Description
48-22-3201	5 Pc INKZALL™ Chisel Tip Yellow Highlighter
48-22-3206	5 Pc INKZALL™ Chisel Tip Colored Highlighter

COMFORT GRIP STRAIGHT JAW PLIERS

**REAM
AND PUNCH™**

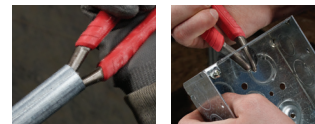

Ream

Punch



Model #	Description	Jaw Capacity	Reaming Capacity
48-22-6306	6" Comfort Grip Straight Jaw Pliers	1"	3/4"
48-22-6310	10" Comfort Grip Straight Jaw Pliers	2"	2"
48-22-6312	12" Comfort Grip Straight Jaw Pliers	2-1/4"	2-3/4"
48-22-6316	16" Comfort Grip Straight Jaw Pliers	4-1/4"	3"
48-22-6320	20" Comfort Grip Straight Jaw Pliers	5-1/2"	3-1/2"
48-22-6330	2 Pc 6" & 10" Comfort Grip Straight Jaw Pliers Set	1" & 2"	3/4" & 2"
48-22-6331	3 Pc Comfort Grip Pliers Set	2"	2"

STRAIGHT JAW PLIERS

**MAXIMUM GRIP.
FORGED STRENGTH.**



Reaming Head

Model #	Description	Jaw Capacity	Reaming Capacity
48-22-6510	10" Straight Jaw Pliers	2"	2"
48-22-6512	12" Straight Jaw Pliers	2-1/4"	2-3/4"

SMOOTH JAW PLIERS

**SMOOTH JAW
PROTECTS SURFACES**



Non-Marring Smooth Jaw for Finish Applications

Model #	Description	Jaw Capacity	Reaming Capacity
48-22-6550	10" Smooth Jaw Pliers	2"	2"
48-22-6552	12" Smooth Jaw Pliers	2-1/4"	2-3/4"

V-JAW PLIERS



Ream

Punch



Model #	Description	Jaw Capacity	Reaming Capacity
48-22-6208	8" Comfort Grip V-Jaw Pliers	1-1/2"	1-1/2"
48-22-6210	10" Comfort Grip V-Jaw Pliers	2"	2"
48-22-6212	12" Comfort Grip V-Jaw Pliers	2-3/4"	2-3/4"

LINEMAN'S PLIERS

**MAXIMUM LEVERAGE.
EASIER CUTS.***



Easily Cuts #2 ACSR
* When compared to other ACSR cutting lineman pliers

Model #	Description
48-22-6100	Comfort Grip High-Leverage Lineman's Pliers with Crimper
48-22-6500	High-Leverage Lineman's Pliers with Crimper
48-22-6502	High-Leverage Lineman's Pliers
48-22-6503	High-Leverage Lineman's Pliers with Thread Cleaner

ANGLED HEAD PLIERS

BETTER ACCESS



Angled Head

Model #	Description
48-22-6128	8" Comfort Grip Angled Head Diagonal Cutting Pliers
48-22-6528	8" Angled Head Diagonal Cutting Pliers

LONG NOSE PLIERS

LONG REACH



2" Gripping Nose



Also Available:
8" Long Nose Pliers
48-22-6501

Model #	Description
48-22-6101	8" Comfort Grip Long Nose Pliers
48-22-6501	8" Long Nose Pliers

DIAGONAL PLIERS

UP TO 2X MORE CUTS IRON-CARBIDE EDGE



Tapered Nose




Also Available:
8" Diagonal Cutting Pliers
48-22-6508

Model #	Description
48-22-6106	6" Comfort Grip Diagonal Cutting Pliers
48-22-6107	7" Comfort Grip Diagonal Cutting Pliers
48-22-6108	8" Comfort Grip Diagonal Cutting Pliers
48-22-6508	8" Diagonal Cutting Pliers

6 IN 1 COMBINATION PLIERS



6IN1

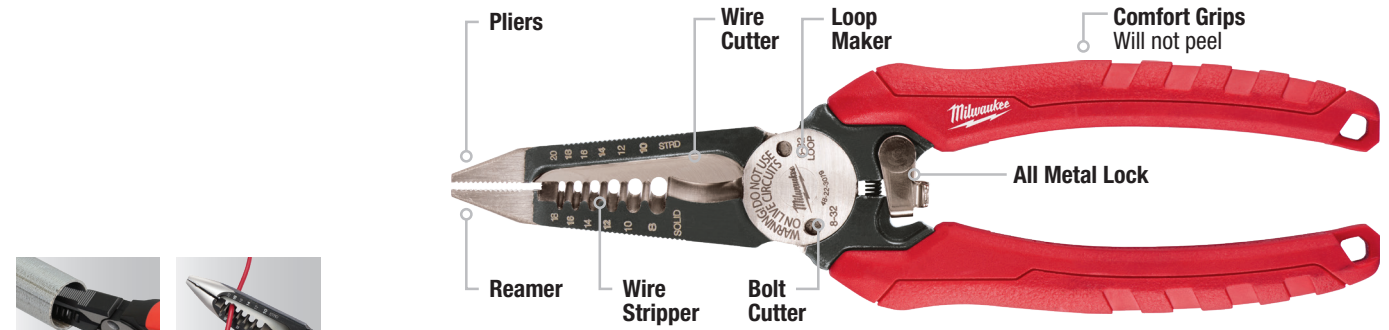

Model #	Description	Wire Stripper
48-22-3079	6in1 Comfort Grip Combination Pliers	8-18 AWG Solid, 10-20 AWG Stranded

MULTI-FUNCTION

FAST, ONE-HANDED OPERATION

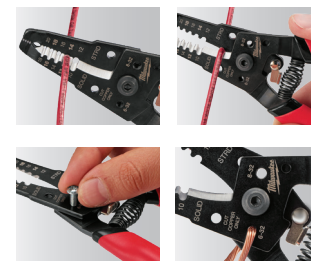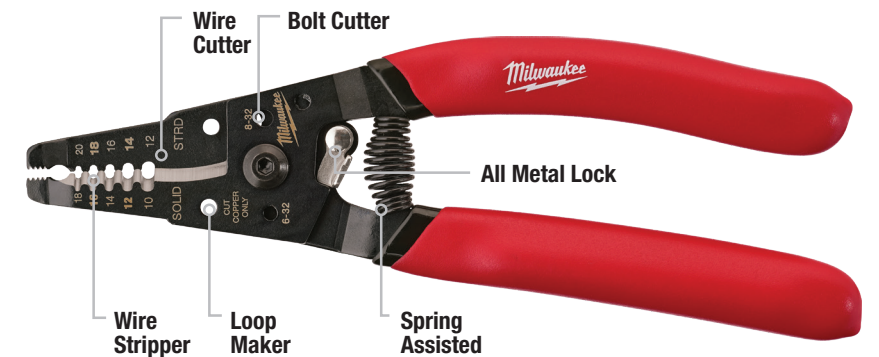

Model #	Description	Wire Stripper
48-22-6109	Wire Stripper	10-18 AWG Solid, 12-20 AWG Stranded
48-22-6579	Multi-Purpose Wire Stripper with Crimper	10-20 AWG Solid, 12-22 AWG Stranded