



FEATURES:

High data accuracy

Quick and intuitive
snap-in installation

Includes auto-detecting Smart
Current Transformers (CTs)

GENERAC

PWRVIEW

Home Energy Monitor
Model: W2HEM

The PWRview W2HEM is a consumption and/or generation meter that combines accuracy, intelligent hardware, and installation ease. Smart CT's are factory calibrated and encoded to enable the meter to automatically configure to the installed CT's.

WHAT'S IN THE BOX



✓ 1x Meter ✓ 2x Current Transformers ✓ 1x Welcome Guide

COMPATIBILITY

The W2HEM energy meter is compatible with most North American, European and Australian residential electrical panels. Universal Current Transformers allow for seamless installation across all panel configurations.

ADDITIONAL FEATURES

- Removes the friction of installations
- Added layer of reliability and data accuracy
- Convenience of Smart CT auto detection

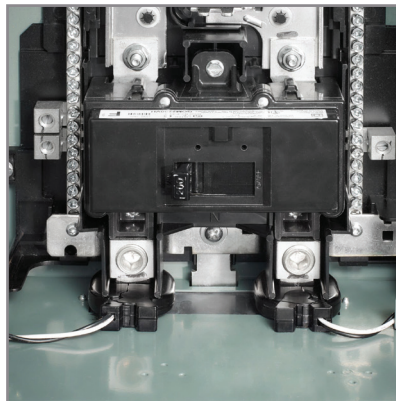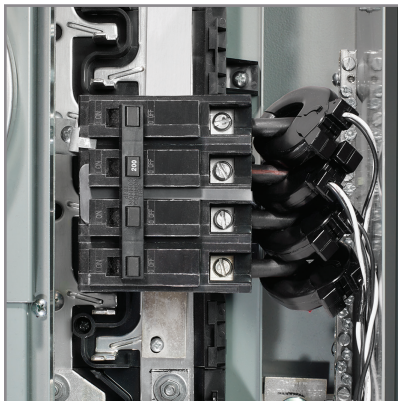

GENERAC

Generac Power Systems, Inc.
S45 W29290 Hwy. 59, Waukesha, WI 53189
www.Generac.com 1-888-GENERAC (1-888-436-3722)

Specifications



METER (W2)

| | | | |
|---------------------------|---|--------------------------|---|
| ACCURACY | ±1% of reading from 2A-264A | BANDWIDTH | < 1GB (monthly) |
| RESOLUTIONS | 1W Power, 1Wh Energy | CURRENT COMPATABILITY | 120/208/240V 50/60 Hz 1/2/3 Phase (Wye only) |
| POWER CONSUMPTION | <5W | POWER SOURCE | 120/208/240V, hardwired |
| MEASUREMENTS | Real Power, Reactive Power, Energy Imported/Exported, RMS Current, RMS Voltage, Line Frequency | METER DIMENSIONS (L,W,H) | 4.9" x 1.9" x 1.0" |
| RADIO STANDARD | Wi-Fi, 802.11b/g/n | OPERATING TEMPERATURE | -20°C to 70°C |
| RADIO OPERATING FREQUENCY | 2.4 GHz | CERTIFICATIONS | UL/CSA 61010-1, FCC, IC, ETSI, AS/NZS |
| RADIO TRANSMIT POWER | +17.5dBm | METER WEIGHT | 0.3 lbs |
| RECEIVE SENSITIVITY | +97dBm | WARRANTY | 1 year |
| WIRED CONNECTIVITY | 1x RS-485 | | |

CURRENT TRANSFORMER (UCT)

| | | | |
|-----------------------|-----------------------------|---------------------------|---------------|
| VOLTAGE | 110-240 VAC | WINDOW SIZE | 0.75" |
| FREQUENCY | 50/60Hz | WIRE LENGTH | 4' |
| MAX PRIMARY CURRENT | 264 A | BUILT-IN PROTECTION DIODE | Yes |
| ACCURACY | ±1% of reading from 2A-264A | WARRANTY | 1 Year |
| CT DIMENSIONS (L,W,H) | 2.26" x 2.03" x 0.47" | OPERATING TEMPERATURE | -20°C to 70°C |

Specifications subject to change without notice.