



# Double Ended Linear

## Double Ended Linear BC100T3Q/CL/1CD

High-quality white light with superior lumen performanceHalogen Double Ended lamps provide bright,white light for work lights and security lighting. Rugged construction for busy work sites. Offered in several lengths to meet most application needs.High lumen output provides light where you need it.


### Product data

General information	
Cap-Base	R7S [ R7s]
Operating Position	Universal [ Universal]
Nominal Lifetime (Nom)	2000 h
Rated Lifetime (Hours)	2000 h
Light technical	
Luminous Flux (Nom)	1750 lm
Correlated Color Temperature (Nom)	2900 K
Luminous Efficacy (rated) (Nom)	17.5 lm/W
Color Rendering Index (Nom)	100
Operating and electrical	
Power (Rated) (Nom)	100.0 W
Lamp Current (Nom)	0.83 A
Starting Time (Nom)	0.0 s
Voltage (Nom)	120 V
Controls and dimming	
Dimmable	Yes

Mechanical and housing	
Bulb Finish	Clear
Cap-Base Information	10
Bulb Shape	T3 [ Diameter: .433 inch/11mm]
Luminaire design requirements	
Bulb Temperature (Max)	900 °C
Pinch Temperature (Max)	350 °C
Product data	
Order product name	Double Ended Linear BC100T3Q/CL/1CD
EAN/UPC - Product	046677116118
Order code	112128
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	924502234590
Net Weight (Piece)	0.008 kg
ILCOS Code	HDG//RS-100-120-R7s-74,9

# Double Ended Linear

## Dimensional drawing

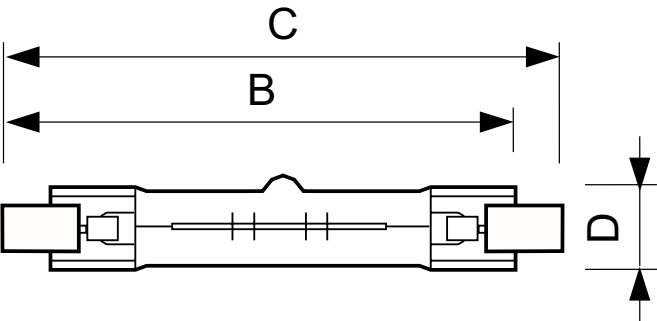

Double Ended Linear BC100T3Q/CL/1CD

Product	D (max)	B (max)	B	B (min)	C (max)
Double Ended Linear BC100T3Q/CL/1CD	12 mm	76.5 mm	74.9 mm	73.3 mm	78.3 mm

