



Hi Intensity

BC-40S11N

Incandescent Hi Intensity light bulbs.


Product data

General information	
Cap-Base	E17 [Intermediate Screw]
Operating Position	Universal [Universal]
Main Application	Showcase
Gas Filling	Gas
Rated Lifetime (Hours)	1500 h
Light technical	
Luminous Flux (Nom)	370 lm
Operating and electrical	
Power (Rated) (Nom)	40 W
Voltage (Nom)	120 V
Mechanical and housing	
Bulb Finish	Clear

Cap-Base Information	Brass [Brass Base]
Filament Shape	CC-2V [Straight V]
Bulb Shape	S11 [S11]
Product data	
Order product name	BC-40S11N
EAN/UPC - Product	067805535168
Order code	595397
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	922746636301
Net Weight (Piece)	0.009 kg

Hi Intensity

Dimensional drawing

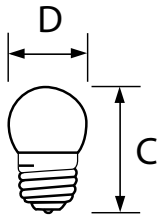

S11
Med.

BC-40S11N

Product

BC-40S11N

