



DuraMax Deco Blunt Tip

BC40ETC/D/LL 6/2PK

Philips DuraMax® Long Life Decorative blunt tip bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. Philips Duramax decorative blunt tip bulbs are available in a variety of shapes, sizes and wattages with clear and frost finishes. The clear bulbs provide decorative sparkle, while the frost bulbs add a soft glow to add a pleasant touch to home decor.

Product data

General information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	Base Down +/- 90 D [Base Down +/- 90 D]
Main Application	Decorative
Gas Filling	Gas
Rated Lifetime (Hours)	2000 h

Light technical	
Luminous Flux (Nom)	266 lm

Operating and electrical	
Power (Rated) (Nom)	40 W
Voltage (Nom)	120 V


Mechanical and housing	
Bulb Finish	Clear

Cap-Base Information	Brass [Brass Base]
Filament Shape	C-7A [Ring]
Bulb Shape	B13 [B13 (B13)]

Product data	
Order product name	BC40ETC/D/LL 6/2PK
EAN/UPC - Product	50046677129267
Order code	129262
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	925169736301
Net Weight (Piece)	0.020 kg

DuraMax Deco Blunt Tip

Dimensional drawing

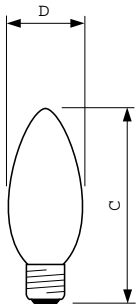

Product

BC40ETC/D/LL 6/2PK

BC40ETC/D/LL 6/2PK

