

LED B11

5.5B11/PER/927-922/CL/G/E12/WGX 1FB T20

Philips LED B11 candles offer energy saving ambiance with the elegant effect of incandescent candles. These designs provides light in an omnidirectional manner, giving lighting designers a long life alternative to standard incandescent sources.

Product data

General information	
Cap-Base	E12 [Candelabra Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	5,5-60W

Light technical	
Color Code	927-922 [CCT of 2700K-2200K]
Luminous Flux (Nom)	500 lm
Color Designation	Warm Glow(WG)
Correlated Color Temperature (Nom)	- K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	5,5 W
Lamp Current (Nom)	60 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s

Power Factor (Nom)	0.75
Voltage (Nom)	120 V

Temperature	
T-Case Maximum (Nom)	60 °C

Controls and dimming	
Dimmable	Yes


Mechanical and housing	
Bulb Finish	Clear
Bulb Shape	B11 [B 35mm]

Approval and application	
Energy Consumption kWh/1000 h	- kWh

Product data	
Order product name	5.5B11/PER/927-922/CL/G/E12/WGX 1FB T20
EAN/UPC - Product	046677549336
Order code	929002204504
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929002204504
Net Weight (Piece)	0.020 kg

LED B11


Dimensional drawing

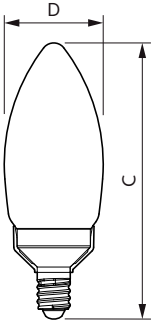


5.5B11/PER/927-922/CL/G/E12/WGX 1FB T20

Product	D	C
5.5B11/PER/927-922/CL/G/E12/WGX 1FB T20	35 mm	100 mm


Photometric data

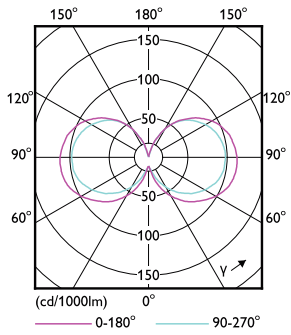

LEDbulb E12 E26 BA11 B11 927 CL-LDD

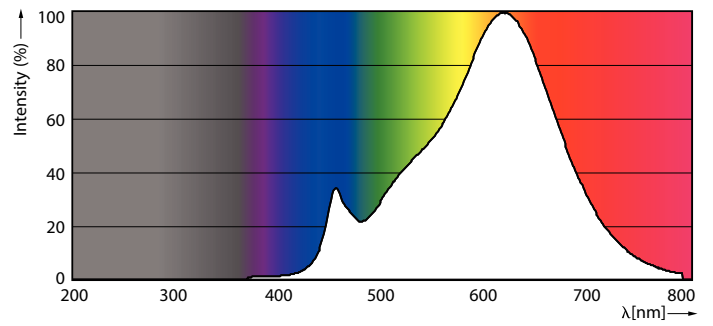

LEDbulb 927 CL-POC

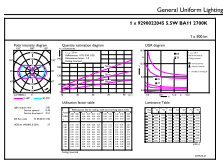

LEDbulb 5.5W E12 B11 927 CL

LED B11

Lifetime



15K LED

15K LMP

