



Optics

Diffuser



Circline



Cloud



Drop Pan


Order code	Description	Finish	Material	Nominal size (in.)	Trim size (in.)	Opening (in.)	Depth (in.)	Case qty
Circline								
35479	CIRC DIFF .075 ACR WH 11x11	White	Acrylic	11	9.88	9.25	2.75	48
35480	CIRC DIFF .075 PLY WH 11x11	White	Polycarbonate	11	9.88	9.25	2.75	48
35483	CIRC MLD DIFF .075 ACR WH 11x11	White	Acrylic	11	9.88	9.25	2.75	48
35481	CIRC DIFF .075 ACR WH 14x14	White	Acrylic	14	12.63	12.00	3.00	36
35482	CIRC DIFF .075 PLY WH 14x14	White	Polycarbonate	14	12.63	12.00	3.00	36
35484	CIRC MLD DIFF .075 ACR WH 14x14	White	Acrylic	14	12.64	12.26	3.00	36
Cloud								
35486	CLOUD DIFFUSER ASS'Y 24"	White	Acrylic	6 x 24	6.00 x 26.75	4.63 x 24.25	4.50	-
35487	CLOUD DIFFUSER ASS'Y 36"	White	Acrylic	6 x 36	6.00 x 38.75	4.63 x 36.25	4.50	-
35488	CLOUD DIFFUSER ASS'Y 48"	White	Acrylic	6 x 48	6.00 x 50.75	4.63 x 48.25	4.50	-
35478	CLOUD DIFF .125 ACR WH 3/4x4	White	Acrylic	9 x 48	11.75 x 75.00	8.50 x 48.75	4.00	-
35634	CLOUD DIFF .125 ACR WH 1x4	White	Acrylic	12 x 48	14.50 x 51.00	12.00 x 48.50	4.00	-
Drop Pan								
35469	DROP PAN DIFF ACR WH 23.75x23.75	White	Acrylic	24 x 24	23.75 x 23.75	21.00 x 21.00	1.50	15
35632	DROP PAN DIFF ACR WH 23.75x47.75	White	Acrylic	24 x 48	23.75 x 47.75	21.00 x 45.31	1.50	15




Flat



Pyramidal

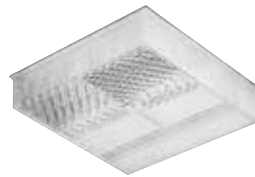

Asymmetrical

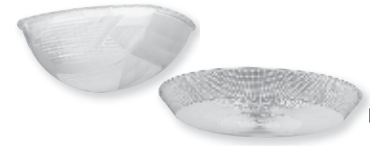

Round

Order code	Description	Colour	Material	Nominal size (in.)	Opening (in.)	Pattern	Depth (in.)	Draft (°)
Flat								
12804	HID FLT DIFF .125 ACR CL K12 1x1	Clear	Acrylic	12 x 12	11.50 x 11.50	K12	2.50	5
35492	HID FLT DIFF .125 ACR CL 2x2	Clear	Acrylic	24 x 24	19.38 x 19.38	Smooth	3.00	5
35638	HID FLT DIFF .125 PLY CL 2x2	Clear	Polycarbonate	24 x 24	19.38 x 19.38	Smooth	3.00	5
Pyramidal								
35640	HID PYR DIFF .125 ACR CL 1.5x1.5	Clear	Acrylic	18 x 18	19.63 x 19.63	-	4.38	15
12899	HID PYR DIFF .200 ACR CL K12 2x2	Clear	Acrylic	22.25 x 22.25	21.50 x 21.50	-	3.63	15
35642	HID PYR DIFF .200 ACR CL 2x2	Clear	Acrylic	24 x 24	23.63 x 23.63	-	3.63	15
Asymmetrical								
35490	HID ASYM DIFF ACR CL 12x12	Clear	Acrylic	12 x 12	11.15 x 11.15	-	2.50	5
57537	HID ASYM DIFF ACR WH K12 12x12	White	Acrylic	12 x 12	11.40 x 11.40	-	2.50	5
35769	HID ASYM DIFF PLY CL 20x20	Clear	Polycarbonate	20 x 20	19.08 x 19.08	-	2.50	5
35491	HID ASYM DIFF ACR CL 20x20	Clear	Acrylic	20 x 20	19.40 x 19.40	-	3.00	5
Round								
57634	HID ROUND DIFF ACR CL 14X12	Clear	Acrylic	14 x 12	-	-	5.50	-
57914	HID ROUND DIFF GLS CL 14X12	Clear	Glass	14 x 12	-	-	5.50	-

Globe



Order code	Description	Colour	Material	Globe diameter (in.)	Min. hole opening (in.)	Neck diameter (in.)	Fitter model	Maximum wattage (W)			Case qty (master)
								INC	CFL	HID	
Without Neck											
35535	GLOBE 8" ACR CL 5.25" HOLE	Clear	Acrylic	8	5.25	-	N/A	75	PL5 - PL13	50	27
35500	GLOBE 10" ACR WH 4" HOLE	White	Acrylic	10	4.00	-	N/A	100	PL5 - PL13	50	14
35499	GLOBE 10" ACR WH 5.25" HOLE	White	Acrylic	10	5.25	-	N/A	100	PL5 - PL13	50	14
35503	GLOBE 12" ACR WH 5.25" HOLE	White	Acrylic	12	5.25	-	B-4	150	PL5 - PL13	50	9
35522	GLOBE 12" ACR CL 5.25" HOLE	Clear	Acrylic	12	5.25	-	B-4	150	PL5 - PL13	50	9
35504	GLOBE 12" ACR WH 6" HOLE	White	Acrylic	12	6.00	-	B-4	150	PL5 - PL13	50	9
35507	GLOBE 14" ACR WH 5.25" HOLE	White	Acrylic	14	5.25	-	B-4	150	PL5 - PL13	75	1
35525	GLOBE 14" ACR CL 5.25" HOLE	Clear	Acrylic	14	5.25	-	B-4	150	PL5 - PL13	75	1
35561	GLOBE 14" ACR BZ 5.25" HOLE	Bronze	Acrylic	14	5.25	-	B-1	150	PL5 - PL13	75	1
35508	GLOBE 14" ACR WH 6" HOLE	White	Acrylic	14	6.00	-	B-1	150	PL5 - PL13	75	1
35510	GLOBE 16" ACR WH 5.25" HOLE	White	Acrylic	16	5.25	-	B-4	200	PL5 - PL13	100	1
35527	GLOBE 16" ACR CL 5.25" HOLE	Clear	Acrylic	16	5.25	-	B-4	200	PL5 - PL13	100	1
35656	GLOBE 16" ACR BZ 5.25" HOLE	Bronze	Acrylic	16	5.25	-	B-4	200	PL5 - PL13	100	1
35512	GLOBE 18" ACR WH 5.25" HOLE	White	Acrylic	18	5.25	-	B-4	200	PL5 - PL13	175	1
35530	GLOBE 18" ACR CL 5.25" HOLE	Clear	Acrylic	18	5.25	-	B-4	200	PL5 - PL13	175	1
35538	GLOBE 18" ACR BZ 5.25" HOLE	Bronze	Acrylic	18	5.25	-	B-4	200	PL5 - PL13	175	1
35646	GLOBE 18" ACR WH 6" HOLE	White	Acrylic	18	6.00	-	B-4	200	PL5 - PL13	175	1
57637	GLOBE 18" ACR CL 6" HOLE	Clear	Acrylic	18	6.00	-	B-4	200	PL5 - PL13	175	1
58120	GLOBE 18" ACR CL 8.63" HOLE	Clear	Acrylic	18	8.63	-	B-6	200	PL5 - PL13	175	1
35647	GLOBE 20" ACR WH 7.25" HOLE	White	Acrylic	20	7.25	-	B-6	300	PL5 - PL13	175	1
35531	GLOBE 20" ACR CL 7.25" HOLE	Clear	Acrylic	20	7.25	-	B-6	300	PL5 - PL13	175	1
35564	GLOBE 20" ACR WH 8.5" HOLE	White	Acrylic	20	8.50	-	B-6	300	PL5 - PL13	175	1
35648	GLOBE 22" ACR WH 8.63" HOLE	White	Acrylic	22	8.63	-	B-7	300	PL5 - PL13	175	1
35532	GLOBE 22" ACR CL 8.63" HOLE	Clear	Acrylic	22	8.63	-	B-7	300	PL5 - PL13	175	1
35515	GLOBE 24" ACR WH 8.63" HOLE	White	Acrylic	24	8.63	-	B-7	300	PL5 - PL13	200	1
12829	GLOBE 10" POLY WH 5.25" HOLE	White	Polycarbonate	10	5.25	-	B-4	150	PL5 - PL13	70	14
35540	GLOBE 12" POLY WH 5.25" HOLE	White	Polycarbonate	12	5.25	-	B-1	200	PL5 - PL13	100	8
16851	GLOBE 14" POLY CL 5.25" HOLE	Clear	Polycarbonate	14	5.25	-	B-4	200	PL5 - PL13	100	1
35539	GLOBE 16" POLY CL 5.25" HOLE	Clear	Polycarbonate	16	5.25	-	B-4	300	PL5 - PL13	175	1
58276	GLOBE 20" POLY BZ 7" HOLE	Bronze	Polycarbonate	20	7.00	-	B-6	400	PL5 - PL13	250	1
58897	GLOBE 22" POLY CL 8.63" HOLE	Clear	Polycarbonate	22	8.63	-	B-7	500	PL5 - PL13	250	1
With Neck											
35519	GLOBE 8" ACR WH 4" NECK	White	Acrylic	8	-	4.00	N/A	75	PL5 - PL13	50	27
35536	GLOBE 8" ACR CL 4" NECK	Clear	Acrylic	8	-	4.00	N/A	75	PL5 - PL13	50	27
35501	GLOBE 10" ACR WH 4" NECK	White	Acrylic	10	-	4.00	N/A	100	PL5 - PL13	50	14
35506	GLOBE 11" ACR WH 4" NECK	White	Acrylic	11	-	4.00	B-2	100	PL5 - PL13	50	9
35505	GLOBE 12" ACR WH 5.75" NECK	White	Acrylic	12	-	5.75	B-1	150	PL5 - PL13	50	8
35509	GLOBE 14" ACR WH 5.75" NECK	White	Acrylic	14	-	5.75	B-1	150	PL5 - PL13	75	1
35526	GLOBE 14" ACR CL 5.75" NECK	Clear	Acrylic	14	-	5.75	B-1	150	PL5 - PL13	75	1
35537	GLOBE 14" ACR BZ 5.75" NECK	Bronze	Acrylic	14	-	5.75	B-4	150	PL5 - PL13	75	1
12825	GLOBE 16" ACR BZ 5.75" NECK	Bronze	Acrylic	16	-	5.75	B-1	200	PL5 - PL13	100	1
35511	GLOBE 16" ACR WH 5.75" NECK	White	Acrylic	16	-	5.75	B-1	200	PL5 - PL13	100	1
35529	GLOBE 16" ACR CL 5.75" NECK	Clear	Acrylic	16	-	5.75	B-1	200	PL5 - PL13	100	1
57601	GLOBE 18" ACR CL 5.25" NECK	Clear	Acrylic	18	-	5.25	B-4	200	PL5 - PL13	175	1
57241	GLOBE 20" ACR WH 7.5" NECK	White	Acrylic	20	-	7.50	B-6	300	PL5 - PL13	175	1



Order code	Description	Colour	Material	Globe diameter (in.)	Min. hole opening (in.)	Neck diameter (in.)	Filter model	Maximum wattage (W)			Case qty (master)
								INC	CFL	HID	

Specialty

12853	GLOBE CYL 5.5" POLY WH 3.25" THREAD NECK	White	Polycarbonate	5.5	-	3.25	-	60	PL5 - PL13	35	50
35516	GLOBE 6" ACR WH 3.25" THREAD NECK	White	Acrylic	6.0	-	3.25	-	60	PL5 - PL13	35	50
35517	GLOBE 6" ACR WH 3.25" LIP NECK	White	Acrylic	6.0	-	3.25	-	60	PL5 - PL13	35	50




Order code	Description	Colour	Material	Type	Maximum wattage (W)	Wiring	Case qty (master)
------------	-------------	--------	----------	------	---------------------	--------	-------------------

Post Top Fitter

35545	POST TOP FITTER POLY BL 3" 4KV	Black	Polycarbonate	Solid Flange	60	Snap-in 4 KV pulse rated	50
35547	POST TOP FITTER POLY WH 3" 4KV	White	Polycarbonate	Solid Flange	60	Snap-in 4 KV pulse rated	50
35544	POST TOP FITTER POLY BL 3" PL13	Black	Polycarbonate	Solid Flange	13	PL13 including ballast	50
35546	POST TOP FITTER B-4 HARDWARE KIT	-	-	-	-	-	1

 Lens



Flat Sheet



Cracked Ice

Order code	Description	Colour	Material	Nominal size (ft)	Actual size (in.)	Thickness (in.)
------------	-------------	--------	----------	-------------------	-------------------	-----------------


Flat Sheet

12405	FLAT SHEET LENS 0.060 ACR OP 1x4	Opal	Acrylic	1 x 4	11-3/4 x 47-3/4	0.060
12406	FLAT SHEET LENS 0.080 ACR WH 1x4 NOM	White	Acrylic	1 x 4	11-3/4 x 47-3/4	0.080
35573	FLAT SHEET LENS 0.125 ACR OP 1x4	Opal	Acrylic	1 x 4	11-3/4 x 47-3/4	0.125
35023	FLAT SHEET LENS 0.060 ACR OP 2x2	Opal	Acrylic	2 x 2	23-3/4 x 23-3/4	0.060
35022	FLAT SHEET LENS 0.080 ACR OP 2x2	Opal	Acrylic	2 x 2	23-3/4 x 23-3/4	0.080
59092	FLAT SHEET LENS 0.060 ACR OP 2x4	Opal	Acrylic	2 x 4	23-3/4 x 47-3/4	0.060
35024	FLAT SHEET LENS 0.080 ACR OP 2x4	Opal	Acrylic	2 x 4	23-3/4 x 47-3/4	0.080
12407	FLAT SHEET LENS 0.125 ACR CL 2x4	Clear	Acrylic	2 x 4	23-3/4 x 47-3/4	0.125
59093	FLAT SHEET LENS 0.125 ACR OP 2x4	Opal	Acrylic	2 x 4	23-3/4 x 47-3/4	0.125
59078	FLAT SHEET LENS 0.020 ACR WH 3x5	White	Acrylic	3 x 5	36 x 60	0.020
12882	FLAT SHEET LENS 0.060 POLY CL 4x8	Clear	Polycarbonate	4 x 8	48 x 96	0.060
59073	FLAT SHEET LENS 0.118 ACR CL 4x8	Clear	Acrylic	4 x 8	48 x 96	0.118
12881	FLAT SHEET LENS 0.125 ACR BL 4x8	Blue	Acrylic	4 x 8	48 x 96	0.125
59097	FLAT SHEET LENS 0.125 ACR WH 4x8	White	Acrylic	4 x 8	48 x 96	0.125
59074	FLAT SHEET LENS 0.125 POLY CL 4x8	Clear	Polycarbonate	4 x 8	48 x 96	0.125
59069	FLAT SHEET LENS 0.177 ACR CL 4x8	Clear	Acrylic	4 x 8	48 x 96	0.177

Cracked Ice

12404	CRACKED ICE LENS 0.060 STY CL 1x4	Clear	Styrene	1 x 4	11-3/4 x 47-3/4	0.060
59088	CRACKED ICE LENS 0.060 STY CL 2x4	Clear	Styrene	2 x 4	23-3/4 x 47-3/4	0.060
59089	CRACKED ICE LENS 0.060 STY OP 2x4	Opal	Styrene	2 x 4	23-3/4 x 47-3/4	0.060



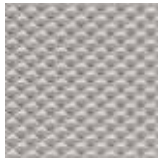


K12



K15



K19

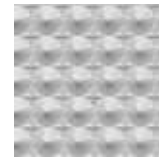

K23

Order code	Description	Colour	Material	Nominal size (ft)	Actual size (in.)	Thickness (in.)
K12 Prismatic						
60111	K12 LENS 0.095 ACR CL 1.25x4	Clear	Acrylic	1.25 x 4	14 3/8 x 47 1/4	0.095
12889	K12 LENS 0.100 ACR CL 1x4 NOM	Clear	Acrylic	1 x 4	11-3/4 x 47-3/4	0.100
35139	K12 LENS 0.100 ACR CL 1x4 FULL	Clear	Acrylic	1 x 4	12 x 48	0.100
35570	K12 LENS 0.110 ACR OP 1x4	Opal	Acrylic	1 x 4	11-3/4 x 47-3/4	0.110
11254	K12 LENS 0.110 ACR CL 1x4 FULL	Clear	Acrylic	1 x 4	12 x 48	0.110
11255	K12 LENS 0.125 ACR CL 1x4 FULL	Clear	Acrylic	1 x 4	12 x 48	0.125
58173	K12 LENS 0.100 ACR CL 2x2 NOM	Clear	Acrylic	2 x 2	23-3/4 x 23-3/4	0.100
58174	K12 LENS 0.100 ACR CL 2x2 FULL	Clear	Acrylic	2 x 2	24 x 24	0.100
35005	K12 LENS 0.110 ACR CL 2x2 NOM	Clear	Acrylic	2 x 2	23-3/4 x 23-3/4	0.110
35571	K12 LENS 0.110 ACR OP 2x2	Opal	Acrylic	2 x 2	23-3/4 x 23-3/4	0.110
35222	K12 LENS 0.110 ACR CL 2x2 FULL	Clear	Acrylic	2 x 2	24 x 24	0.110
35006	K12 LENS 0.125 ACR CL 2x2	Clear	Acrylic	2 x 2	23-3/4 x 23-3/4	0.125
64630	K12 LENS 0.100 ACR CL 2x4 FULL	Clear	Acrylic	2 x 4	24 x 48	0.100
64628	K12 LENS 0.110 ACR CL 2x4 NOM	Clear	Acrylic	2 x 4	23-3/4 x 47-3/4	0.110
59087	K12 LENS 0.110 ACR OP 2x4	Opal	Acrylic	2 x 4	23-3/4 x 47-3/4	0.110
64629	K12 LENS 0.110 ACR CL 2x4 FULL	Clear	Acrylic	2 x 4	24 x 48	0.110
64631	K12 LENS 0.125 ACR CL 2x4 NOM	Clear	Acrylic	2 x 4	23-3/4 x 47-3/4	0.125
59086	K12 LENS 0.125 POLY CL 2x4	Clear	Polycarbonate	2 x 4	23-3/4 x 47-3/4	0.125
64632	K12 LENS 0.125 ACR CL 2x4 FULL	Clear	Acrylic	2 x 4	24 x 48	0.125
12395	K12 LENS 0.125 ACR CL 3x3	Clear	Acrylic	3 x 3	35-3/4 x 35-3/4	0.125
61938	K12 LENS 0.110 ACR CL 3.5x4	Clear	Acrylic	3.5 x 4	44 x 47 1/4	0.110
12398	K12 LENS 0.125 ACR CL 4x4	Clear	Acrylic	4 x 4	47-3/4 x 47-3/4	0.125
59070	K12 LENS 0.125 ACR CL 4x8	Clear	Acrylic	4 x 8	48 x 96	0.125
K15 Prismatic						
35579	K15 LENS 0.200 ACR CL 1x4	Clear	Acrylic	1 x 4	11-3/4 x 47-3/4	0.200
35580	K15 LENS 0.200 ACR CL 2x2	Clear	Acrylic	2 x 2	23-3/4 x 23-3/4	0.200
59091	K15 LENS 0.200 ACR CL 2x4	Clear	Acrylic	2 x 4	23-3/4 x 47-3/4	0.200
59076	K15 LENS 0.200 ACR CL 4x4	Clear	Acrylic	4 x 4	50 x 51	0.200
K19 Prismatic						
35029	K19 LENS 0.160 ACR CL 1x4	Clear	Acrylic	1 x 4	11-3/4 x 47-3/4	0.160
35581	K19 LENS 0.160 ACR CL 2x2	Clear	Acrylic	2 x 2	23-3/4 x 23-3/4	0.160
59094	K19 LENS 0.160 ACR CL 2x4	Clear	Acrylic	2 x 4	23-3/4 x 47-3/4	0.160
K23 Prismatic						
59125	K23 LENS 0.125 ACR CL 2x4	Clear	Acrylic	2 x 4	23-3/4 x 47-3/4	0.125

Louver



Paracube 1



Paracube 2



Paracube 3


Order code	Description	Colour	Material	Nominal size (ft)	Actual size (in.)	Cell size (in.)
Paracube 1						
35413	PARACUBE 1 ACR SLV 2x4 FLG	Silver	Acrylic	2.0 x 4.0	22-1/2 x 46-1/2	1/2 x 1/2 x 3/8
10395	PARACUBE 1 STY SLV 2x4 FLG	Silver	Styrene	2.0 x 4.0	22-1/2 x 46-1/2	1/2 x 1/2 x 3/8
12751	PARACUBE 1 ACR SLV 2x4 TRM	Silver	Acrylic	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 3/8
59105	PARACUBE 1 ACR SLV 2x4 GRD	Silver	Acrylic	2.0 x 4.0	23-3/4 x 47-3/4	5/8 x 5/8 x 3/8
12752	PARACUBE 1 STY SLV 2x4 TRM	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 3/8
59064	PARACUBE 1 STY SLV 2x4 GRD	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 3/8
59106	PARACUBE 1 STY GLD 2x4 GRD	Gold	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 3/8
35602	PARACUBE 1 ACR SLV 2x2 FLG	Silver	Acrylic	2.0 x 2.0	22-1/2 x 22-1/2	1/2 x 1/2 x 3/8
35410	PARACUBE 1 STY SLV 2x2 FLG	Silver	Styrene	2.0 x 2.0	22-1/2 x 22-1/2	1/2 x 1/2 x 3/8
35409	PARACUBE 1 ACR SLV 2x2 GRD	Silver	Acrylic	2.0 x 2.0	23-3/4 x 23-3/4	1/2 x 1/2 x 3/8
12748	PARACUBE 1 STY SLV 2x2 TRM	Silver	Styrene	2.0 x 2.0	23-3/4 x 23-3/4	1/2 x 1/2 x 3/8
35403	PARACUBE 1 ACR SLV 1x4 FLG	Silver	Acrylic	1.0 x 4.0	10-1/2 x 46-1/2	1/2 x 1/2 x 3/8
35406	PARACUBE 1 STY SLV 1x4 FLG	Silver	Styrene	1.0 x 4.0	10-1/2 x 46-1/2	1/2 x 1/2 x 3/8
12743	PARACUBE 1 ACR SLV 1x4 TRM	Silver	Acrylic	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 3/8
35404	PARACUBE 1 ACR SLV 1x4 GRD	Silver	Acrylic	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 3/8
35600	PARACUBE 1 ACR GLD 1x4 GRD	Gold	Acrylic	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 3/8
10394	PARACUBE 1 STY SLV 1x4 GRD	Silver	Styrene	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 3/8
12744	PARACUBE 1 STY SLV 1x4 TRM	Silver	Styrene	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 3/8
Paracube 2						
35430	PARACUBE 2 STY SLV 2x4 FLG	Silver	Styrene	2.0 x 4.0	22-1/2 x 46-1/2	1-1/2 x 1-1/2 x 1
12758	PARACUBE 2 ACR SLV 2x4 TRM	Silver	Acrylic	2.0 x 4.0	23-3/4 x 47-3/4	1-1/2 x 1-1/2 x 1
59103	PARACUBE 2 ACR SLV 2x4 GRD	Silver	Acrylic	2.0 x 4.0	23-3/4 x 47-3/4	1-1/2 x 1-1/2 x 1
12759	PARACUBE 2 STY SLV 2x4 TRM	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1-1/2 x 1-1/2 x 1
59104	PARACUBE 2 STY SLV 2x4 GRD	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1-1/2 x 1-1/2 x 1
35426	PARACUBE 2 STY SLV 2x2 FLG	Silver	Styrene	2.0 x 2.0	22-1/2 x 22-1/2	1-1/2 x 1-1/2 x 1
36000	PARACUBE 2 ACR SLV 2x2 GRD	Silver	Acrylic	2.0 x 2.0	23-3/4 x 23-3/4	1-1/2 x 1-1/2 x 1
57153	PARACUBE 2 STY SLV 2x2 GRD	Silver	Styrene	2.0 x 2.0	23-3/4 x 23-3/4	1-1/2 x 1-1/2 x 1
12755	PARACUBE 2 ACR SLV 1x4 FLG ESP	Silver	Acrylic	1.0 x 4.0	10-1/2 x 46-1/2	1-1/2 x 1-1/2 x 1
12894	PARACUBE 2 STY SLV 1x4 TRM	Silver	Styrene	1.0 x 4.0	10-1/2 x 46-1/2	1-1/2 x 1-1/2 x 1
35424	PARACUBE 2 STY SLV 1x4 FLG	Silver	Styrene	1.0 x 4.0	10-1/2 x 46-1/2	1-1/2 x 1-1/2 x 1
35423	PARACUBE 2 ACR SLV 1x4 GRD	Silver	Acrylic	1.0 x 4.0	11-3/4 x 47-3/4	1-1/2 x 1-1/2 x 1
35606	PARACUBE 2 STY SLV 1x4 GRD	Silver	Styrene	1.0 x 4.0	11-3/4 x 47-3/4	1-1/2 x 1-1/2 x 1
Paracube 3						
59109	PARACUBE 3 STY SLV 2x4 GRD	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	3 x 3 x 1-1/2
35434	PARACUBE 3 STY SLV 2x2 FLG	Silver	Styrene	2.0 x 2.0	22-1/2 x 22-1/2	3 x 3 x 1-1/2



Paracube 5




Decorative Louver

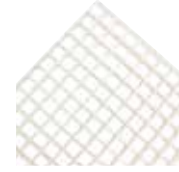

Eggcrate

Order code	Description	Colour	Material	Nominal size (ft)	Actual size (in.)	Cell size (in.)
Paracube 5						
35495	PARACUBE 5 STY SLV 2x4 FLG	Silver	Styrene	2.0 x 4.0	22-1/2 x 46-1/2	3/4 x 3/4 x 3/8
35766	PARACUBE 5 ACR SLV 2x4 TRM	Silver	Acrylic	2.0 x 4.0	23-3/4 x 47-3/4	3/4 x 3/4 x 3/8
59130	PARACUBE 5 ACR SLV 2x4 GRD	Silver	Acrylic	2.0 x 4.0	23-3/4 x 47-3/4	3/4 x 3/4 x 3/8
12811	PARACUBE 5 STY SLV 2x4 TRM	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	3/4 x 3/4 x 3/8
59108	PARACUBE 5 STY SLV 2x4 GRD	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	3/4 x 3/4 x 3/8
12808	PARACUBE 5 ACR SLV 2x2 GRD	Silver	Acrylic	2.0 x 2.0	23-3/4 x 23-3/4	3/4 x 3/4 x 3/8
12810	PARACUBE 5 STY SLV 2x2 GRD	Silver	Styrene	2.0 x 2.0	23-3/4 x 23-3/4	3/4 x 3/4 x 3/8
35758	PARACUBE 5 ACR SLV 1x4 TRM	Silver	Acrylic	1.0 x 4.0	11-3/4 x 47-3/4	3/4 x 3/4 x 3/8
35760	PARACUBE 5 ACR SLV 1x4 GRD	Silver	Acrylic	1.0 x 4.0	11-3/4 x 47-3/4	3/4 x 3/4 x 3/8
35789	PARACUBE 5 STY SLV 1x4 GRD	Silver	Styrene	1.0 x 4.0	11-3/4 x 47-3/4	3/4 x 3/4 x 3/8
Decorative Louver						
59126	HEXALITE STY SLV 2x4 GRD 1/2x1/2x1/2	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 1/2
Eggcrate						
35443	EGGCRATE ACR WH 1x4 1/2x1/2x1/2	White	Acrylic	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 1/2
35628	EGGCRATE STY BL 1x4 1/2x1/2x3/8	Black	Styrene	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 3/8
35449	EGGCRATE STY WH 1x4 1/2x1/2x3/8	White	Styrene	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 3/8
35444	EGGCRATE STY WH 1x4 1/2x1/2x1/2	White	Styrene	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 1/2
35629	EGGCRATE STY WH 2x2 1/2x1/2x3/8	White	Styrene	2.0 x 2.0	23-3/4 x 23-3/4	1/2 x 1/2 x 3/8
35627	EGGCRATE ACR WH 2x2 1/2x1/2x1/2	White	Acrylic	2.0 x 2.0	23-3/4 x 23-3/4	1/2 x 1/2 x 1/2
59120	EGGCRATE STY BL 2x4 1/2x1/2x3/8	Black	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 3/8
59112	EGGCRATE STY SLV 2x4 1/2x1/2x3/8	Silver	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 3/8
59113	EGGCRATE STY WH 2x4 1/2x1/2x3/8	White	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 3/8
59115	EGGCRATE ACR WH 2x4 1/2x1/2x1/2	White	Acrylic	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 1/2
59116	EGGCRATE STY WH 2x4 1/2x1/2x1/2	White	Styrene	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 1/2
35437	EGGCRATE ALM ML 1x4 1/2x1/2x1/2	Mill	Aluminum	1.0 x 4.0	11-3/4 x 47-3/4	1/2 x 1/2 x 1/2
12760	EGGCRATE ALM ML 2x2 1/2x1/2x1/2	Mill	Aluminum	2.0 x 2.0	23-3/4 x 23-3/4	1/2 x 1/2 x 1/2
59081	EGGCRATE ALM BL 2x4 1/2x1/2x1/2	Black	Aluminum	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 1/2
59110	EGGCRATE ALM ML 2x4 1/2x1/2x1/2	Mill	Aluminum	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 1/2
59111	EGGCRATE ALM WH 2x4 1/2x1/2x1/2	White	Aluminum	2.0 x 4.0	23-3/4 x 47-3/4	1/2 x 1/2 x 1/2
59117	EGGCRATE ALM ML 2x4 1x1x1	Mill	Aluminum	2.0 x 4.0	23-3/4 x 47-3/4	1 x 1 x 1
59101	EGGCRATE ALM WH 2x5 1x1x1	White	Aluminum	2.5 x 5.0	29-3/4 x 59-3/4	1 x 1 x 1
59099	EGGCRATE ALM ML 2x5 1/2x1/2x1/2	Mill	Aluminum	2.5 x 5.0	29-3/4 x 59-3/4	1/2 x 1/2 x 1/2

Strip Conversion Kit

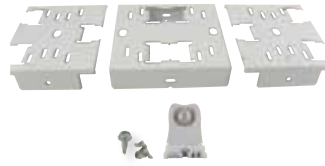

Bracket Kit



Strip Kit

Order code	Description	Colour	Material	Nominal size (in.)	Actual width (in.)
Strip Conversion Kit					
58166	8' WHT STRIP CONVERSION KIT (1L TO 2L)	White	Steel	4 x 96	4.3125
58167	8' WHT STRIP CONVERSION KIT (2L TO 4L)	White	Steel	4 x 96	4.3125
59266	8' WHT STRIP CONVSN KIT (2L TO 4L) INDIV	White	Aluminum	4 x 96	4.3125
58863	4' WHT STRIP CONVERSION KIT (2L TO 1L)	White	Aluminum	4 x 48	4.3125
58906	8' TANDEM CONVERSION BRACKET KIT (2L)	White	Aluminum	-	-
59607	8' TANDEM CONVERSION BRACKET KIT (1L)	White	Aluminum	-	-




8' Strip Kit

Order code	Description	Colour	Material	Size (in.)	Starting method	Line voltage (V)	System watts (W) F32T8	System watts (W) F28T8ES	Ballast factor
Strip Conversion Kit									
61090	8' WHT STRIP KIT WITH E432T8IS347/L	White	Aluminum	4.5 x 96	Instant start	347	92	84	0.77
61091	8' WHT STRIP KIT WITH E232T8IS120/L	White	Aluminum	4.5 x 96	Instant start	120	48	42	0.77
61092	8' WHT STRIP KIT WITH E232T8IS347/L	White	Aluminum	4.5 x 96	Instant start	347	50	42	0.77

All conversion kits include ballast covers, socket plates, sockets, and hardware.
 All bracket kits include, socket plates, sockets, and hardware only.
 4' kit only includes one ballast cover.
 All conversion kits include an 8' ballast cover, ballast, sockets, and luminaire disconnect.



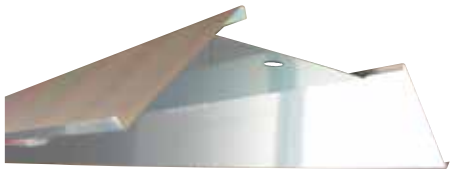

Strip Reflector Kit



Urbanus



Troffer Lamp 1



Troffer Lamp 2



Pegasus



Retropak Frame

Order code	Description	Colour	Material	Nominal size (in.)
Strip Reflector Kit				
58957	8' SLV STRIP REFLECTOR KIT (1L TO 2L)	Silver	Aluminum	4 x 96
58958	8' WHT STRIP REFLECTOR KIT (1L TO 2L)	White	Aluminum	4 x 96
58960	4' WHT STRIP REFLECTOR KIT (2L TO 1L)	White	Aluminum	4 x 48
58961	4' SLV STRIP REFLECTOR KIT (2L TO 1L)	Silver	Aluminum	4 x 48
58895	8' WHT STRIP REFLECTOR KIT (2L TO 4L)	White	Aluminum	4 x 96
58896	8' SLV STRIP REFLECTOR KIT (2L TO 4L)	Silver	Aluminum	4 x 96
Urbanus				
12786	4' REFL WHT W/ PERF BASKET	White	Aluminum	24 x 48
12787	8' REFL WHT W/ PERF BASKET	White	Aluminum	24 x 96
Fluorescent Troffer Retrofit Kit				
58753	4' WHT TROFFER KIT (1' x 4' - 2L TO 1L)	White	Aluminum	12 x 48
59223	4' SLV TROFFER KIT (1' x 4' - 2L TO 1L)	Silver	Aluminum	12 x 48
57933	2' WHT TROFFER KIT (2' x 2' - 4L TO 2L)	White	Aluminum	24 x 24
12788	2' SLV TROFFER KIT (2' x 2' - 4L TO 2L)	Silver	Aluminum	24 x 24
57932	4' WHT TROFFER KIT (2' x 4' - 4L TO 2L)	White	Aluminum	24 x 48
12789	4' SLV TROFFER KIT (2' x 4' - 4L TO 2L)	Silver	Aluminum	24 x 48
Pegasus				
12863	4' REFL WHT DIR/INDIR W/ PERF BASKET	Silver	Aluminum	14 x 48
Retropak Frame				
35457	RETRO PAK FRAME 1x4 WH	White	Aluminum	12 x 48
35458	RETRO PAK FRAME 2x4 WH	White	Aluminum	24 x 48

All reflector kits include reflectors, socket plates, sockets, and hardware.


Tube Guard



Order code	Description	Colour	Lamp shape	Lamp type	Tube length (in.)	Overall diameter (in.)	UV filtering (nm)	Case qty (master)
T5								
57142 ¹	TGF28T5/44.56" CLEAR	Clear	T5	F28	44.56	0.75	370	96
T8								
35101	TGF15T8/16.38" CLEAR	Clear	T8	F15	16.38	1.24	370	24
35138	TGF17T8/22.44" CLEAR	Clear	T8	F17	22.44	1.24	370	24
12381	TGF25T8/34.00" CLEAR	Clear	T8	F25	34.00	1.24	370	24
12380	TGF25T8/34.44" CLEAR	Clear	T8	F25	34.44	1.24	370	24
35102	TGF30T8/34.38" CLEAR	Clear	T8	F30	34.38	1.24	370	24
12375	TGF32T8/46.00" CLEAR W/O CAP	Clear	T8	F32	46.00	1.24	370	24
35103	TGF32T8/46.44" CLEAR	Clear	T8	F32	46.44	1.24	370	24
35104	TGF32T8/46.44" AMBER	Amber	T8	F32	46.44	1.24	370	24
35108	TGF32T8/46.44" RED	Red	T8	F32	46.44	1.24	370	24
35105	TGF32T8/46.44" BLUE	Blue	T8	F32	46.44	1.24	370	24
35106	TGF32T8/46.44" GREEN	Green	T8	F32	46.44	1.24	370	24
35107	TGF32T8/46.44" PINK	Pink	T8	F32	46.44	1.24	370	24
35109	TGF32T8/46.44" YELLOW	Yellow	T8	F32	46.44	1.24	370	24
35110	TGF96T8/92.44" CLEAR	Clear	T8	F96	92.44	1.24	370	24
T12								
35111	TGF20T12/22.25" CLEAR	Clear	T12	F20	22.25	1.65	370	48
35112	TGF30T12/34.25" CLEAR	Clear	T12	F30	34.25	1.65	370	24
35113	TGF40T12/46.25" CLEAR	Clear	T12	F40	46.25	1.65	370	24
35100	TGF40T12/46.25" YELLOW	Yellow	T12	F40	46.25	1.65	370	24
35115	TGF40T12/46.25" BLUE	Blue	T12	F40	46.25	1.65	370	24
35116	TGF40T12/46.25" GREEN	Green	T12	F40	46.25	1.65	370	24
35117	TGF40T12/46.25" PINK	Pink	T12	F40	46.25	1.65	370	24
35119	TGF40T12/46.25" RED	Red	T12	F40	46.25	1.65	370	24
35121	TGF60T12/56.25" CLEAR	Clear	T12	F60	56.25	1.65	370	24
35122	TGF72T12/68.25" CLEAR	Clear	T12	F72	68.25	1.65	370	24
35124	TGF96T12/92.25" AMBER	Amber	T12	F96	92.25	1.65	370	24
35126	TGF96T12/92.25" GREEN	Green	T12	F96	92.25	1.65	370	24
35127	TGF96T12/92.25" PINK	Pink	T12	F96	92.25	1.65	370	24
35128	TGF96T12/92.25" RED	Red	T12	F96	92.25	1.65	370	24
35129	TGF96T12/92.25" YELLOW	Yellow	T12	F96	92.25	1.65	370	24
35123	TGF96T12/92.25" CLEAR	Clear	T12	F96	92.25	1.65	370	24
35125	TGF96T12/92.25" BLUE	Blue	T12	F96	92.25	1.65	370	24
UV Filtering								
12377	TGF40T8/UV/46.00" CLEAR W/O CAP	Clear	T8	F40	46.00	1.24	395	24
35132	TGF32T8/UV/46.44" CLEAR	Clear	T8	F32	46.44	1.24	395	24
35131	TGF40T12/UV/46.25" CLEAR	Clear	T12	F40	46.25	1.65	395	24
35133	TGF96T12/UV/92.25" CLEAR	Clear	T12	F96	92.25	1.65	395	24

Accessories

Order code	Description	Colour	Material	Figure
Sheet				
12378	HEAT SINK SCREEN	Black	Metal mesh	A
End Cap				
35136	TUBE GUARD END CAP T8	Black	Polycarbonate	B
35137	TUBE GUARD END CAP T12	Black	Polycarbonate	C

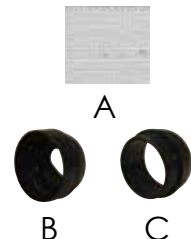

¹T5 tube guards cannot be used with T5HO lamps



 


Vapour Proof



Vapour proof Kit



Replacement Lens

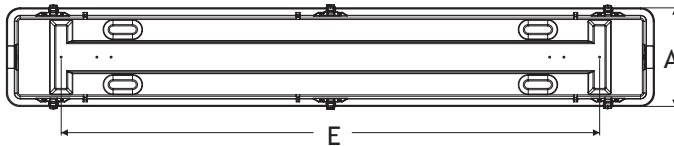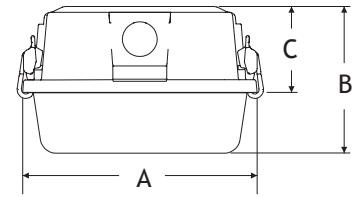

Order code	Description	Colour	Material	Dimensions (in.)				
				A	B	C	D	E

Vapour Proof Kit

35554	VPR PROOF HOUSING SHALLOW KIT 24L	White	Fiberglass	6-5/8	5-3/16	3-3/16	25-7/8	14-3/4
35552	VPR PROOF HOUSING SHALLOW KIT 48L	White	Fiberglass	7-5/8	5-5/8	2-13/16	49-59/64	38-3/4
35553	VPR PROOF HOUSING DEEP KIT 96L	White	Fiberglass	7-5/8	5-5/8	2-13/16	97-15/16	86-3/4

Order code	Description	Colour	Material	Pattern	Outside height (in.)	Outside length (in.)	Outside width (in.)
------------	-------------	--------	----------	---------	----------------------	----------------------	---------------------

Replacement Lens

35217	VPR PROOF LENS ACR CL SMTH 49-5/8L	Clear	Acrylic	Smooth	2-11/16	49-5/8	7-3/4
56004	VPR PROOF LENS ACR CL CRP 49-11/16L	Clear	Acrylic	Crepe	2	49-11/16	6-1/2
57072	VPR PROOF LENS ACR CL CRP 49-3/4L	Clear	Acrylic	Crepe	2-5/8	49-3/4	7-1/2
35749	VPR PROOF LENS ACR CL CRP 49-15/16L	Clear	Acrylic	Crepe	2-5/8	49-15/16	7-5/8
35212	VPR PROOF LENS ACR CL CRP 50-7/8L	Clear	Acrylic	Crepe	2	50-7/8	6-1/2
35208	VPR PROOF LENS ACR CL CRP 52L	Clear	Acrylic	Crepe	2-5/8	52	7-1/2
35209	VPR PROOF LENS POLY CL SMTH 52L	Clear	Polycarbonate	Smooth	2-5/8	52	7-1/2
35227	VPR PROOF LENS ACR OP S80 52L	Opal	Acrylic	S80	2-5/8	52	7-1/2
35748	VPR PROOF LENS ACR CL CRP 52L DEEP	Clear	Acrylic	Crepe	3	52	7-1/2
35551	VPR PROOF LENS ACR CL CRP 97-3/4L	Clear	Acrylic	Crepe	2-5/8	97-3/4	7-1/2
35751	VPR PROOF LENS ACR CL CRP 97-3/4L DEEP	Clear	Acrylic	Crepe	3	97-3/4	6-1/2
35752	VPR PROOF LENS ACR CL CRP 102L DEEP	Clear	Acrylic	Crepe	3	102	7-1/2
35211	VPR PROOF LENS ACR CL CRP 102L	Clear	Acrylic	Crepe	2-5/8	102	7-1/2

08

Accessory

Order code	Description	Colour	Material
12866	VPR PROOF CLIP POLY WH	White	Polycarbonate



Replacement Clip

* For exact shapes and dimensions, please refer to our Optics Lens Chart, or Optics Acrylic replacement Lenses guide, or our website.

Wrap Lens

Order code	Description	Colour	Material	Outside height (in.)	Outside width (in.)	Outside length (in.)	Pattern	Thickness (in.)
Wrap Lens								
35234	SUC322 WRAP LENS ACR OP 24L	Opal	Acrylic	1-1/2	2-3/4	24	S80	0.080
35259	SF821 WRAP LENS ACR OP 29-3/4L	Opal	Acrylic	2-7/8	4-7/8	29-3/4	S80	0.080
35269	SF101 WRAP LENS ACR CL 29-3/4L	Clear	Acrylic	2-7/8	4-7/8	29-3/4	K12	0.110
12443	SF152/S WRAP LENS ACR CL 47-1/16L	Clear	Acrylic	2-1/8	8	47-1/16	K12	0.110
12442	SF142/S WRAP LENS ACR CL 47-3/16L	Clear	Acrylic	2-1/4	9-15/16	47-3/16	K12	0.110
12440	SF102/O WRAP LENS ACR OP 47-1/4L	Opal	Acrylic	2-1/2	7	47-1/4	S80	0.080
35270	SF102 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-9/16	7	47-1/4	K12	0.110
35298	SF232 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-1/2	7-1/4	47-1/4	K12	0.110
35262	SF832 WRAP LENS ACR OP 47-1/4L	Opal	Acrylic	2-23/32	7-11/16	47-1/4	S80	0.080
35300	SF833 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-3/4	7-3/4	47-1/4	K12	0.110
35265	SF842 WRAP LENS ACR OP 47-1/4L	Opal	Acrylic	2-3/4	8-3/4	47-1/4	S80	0.080
35273	SF112 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-3/4	8-3/4	47-1/4	K12	0.110
35277	SF132 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-1/4	9	47-1/4	K12	0.110
35297	SF222 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	3	9	47-1/4	K12	0.110
35275	SF122 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-1/4	9-3/4	47-1/4	K12	0.110
35285	SF162 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	3-1/8	9-3/4	47-1/4	K12	0.110
35598	SF172 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	3-1/4	10-1/2	47-1/4	K12	0.110
35296	SF204 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-1/2	12-3/8	47-1/4	K12	0.110
35294	SF194 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	3	14	47-1/4	K12	0.110
35278	SF134 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	3-1/4	14-1/8	47-1/4	K12	0.110
35274	SF114 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-1/4	14-1/2	47-1/4	K12	0.110
35201	SE114 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-1/4	15-13/16	47-1/4	K12	0.110
35272	SF104 WRAP LENS ACR CL 47-1/4L	Clear	Acrylic	2-7/8	15-7/8	47-1/4	K12	0.110
35200	SE112 WRAP LENS ACR CL 47-5/16L	Clear	Acrylic	2-7/8	10-1/2	47-5/16	K12	0.110
35290	SF184 WRAP LENS ACR CL 47-3/8L	Clear	Acrylic	1-3/4	13-3/4	47-3/8	K12	0.110
35281	SF144 WRAP LENS ACR CL 47-1/2L	Clear	Acrylic	3-3/4	15-13/16	47-1/2	K12	0.110
35267	SF861 WRAP LENS ACR OP 47-11/16L	Opal	Acrylic	3-3/4	4	47-11/16	S80	0.080
35289	SF182 WRAP LENS ACR CL 47-11/16L	Clear	Acrylic	3-1/8	8-7/8	47-11/16	K12	0.110
35261	SF831 WRAP LENS ACR OP 47-3/4L	Opal	Acrylic	2-1/2	2-3/4	47-3/4	S80	0.080
35299	SF242 WRAP LENS ACR CL 47-3/4L	Clear	Acrylic	1-5/8	7-3/8	47-3/4	K12	0.110
35213	SE172 WRAP LENS ACR CL 47-3/4L	Clear	Acrylic	2	8-1/2	47-3/4	K12	0.125
35595	SM122 WRAP LENS ACR CL 47-13/16L	Clear	Acrylic	3-1/2	10-3/8	47-13/16	K12	0.110
57101	SE701 WRAP LENS ACR OP 47-7/8L	Opal	Acrylic	31/32	3-3/16	47-7/8	S80	0.080
12436	SF811/S WRAP LENS ACR OP 47-7/8L	Opal	Acrylic	3	3-15/16	47-7/8	S80	0.080
35263	SF841 WRAP LENS ACR OP 47-7/8L	Opal	Acrylic	2-9/16	4	47-7/8	S80	0.080
35264	SF841/C WRAP LENS ACR CL 47-7/8L	Clear	Acrylic	2-5/8	4	47-7/8	K12	0.110
35266	SF851 WRAP LENS ACR OP 47-7/8L	Opal	Acrylic	4-1/8	4-1/8	47-7/8	S80	0.080
35295	SF202 WRAP LENS ACR CL 47-7/8L	Clear	Acrylic	1-1/4	8-13/16	47-7/8	K12	0.110
35597	SM142 WRAP LENS ACR CL 47-7/8L	Clear	Acrylic	3	9-15/16	47-7/8	K12	0.110
35251	SM172 WRAP LENS ACR CL 47-7/8L	Clear	Acrylic	1-1/2	9-5/8	47-7/8	K12	0.110
35240	SM922 WRAP LENS ACR CL 47-7/8L	Clear	Acrylic	2	10	47-7/8	K12	0.125
35249	SM162 WRAP LENS ACR CL 47-7/8L	Clear	Acrylic	1-5/8	10-7/8	47-7/8	K12	0.110
35248	SM154 WRAP LENS ACR CL 47-7/8L	Clear	Acrylic	1-3/4	15-5/8	47-7/8	K12	0.110
35246	SM144 WRAP LENS ACR CL 47-7/8L	Clear	Acrylic	1-1/2	15-11/16	47-7/8	K12	0.110
35230	SE871 WRAP LENS ACR OP 47-15/16L	Opal	Acrylic	3-21/32	3-5/16	47-15/16	S80	0.080
35225	SE831 WRAP LENS ACR OP 47-15/16L	Opal	Acrylic	3-5/8	4-1/8	47-15/16	S80	0.080
35282	SF152 WRAP LENS ACR CL 47-15/16L	Clear	Acrylic	2-1/8	8	47-15/16	K12	0.110
35210	SE153 WRAP LENS ACR CL 47-15/16L	Clear	Acrylic	1-3/8	8-1/4	47-15/16	K12	0.125
35279	SF142 WRAP LENS ACR CL 47-15/16L	Clear	Acrylic	2-1/4	9-15/16	47-15/16	K12	0.110
35253	SM192 WRAP LENS ACR CL 47-15/16L	Clear	Acrylic	1-11/16	11-1/16	47-15/16	K12	0.110
35207	SE144 WRAP LENS ACR CL 47-15/16L	Clear	Acrylic	1-15/16	14	47-15/16	Line	0.125
35286	SF164 WRAP LENS ACR CL 47-15/16L	Clear	Acrylic	2-1/8	15	47-15/16	K12	0.110
35276	SF124 WRAP LENS ACR CL 47-15/16L	Clear	Acrylic	2-1/4	16	47-15/16	K12	0.110
35596	SM124 WRAP LENS ACR CL 47-15/16L	Clear	Acrylic	1-7/8	16	47-15/16	K12	0.110
35255	SF802 WRAP LENS ACR OP 48L	Opal	Acrylic	4-13/16	2-11/16	48	S80	0.080
35254	SF801 WRAP LENS ACR OP 48L	Opal	Acrylic	2-3/4	2-15/16	48	S80	0.080
35260	SF822 WRAP LENS ACR OP 48L	Opal	Acrylic	4-13/32	3-5/16	48	S80	0.080
35599	SF212 WRAP LENS ACR CL 48-3/8L	Clear	Acrylic	1-5/8	10-1/2	48-3/8	K12	0.110
35256	SF811 WRAP LENS ACR OP 48-15/32L	Opal	Acrylic	3	3-15/16	48-15/32	S80	0.080
35258	SF812 WRAP LENS ACR OP 48-15/32L	Opal	Acrylic	5-3/32	3-15/16	48-15/32	S80	0.080



For exact shapes and dimensions, please refer to our Wrap Lens Profile Chart, our Acrylic Replacement Lenses Guide, or our website. For custom lenses, please contact your local sales representative.