


# Reflector

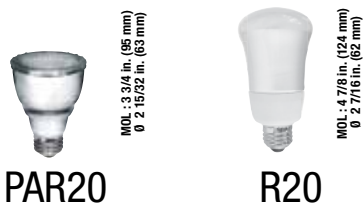

Order code	Description	Watts (W)	Base	Color temp. (K)	Lumen output (lm)	Average life (hrs)	CRI	Hal/Incan equivalent (W)	Case qty (inner/master)
<b>PAR20</b>									
14100 <sup>1</sup>	CF9/27K/PAR20/E26/STD	9	E26	2 700	300	8 000	82	50	6/48
14102 <sup>1</sup>	CF9/35K/PAR20/E26/STD	9	E26	3 500	300	8 000	82	50	6/48
<b>R20</b>									
14162	CF11/27K/R20/E26/STD	11	E26	2 700	350	8 000	82	50	6/48

# Cold Cathode



A19

Order code	Description	Watts (W)	Base	Color temp. (K)	Lumen output (lm)	Average life (hrs)	Color	CRI	Incandescent equivalent (W)	Case qty (inner/master)
<b>A19</b>										
58427	CCFL8/F/A19/25M/E26/STD	8	E26	2 700	320	25 000	Frost	82	35-40	1/48



<sup>1</sup>Suitable for outdoor use(base upwards)

