


# Tube Guard



Order code	Description	Color	Lamp shape	Lamp type	Tube length (in.)	Overall diameter (in.)	UV filtering (nm)	Case qty (master)
<b>T5</b>								
57142 <sup>1</sup>	TGF28T5/44.56" CLEAR	Clear	T5	F28	44.56	0.75	370	96
<b>T8</b>								
35101	TGF15T8/16.38" CLEAR	Clear	T8	F15	16.38	1.24	370	24
12381	TGF25T8/34.00" CLEAR W/O CAP	Clear	T8	F25	34.00	1.24	370	24
12380	TGF25T8/34.44" CLEAR	Clear	T8	F25	34.44	1.24	370	24
12375	TGF32T8/46.00" CLEAR W/O CAP	Clear	T8	F32	46.00	1.24	370	24
35103	TGF32T8/46.44" CLEAR	Clear	T8	F32	46.44	1.24	370	24
35104	TGF32T8/46.44" AMBER	Amber	T8	F32	46.44	1.24	370	24
35108	TGF32T8/46.44" RED	Red	T8	F32	46.44	1.24	370	24
35105	TGF32T8/46.44" BLUE	Blue	T8	F32	46.44	1.24	370	24
35106	TGF32T8/46.44" GREEN	Green	T8	F32	46.44	1.24	370	24
35107	TGF32T8/46.44" PINK	Pink	T8	F32	46.44	1.24	370	24
35109	TGF32T8/46.44" YELLOW	Yellow	T8	F32	46.44	1.24	370	24
35110	TGF96T8/92.44" CLEAR	Clear	T8	F96	92.44	1.24	370	24
<b>T12</b>								
35111	TGF20T12/22.25" CLEAR	Clear	T12	F20	22.25	1.65	370	48
35112	TGF30T12/34.25" CLEAR	Clear	T12	F30	34.25	1.65	370	24
35113	TGF40T12/46.25" CLEAR	Clear	T12	F40	46.25	1.65	370	24
35100	TGF40T12/46.25" YELLOW	Yellow	T12	F40	46.25	1.65	370	24
35115	TGF40T12/46.25" BLUE	Blue	T12	F40	46.25	1.65	370	24
35116	TGF40T12/46.25" GREEN	Green	T12	F40	46.25	1.65	370	24
35117	TGF40T12/46.25" PINK	Pink	T12	F40	46.25	1.65	370	24
35119	TGF40T12/46.25" RED	Red	T12	F40	46.25	1.65	370	24
35124	TGF96T12/92.25" AMBER	Amber	T12	F96	92.25	1.65	370	24
35126	TGF96T12/92.25" GREEN	Green	T12	F96	92.25	1.65	370	24
35127	TGF96T12/92.25" PINK	Pink	T12	F96	92.25	1.65	370	24
35128	TGF96T12/92.25" RED	Red	T12	F96	92.25	1.65	370	24
35129	TGF96T12/92.25" YELLOW	Yellow	T12	F96	92.25	1.65	370	24
35123	TGF96T12/92.25" CLEAR	Clear	T12	F96	92.25	1.65	370	24
35125	TGF96T12/92.25" BLUE	Blue	T12	F96	92.25	1.65	370	24
<b>UV Filtering</b>								
12377	TGF40T8/UV/46.00" CLEAR W/O CAP	Clear	T8	F40	46.00	1.24	395	24
35132	TGF32T8/UV/46.44" CLEAR	Clear	T8	F32	46.44	1.24	395	24
35131	TGF40T12/UV/46.25" CLEAR	Clear	T12	F40	46.25	1.65	395	24

## Accessories

Order code	Description	Color	Material	Figure
<b>Sheet</b>				
12378	HEAT SINK SCREEN	Black	Metal mesh	A
<b>End Cap</b>				
35136	TUBE GUARD END CAP T8	Black	Polycarbonate	B
35137	TUBE GUARD END CAP T12	Black	Polycarbonate	C

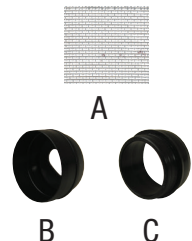

<sup>1</sup>T5 tube guards cannot be used with T5HO lamps