



Single Ended JD

These lamps provide crisp white light and long reliable life.

Features

- Crisp white light
- Consistent colour and brightness
- Reliable long life

Applications

- Display cases
- Museums
- Restaurants
- Marine/boat applications
- Lounges
- Retail Stores




Order code	Description	ANSI code	Watts (W)	Base	Volts (V)	Colour temp. (K)	Initial lumens (lm)	Average life (hrs)	MOL** (in.) (mm)	Case Qty
JD E10 Base										
30315	75Q/CL/MS/28V EYE	-	75	E10	28	2 950	1 350	2 000	2.40 61	50
JD E14 Base										
30303	75Q/CL/E14/130V EYE	-	75	E14	130	2 850	1 150	1 500	2.95 75	50
30298	100Q/CL/E14/130V EYE	-	100	E14	130	2 850	1 600	1 500	2.95 75	50
30299	150Q/CL/E14/130V EYE	-	150	E14	130	2 900	2 400	2 000	2.95 75	50
30301	250Q/CL/E14/130V EYE	-	250	E14	130	2 950	4 500	2 000	3.46 88	50
30302	500Q/CL/E14/130V EYE	-	500	E14	130	2 950	9 500	2 000	3.74 95	50
JD E27 Base										
15432	150QCL/MED/130V EYE	-	150	E27	130	2 900	2 400	2 000	3.46 88	20
30300	250Q/CL/MED/130V EYE	-	250	E27	130	2 950	4 500	2 000	3.94 100	20
JD Frosted E27 Base										
58997	100Q/F/MED/130V EYE	-	100	E27	130	2 850	1 520	2 000	3.46 88	20
JD Mini Can Base										
30213	50Q/CL/MC/130V EYE	-	50	E11	130	2 900	725	2 000	2.75 70	50
30250	75Q/CL/MC/130V EYE	-	75	E11	130	2 900	1 150	2 000	2.75 70	50
30219	100Q/CL/MC/130V EYE	ESN	100	E11	130	2 900	1 600	2 000	2.75 70	50
30225	150Q/CL/MC/130V EYE	ETG	150	E11	130	2 900	2 800	2 000	2.75 70	50
30231	250Q/CL/MC/130V EYE	EHT	250	E11	130	2 900	4 500	2 000	2.95 75	50
30237	400Q/CL/MC/130V EYE	-	400	E11	130	2 900	8 250	2 000	3.74 95	50
30242	500Q/CL/MC/130V EYW EYE	EYW	500	E11	130	2 900	9 500	2 000	3.74 95	50
JD Frosted Mini Can Base										
30254	75Q/F/MC/130V EYE	-	75	E11	130	2 900	1 050	2 000	2.75 70	50
15435	150Q/F/MC/130V EYE	ETH	150	E11	130	2 900	2 660	2 000	2.75 70	50
30233	250Q/F/MC/130V EYE	ESM	250	E11	130	2 900	4 750	2 000	3.46 88	50
30235	400Q/F/MC/130V EYE	-	400	E11	130	2 900	7 840	2 000	3.74 95	50
30244	500Q/F/MC/130V EYV EYE	EYV	500	E11	130	2 900	9 930	2 000	3.74 95	50
JD Mini Can Base - High Voltage										
30307	250Q/CL/MC/220/230V EYE	-	250	E11	230	2 900	4 500	2 000	3.46 88	50
15448	250Q/CL/MC/240/250V EYE	-	250	E11	250	2 900	4 500	2 000	3.46 88	50
15461	500Q/CL/MC/220/230V EYE	-	500	E11	230	2 950	9 500	2 000	3.74 95	50

** Conversions may vary slightly



Single Ended JD

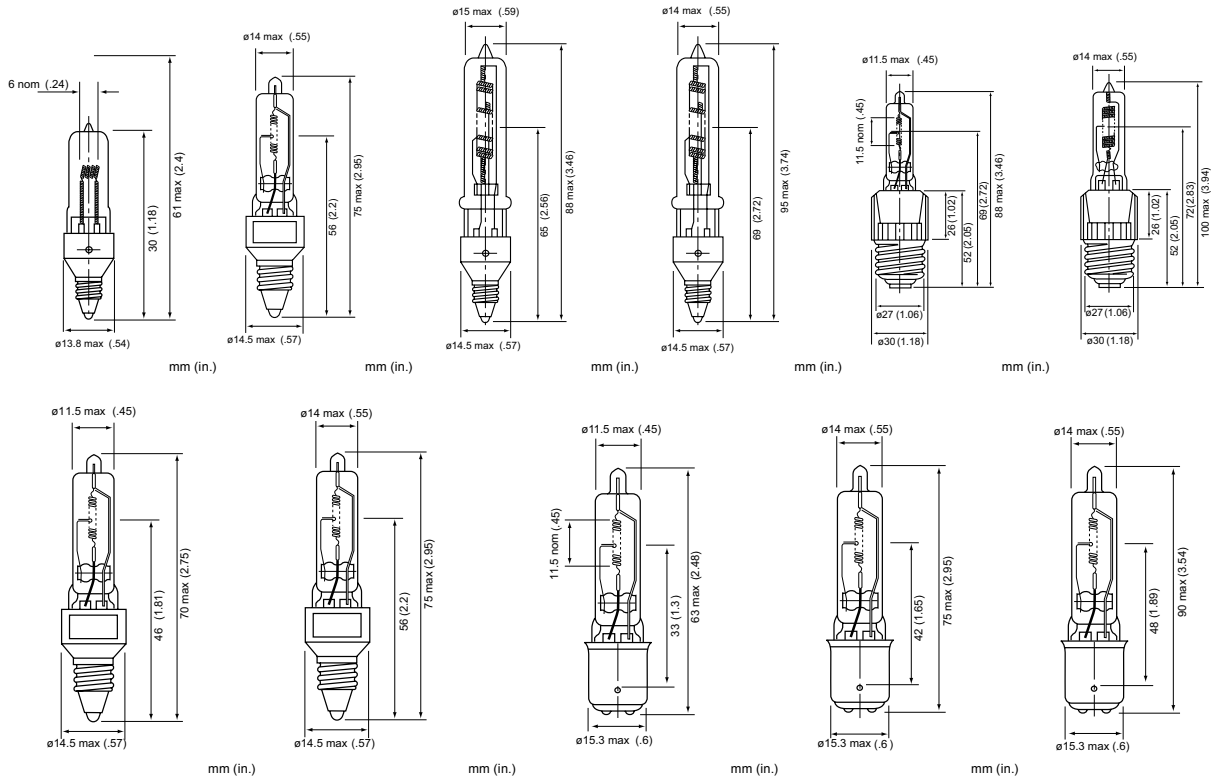

Order code	Description	Watts (W)	Base	Volts (V)	Colour temp. (K)	Initial lumens (lm)	Average life (hrs)	MOL** (in.) (mm)	Case Qty
------------	-------------	-----------	------	-----------	------------------	---------------------	--------------------	------------------	----------

JD DC Base

30212	50Q/CL/DC/130V EYE	50	BA15d	130	2 850	725	2 000	2.48 63	50
30214	75Q/CL/DC/130V EYE	75	BA15d	130	2 850	1 200	2 000	2.48 63	50
30249	75Q/CL/DC/28V EYE	75	BA15d	28	2 850	1 350	2 000	2.40 61	50
30218	100Q/CL/DC/130V EYE	100	BA15d	130	2 850	1 600	2 000	2.48 63	50
15430	150Q/CL/DC/130V EYE	150	BA15d	130	2 850	2 400	2 000	2.48 63	50
15445	250Q/CL/DC/130V EYE	250	BA15d	130	2 900	4 500	2 000	2.95 75	50
30306	250Q/CL/DC/220/230V EYE	250	BA15d	230	2 900	4 500	2 000	2.95 75	50
15450	400Q/CL/DC/130V EYE	400	BA15d	130	2 900	7 600	2 000	3.54 90	50
30241	500Q/CL/DC/130V EYE	500	BA15d	130	2 950	9 500	2 000	3.54 90	50

JD Frosted DC Base

15472	75Q/F/DC/130V EYE	75	BA15d	130	2 850	1 150	2 000	2.48 63	50
30220	100Q/F/DC/130V EYE	100	BA15d	130	2 850	1 550	2 000	2.48 63	50
30226	150Q/F/DC/130V EYE	150	BA15d	130	2 850	2 300	2 000	2.48 63	50
15446	250Q/F/DC/130V EYE	250	BA15d	130	2 900	4 300	2 000	2.95 75	50
15459	500Q/F/DC/130V EYE	500	BA15d	130	2 950	9 930	2 000	3.54 90	50

** Conversions may vary slightly

April 29, 2013