




# LED Presto

Presto LED downlight is an all-in-one product that will fit seamlessly into all residential lighting applications. The base model is complete with a white baffle finish, but this line also offers trims made of stamped metal that will enhance the look of the luminaire, creating a sophisticated look tailored to your decor.



Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
<b>4" Round</b>											
64326	LED/PRESTO/DL4ID/7W/27K/STD	7	120	2 700	590	81	40 000	107	White baffle	50	6
64327	LED/PRESTO/DL4ID/7W/30K/STD	7	120	3 000	630	82	40 000	108	White baffle	50	6
64328	LED/PRESTO/DL4ID/7W/40K/STD	7	120	4 000	638	83	40 000	108	White baffle	50	6
<b>6" Round</b>											
64329	LED/PRESTO/DL6ID/9W/30K/STD	9	120	3 000	805	82	40 000	108	White baffle	65	6
64330	LED/PRESTO/DL6ID/9W/40K/STD	9	120	4 000	835	83	40 000	108	White baffle	65	6

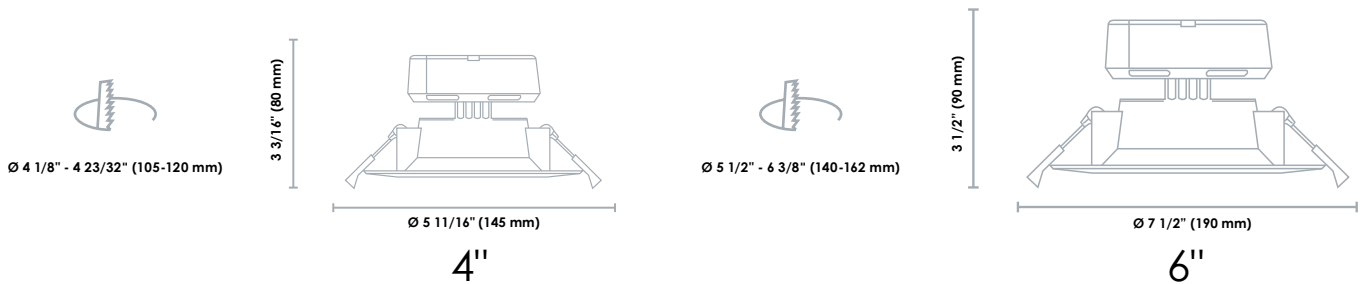


## Accessories - Trims

Order code	Description	Finish	Type	Case qty (master)
<b>4" Round</b>				
64339	LED/PRESTO/ACC.TRIMS/DL4ID/WHT/STD	White	Smooth	120
64340	LED/PRESTO/ACC.TRIMS/DL4ID/BLK/STD	Black	Smooth	120
64341	LED/PRESTO/ACC.TRIMS/DL4ID/SLV/STD	Silver	Smooth	120
64342	LED/PRESTO/ACC.TRIMS/DL4ID/BRZ/STD	Bronze	Smooth	120
<b>6" Round</b>				
64343	LED/PRESTO/ACC.TRIMS/DL6ID/WHT/STD	White	Smooth	120
64346	LED/PRESTO/ACC.TRIMS/DL6ID/BLK/STD	Black	Smooth	120
64347	LED/PRESTO/ACC.TRIMS/DL6ID/SLV/STD	Silver	Smooth	120



## Accessories

Order Code	Description	Opening diameter (in.)	Type	Case qty (master)
66051	ACC/MPLATE/4.25IN/SQR/STD	4 1/4	Square mounting plate	100
66058	ACC/MPLATE/4.25IN/ADJ/STD	4 1/4	Adjustable mounting plate	50
66821	ACC/MPLATE/4.25IN/HANG.BARS/STD	4 1/4	Mounting plate with hanger bars	25
66143	ACC/4/VAPOR BARRIER/STD	4 1/4	Vapor barrier extender	50
66822	ACC/MPLATE/6.25IN/HANG.BARS/STD	6 1/4	Mounting plate with hanger bars	25
64263	ACC/MPLATE/6.25IN/SQR/STD	6 1/4	Square mounting plate	96
64921	ACC/MPLATE/6.25IN/ADJ/STD	6 1/4	Adjustable mounting plate	24
66144	ACC/6/VAPOR BARRIER/STD	6 7/32	Vapor barrier extender	50

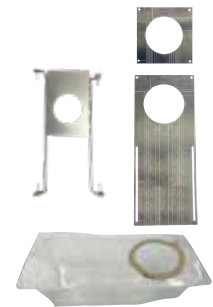

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit [www.standardpro.com](http://www.standardpro.com)