




# LED LPDL™

LPDL™ (Low Profile Downlight) gives you all the flexibility you need during installation, especially in confined areas or when facing constraints such as wood beams, ceiling joist or air ducts. The driver is mounted separately from the light source which allows the luminaire profile to be less than 1" thick!

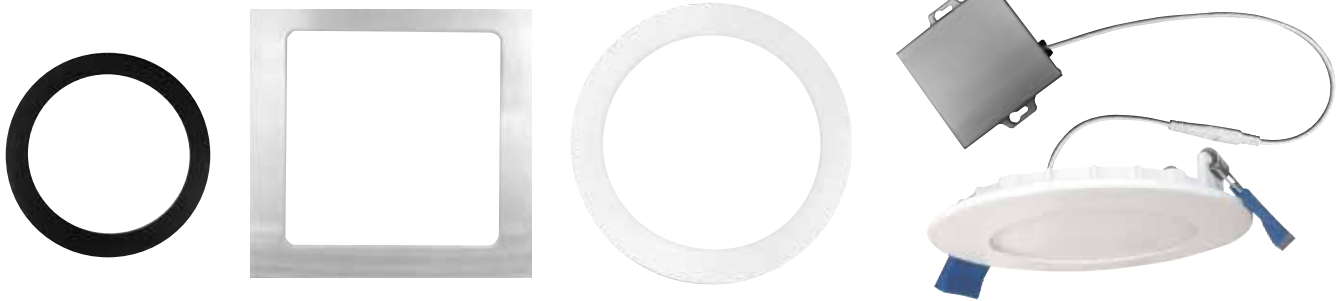

## S1 - Small junction box

(Meets UL standard for branch connection)

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
<b>3" Round</b>											
65851	LPDL3/RND/7W/30K/WH/STD	7	120	3 000	480	80	50 000	110	White	50	24
65852	LPDL3/RND/7W/30K/BN/STD	7	120	3 000	480	80	50 000	110	Brushed nickel	50	24
65853	LPDL3/RND/7W/40K/WH/STD	7	120	4 000	500	80	50 000	110	White	50	24
65854	LPDL3/RND/7W/40K/BN/STD	7	120	4 000	500	80	50 000	110	Brushed nickel	50	24
<b>3" Round Warm-Dim</b>											
65858	LPDL3/RND/7W/30-22K/WH/W-DIM/STD	7	120	3 000-2 200	400	80	50 000	110	White	50	24
65859	LPDL3/RND/7W/30-22K/BN/W-DIM/STD	7	120	3 000-2 200	400	80	50 000	110	Brushed nickel	50	24
<b>3" Square</b>											
65855	LPDL3/SQR/7W/30K/WH/STD	7	120	3 000	430	80	50 000	110	White	50	24
65856	LPDL3/SQR/7W/30K/BN/STD	7	120	3 000	430	80	50 000	110	Brushed nickel	50	24
65857	LPDL3/SQR/7W/40K/WH/STD	7	120	4 000	450	80	50 000	110	White	50	24
<b>4" Round</b>											
63879	LPDL4/RND/9W/27K/WH/STD	9	120	2 700	520	80	50 000	120	White	50	24
63882	LPDL4/RND/9W/30K/WH/STD	9	120	3 000	550	80	50 000	120	White	50	24
63884	LPDL4/RND/9W/30K/BN/STD	9	120	3 000	550	80	50 000	120	Brushed nickel	50	24
63883	LPDL4/RND/9W/30K/BK/STD	9	120	3 000	550	80	50 000	120	Black	50	24
63885	LPDL4/RND/9W/40K/WH/STD	9	120	4 000	580	80	50 000	120	White	50	24
63887	LPDL4/RND/9W/40K/BN/STD	9	120	4 000	580	80	50 000	120	Brushed nickel	50	24
63886	LPDL4/RND/9W/40K/BK/STD	9	120	4 000	580	80	50 000	120	Black	50	24
<b>4" Round Warm-Dim</b>											
65364	LPDL4/RND/9W/30-22K/WH/W-DIM/STD	9	120	3 000-2 200	500	80	50 000	120	White	50	24
65365	LPDL4/RND/9W/30-22K/BN/W-DIM/STD	9	120	3 000-2 200	500	80	50 000	120	Brushed nickel	50	24
<b>4" Square</b>											
63891	LPDL4/SQR/9W/30K/WH/STD	9	120	3 000	530	80	50 000	120	White	50	24
63893	LPDL4/SQR/9W/30K/SLV/STD	9	120	3 000	530	80	50 000	120	Brushed nickel	50	24
<b>6" Round</b>											
63864	LPDL6/RND/12W/30K/WH/STD	12	120	3 000	780	80	50 000	120	White	60	24
63866	LPDL6/RND/12W/30K/BN/STD	12	120	3 000	780	80	50 000	120	Brushed nickel	60	24
63867	LPDL6/RND/12W/40K/WH/STD	12	120	4 000	800	80	50 000	120	White	60	24
63869	LPDL6/RND/12W/40K/BN/STD	12	120	4 000	800	80	50 000	120	Brushed nickel	60	24



AIRTIGHT



DAMP



DIMMABLE



IC RATED



QUICK CONNECT



WARM DIM



PRORATED WARRANTY



Intertek



ENERGY STAR

Lumen values are derived from photometric testing.  
For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit [www.standardpro.com](http://www.standardpro.com)

# 01 LED LPDL™



## S2 - Large junction box

(Meets both UL and CEC standards for branch connection)

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
<b>4" Round Warm-Dim</b>											
65944	LPDL4/S2/RND/9W/30-22K/WH/W-DIM/STD	9	120	3 000-2 200	450	80	50 000	120	White	50	24
65945	LPDL4/S2/RND/9W/30-22K/BN/W-DIM/STD	9	120	3 000-2 200	450	80	50 000	120	Brushed nickel	50	24
<b>4" Round Wet Location</b>											
65724	LPDL4/RND/9W/30K/WH/WET/STD	9	120	3 000	550	80	50 000	120	White	50	24
66220	LPDL4/RND/9W/30K/BN/WET/STD	9	120	3 000	550	80	50 000	120	Brushed nickel	50	24
65725	LPDL4/RND/9W/40K/WH/WET/STD	9	120	4 000	580	80	50 000	120	White	50	24
66221	LPDL4/RND/9W/40K/BN/WET/STD	9	120	4 000	580	80	50 000	120	Brushed nickel	50	24
<b>4" Round FT6 cable for plenum</b>											
66960	LPDL4/S2/FT6/RND/9W/30K/WH/STD	9	120	3 000	550	80	50 000	120	White	50	24
66961	LPDL4/S2/FT6/RND/9W/40K/WH/STD	9	120	4 000	580	80	50 000	120	White	50	24
<b>4" Round</b>											
65936	LPDL4/S2/RND/9W/27K/WH/STD	9	120	2 700	520	80	50 000	120	White	50	24
65937	LPDL4/S2/RND/9W/30K/WH/STD	9	120	3 000	550	80	50 000	120	White	50	24
65938	LPDL4/S2/RND/9W/30K/BN/STD	9	120	3 000	550	80	50 000	120	Brushed nickel	50	24
65939	LPDL4/S2/RND/9W/30K/BLK/STD	9	120	3 000	550	80	50 000	120	Black	50	24
65940	LPDL4/S2/RND/9W/40K/WH/STD	9	120	4 000	580	80	50 000	120	White	50	24
65941	LPDL4/S2/RND/9W/40K/BN/STD	9	120	4 000	580	80	50 000	120	Brushed nickel	50	24
65942	LPDL4/S2/RND/9W/40K/BLK/STD	9	120	4 000	580	80	50 000	120	Black	50	24
65943	LPDL4/S2/RND/9W/50K/WH/STD	9	120	5 000	600	80	50 000	120	White	50	24
<b>4" Square</b>											
65860	LPDL4/SQR/S2/9W/30K/WH/STD	9	120	3 000	550	80	50 000	120	White	50	24
65861	LPDL4/SQR/S2/9W/30K/BN/STD	9	120	3 000	550	80	50 000	120	Brushed nickel	50	24
65862	LPDL4/SQR/S2/9W/40K/WH/STD	9	120	4 000	580	80	50 000	120	White	50	24
65863	LPDL4/SQR/S2/9W/40K/BN/STD	9	120	4 000	580	80	50 000	120	Brushed nickel	50	24
<b>6" Round Wet Location</b>											
65726	LPDL6/RND/12W/30K/WH/WET/STD	12	120	3 000	780	80	50 000	120	White	60	24
65727	LPDL6/RND/12W/40K/WH/WET/STD	12	120	4 000	800	80	50 000	120	White	60	24
<b>6" Round FT6 cable for plenum</b>											
66962	LPDL6/S2/FT6/RND/12W/30K/WH/STD	12	120	3 000	780	80	50 000	120	White	60	24
66963	LPDL6/S2/FT6/RND/12W/40K/WH/STD	12	120	4 000	800	80	50 000	120	White	60	24
<b>6" Round</b>											
65946	LPDL6/S2/RND/12W/30K/WH/STD	12	120	3 000	780	80	50 000	120	White	60	24
65949	LPDL6/S2/RND/12W/30K/BN/STD	12	120	3 000	780	80	50 000	120	Brushed nickel	60	24
65947	LPDL6/S2/RND/12W/40K/WH/STD	12	120	4 000	800	80	50 000	120	White	60	24
65950	LPDL6/S2/RND/12W/40K/BN/STD	12	120	4 000	800	80	50 000	120	Brushed nickel	60	24
65948	LPDL6/S2/RND/12W/50K/WH/STD	12	120	5 000	820	80	50 000	120	White	60	24
<b>6" Square</b>											
65864	LPDL6/SQR/S2/12W/30K/WH/STD	12	120	3 000	780	80	50 000	120	White	60	24



AIRTIGHT



DAMP



DIMMABLE



IC RATED



QUICK CONNECT



WARM DIM



WET



PRORATED WARRANTY




Intertek




ENERGY STAR

# Dimensions

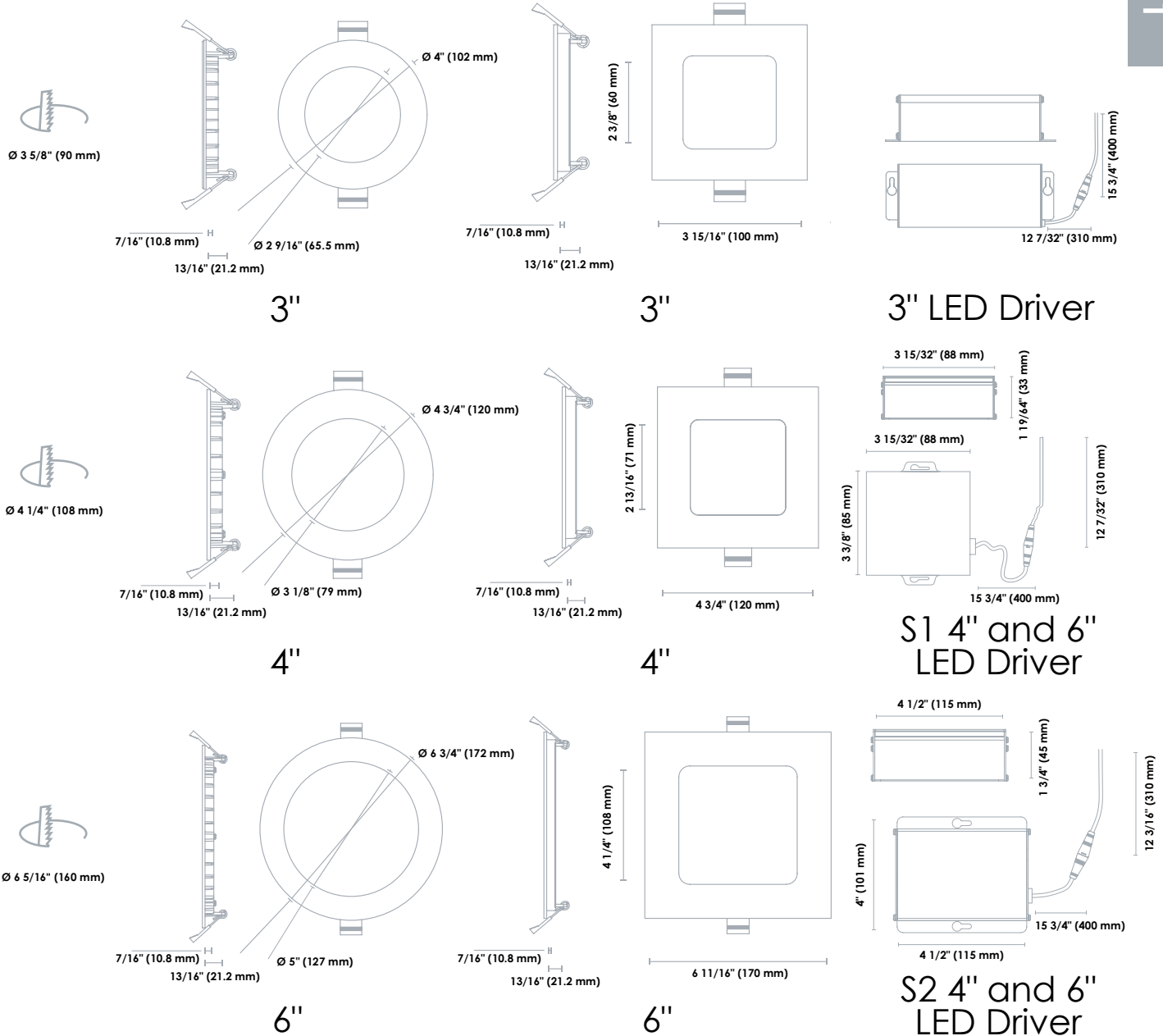

## Accessories

Order Code	Description	Opening diameter (in.)	Type	Case qty (master)
66049	ACC/MPLATE/3.625IN/SQR/STD	3 5/8	Square mounting plate	96
66056	ACC/MPLATE/3.625IN/ADJ/STD	3 5/8	Adjustable mounting plate	96
66142	ACC/3/VAPOR BARRIER/STD	3 5/8	Vapor barrier extender	50
66820	ACC/MPLATE/3.625IN/HANG.BARS/STD	3 5/8	Mounting plate with hanger bars	25
66051	ACC/MPLATE/4.25IN/SQR/STD	4 1/4	Square mounting plate	100
66058	ACC/MPLATE/4.25IN/ADJ/STD	4 1/4	Adjustable mounting plate	50
66821	ACC/MPLATE/4.25IN/HANG.BARS/STD	4 1/4	Mounting plate with hanger bars	25
66143	ACC/4/VAPOR BARRIER/STD	4 1/4	Vapor barrier extender	50
66822	ACC/MPLATE/6.25IN/HANG.BARS/STD	6 1/4	Mounting plate with hanger bars	25
64263	ACC/MPLATE/6.25IN/SQR/STD	6 1/4	Square mounting plate	96
64921	ACC/MPLATE/6.25IN/ADJ/STD	6 1/4	Adjustable mounting plate	24
66144	ACC/6/VAPOR BARRIER/STD	6 7/32	Vapor barrier extender	50
64264	LPDL/ACC/6FT/EXTCABLE/STD	-	6' extension cord	96
66964	LPDL/ACC/6FT/EXTCABLE/FT6/STD	-	6' FT6 extension cord	96

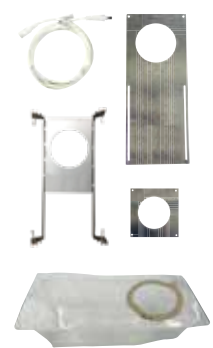

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit [www.standardpro.com](http://www.standardpro.com)