




Presto LED Downlight



With an integrated driver and junction box, the Presto LED Downlight is an all-in-one product that will fit seamlessly into all residential lighting applications. The base model is complete with a white baffle finish, but this line also offers customizable trims made of stamped metal that will enhance the look of the luminaire, creating a sophisticated look tailored to your decor.

- Light weight
- Recessed look – significantly reduces glare

Revolutionizing how Downlights are installed!

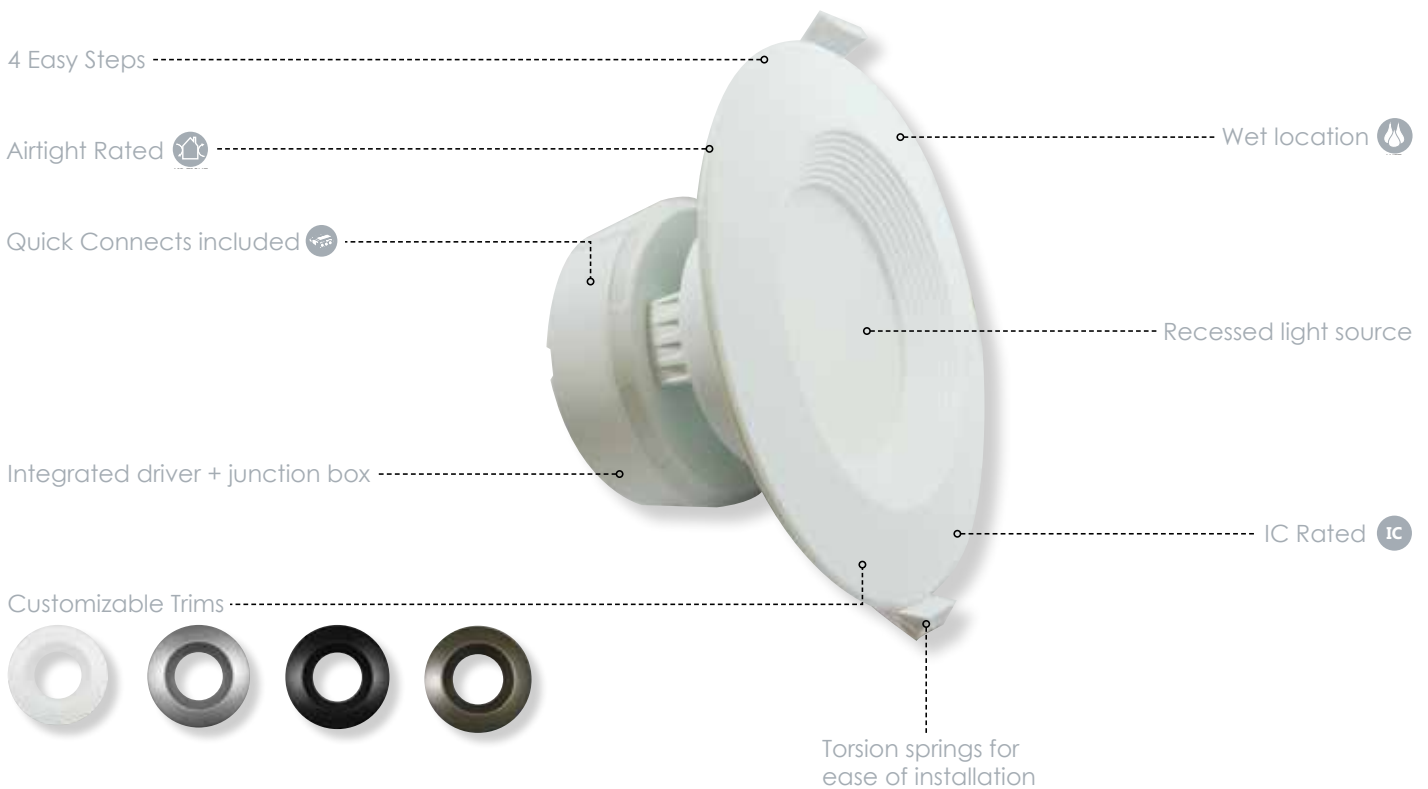

4 Easy Steps

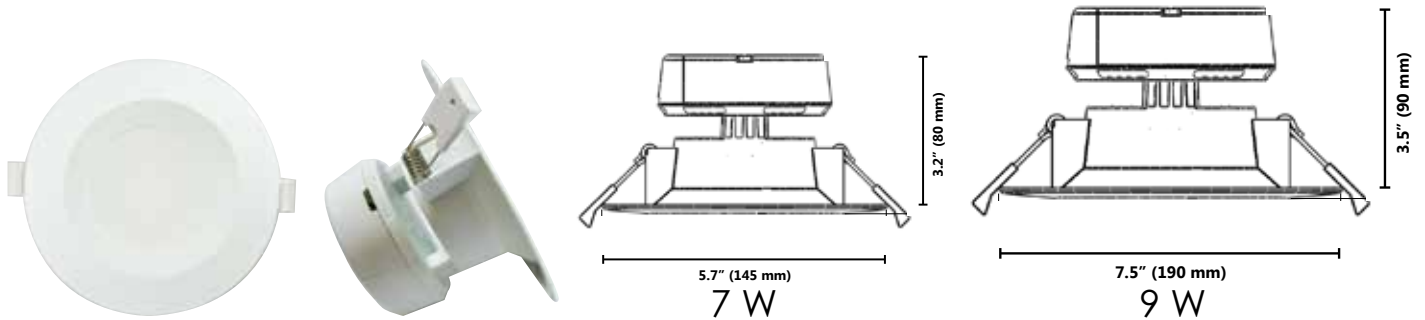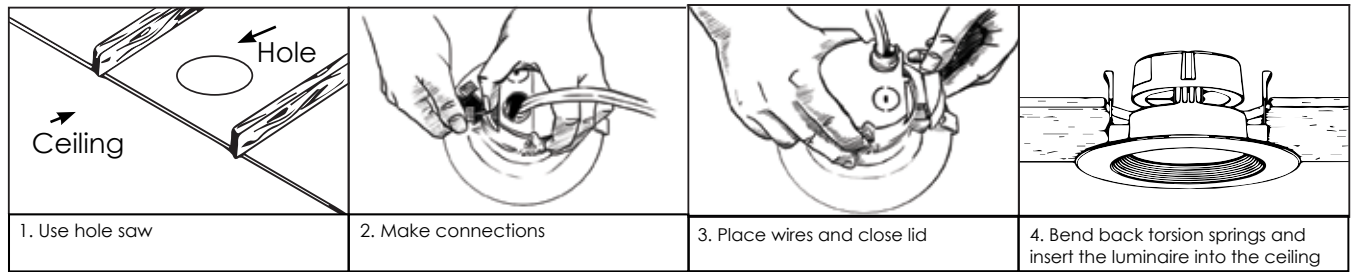

Order code	Description	Watts (W)	Colour	Volts (VAC)	Colour temp. (K)	CRI	Average life ¹ (hrs)	Initial lumens ² (lm)	Traditional equivalent (W)	Beam angle (°)	Dimmable ³ (Yes/No)	Case qty
------------	-------------	-----------	--------	-------------	------------------	-----	---------------------------------	----------------------------------	----------------------------	----------------	--------------------------------	----------

4" Downlight

MOL: 3 3/16 in. (80 mm) DIA: 5 11/16 in. (145 mm)

64326	LED/PRESTO/DL4ID/7W/27K/STD	7	White Baffle	120	2 700	81	40 000	590	50	107	Y	1/6
64327	LED/PRESTO/DL4ID/7W/30K/STD	7	White Baffle	120	3 000	82	40 000	630	50	108	Y	1/6
64328	LED/PRESTO/DL4ID/7W/40K/STD	7	White Baffle	120	4 000	83	40 000	638	50	108	Y	1/6

6" Downlight


MOL: 3 1/2 in. (90 mm) DIA: 7 1/2 in. (190 mm)

64329	LED/PRESTO/DL6ID/9W/30K/STD	9	White Baffle	120	3 000	82	40 000	805	65	109	Y	1/6
64330	LED/PRESTO/DL6ID/9W/40K/STD	9	White Baffle	120	4 000	83	40 000	835	65	110	Y	1/6

Accessories

Order code	Description	Trim colour	Case qty
4" Trim			
64339	LED/PRESTO/ACC.TRIMS/DL4ID/WHT/STD	White	120
64340	LED/PRESTO/ACC.TRIMS/DL4ID/BLK/STD	Black	120
64341	LED/PRESTO/ACC.TRIMS/DL4ID/SLV/STD	Silver	120
64342	LED/PRESTO/ACC.TRIMS/DL4ID/BRZ/STD	Bronze	120
6" Trim			
64343	LED/PRESTO/ACC.TRIMS/DL6ID/WHT/STD	White	120
64346	LED/PRESTO/ACC.TRIMS/DL6ID/BLK/STD	Black	120
64347	LED/PRESTO/ACC.TRIMS/DL6ID/SLV/STD	Silver	120

Order Code	Description	Type
62676	RF/ACC/4/MOUNT. PLATE/SQR/STD	4" square mounting plate
64263	RF/ACC/6/MOUNT. PLATE/SQR/STD	6" square mounting plate
62677	RF/ACC/4/MOUNT. PLATE/ADJ/STD	4" adjustable mounting plate
64921	RF/ACC/6/MOUNT. PLATE/ADJ/STD	6" adjustable mounting plate
62678	RF/ACC/4/MOUNT. PLATE/HANG.BARS/STD	4" mounting plate with hanger bars

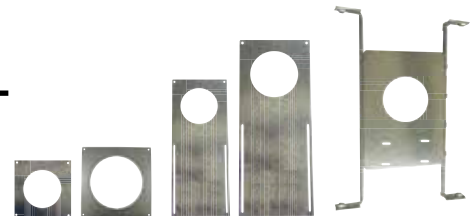

¹ Life rating based on L70 lumen depreciation design criteria. Average life of downlight that have been approved for ENERGY STAR early submission or complete submission can vary. ENERGY STAR early submission dictates that manufacturers can only claim 40 000 hour life with 3 000 hour actual life test data, 6 000 hour LM-80 data and in-situ temperature measurements. Once a product has been fully qualified, manufacturers may increase the lifetime of a product by demonstrating full compliance with the ENERGY STAR criteria at the new lifetime with lumen maintenance at the minimum required test period.

² Typical lumens +/- 10 %

³ For a complete list of compatible dimmers, housings and ENERGY STAR qualified products, please visit www.standardpro.com