

Recessed Fixtures

The E-Lume™ Recessed Fixtures line is composed of airtight housings and of a variety of trims, offering different designs and finishes.

4 1/4" Housings

04



Order code	Description	Opening diameter (in.)	Volts (VAC)	Socket	Case qty (master)
Remodeler - IC Airtight					
64359 ^{2,4}	RF4in/REM0D/IC/LED/E26/ELUME	4 1/4	120	E26	6
64360 ^{1,4}	RF4in/REM0D/IC/LED/GU10/ELUME	4 1/4	120	GU10	6
New Construction - IC Airtight					
64361 ^{1,4}	RF4in/NC/IC/NOBOX/LED/GU10/ELUME	4 1/4	120	GU10	6
64362 ^{2,4}	RF4in/NC/IC/NOBOX/LED/E26/ELUME	4 1/4	120	E26	6
New Construction - IC Airtight					
64363 ³	RF4in/NC/IC/E26/ELUME	4 1/4	120	E26	6
64364 ³	RF4in/NC/IC/GU10/ELUME	4 1/4	120	GU10	6

4 1/4" Trims Compatible Lamp (PAR20)




Order code	Description	Finish	Rotation angle (°)	Case qty (master)
Deep Baffle				
64376	RF4/TRIM/DB/BLK/PAR20/ELUME	Black	N/A	24
64377	RF4/TRIM/DB/BLK_BR.NKL/PAR20/ELUME	Black / Brushed Nickel	N/A	24
64378	RF4/TRIM/DB/WH/PAR20/ELUME	White	N/A	24
Gimbal				
64379	RF4/TRIM/GMB/BLK/PAR20/ELUME	Black	30	12
64381	RF4/TRIM/GMB/BR.NKL/PAR20/ELUME	Brushed Nickel	30	12
64383	RF4/TRIM/GMB/WH/PAR20/ELUME	White	30	12
64384	RF4/TRIM/GMB/BRZ/PAR20/ELUME	Bronze	30	12
Reflector				
64372	RF4/TRIM/RFL_BLK/PAR20/ELUME	Black	N/A	24
64373	RF4/TRIM/RFL_WH/PAR20/ELUME	White	N/A	24
64374	RF4/TRIM/RFL_BR.NKL/PAR20/ELUME	Brushed Nickel	N/A	24



For complete warranty information please visit www.standardpro.com
⁴ Only valid with LED lamps

4 1/4" Trims


Compatible Lamp (MR16 GU10, MR16 E26, PAR16)

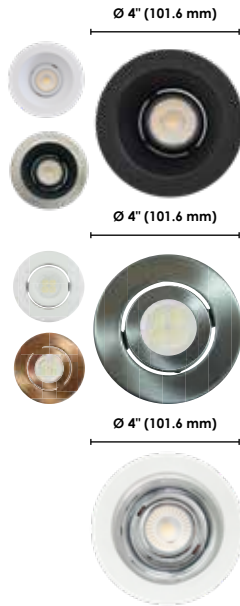

Order code	Description	Finish	Rotation angle (°)	Case qty (master)
Deep Baffle - Gimbal				
64370	RF4/TRIM/GMB.DB/BLK/MR16/ELUME	Black	30	24
64371	RF4/TRIM/GMB.DB/BLK_BR.NKL/MR16/ELUME	Black / Brushed Nickel	30	24
64375	RF4/TRIM/GMB.DB/WH/MR16/ELUME	White	30	24
Gimbal				
64380	RF4/TRIM/GMB/BR.NKL/MR16/ELUME	Brushed Nickel	30	12
64382	RF4/TRIM/GMB/WH/MR16/ELUME	White	30	12
64385	RF4/TRIM/GMB/BRZ/MR16/ELUME	Bronze	30	12
Reflector - Gimbal				
65548	RF4/TRIM/GMB.DB/RFL_WH/MR16/ELUME	Chrome / White	30	24

4 1/4" Shower Trims


Compatible Lamp² (PAR20)

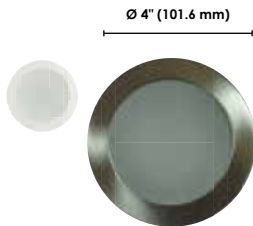

Order code	Description	Finish	Rotation angle (°)	Case qty (master)
Shower				
64387 ¹	RF4/TRIM/SWR/BR.NKL/PAR20/ELUME	Brushed Nickel	N/A	24
64389 ¹	RF4/TRIM/SWR/WH/PAR20/ELUME	White	N/A	24

4 1/4" Shower Trims


Compatible Lamp² (MR16 GU10, MR16 E26, PAR16)

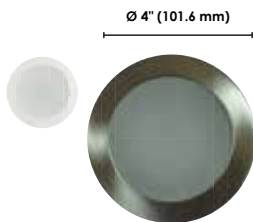

Order code	Description	Finish	Rotation angle (°)	Case qty (master)
Shower				
64386 ¹	RF4/TRIM/SWR/BR.NKL/MR16/ELUME	Brushed Nickel	N/A	24
64388 ¹	RF4/TRIM/SWR/WH/MR16/ELUME	White	N/A	24

Accessories

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
66052	RF/ACC/4.5/MOUNT. PLATE/SQR/STD	4 1/2	Square mounting plate	50
62772	RF/ACC/4.5/MOUNT. PLATE/HANG.BARS/STD	4 1/2	Mounting plate with hanger bars	25
62679	ACC/VAPOR BARRIER/STD	-	Vapor barrier extender	25
66143	ACC/4/VAPOR BARRIER/STD	4 1/4	Vapor barrier extender	50

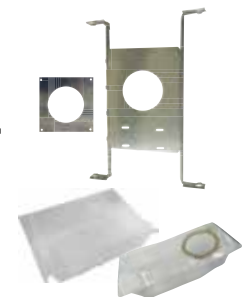


¹ Notes: Not recommended for use in steam showers or when directly exposed to water
² Enclosed fixtures may reduce the LED or CFL lamp life



LED Remodeler Kit

- Airtight Remodeler housing for insulated ceiling (IC)
- Complete set in one box: housing, trim and lamp

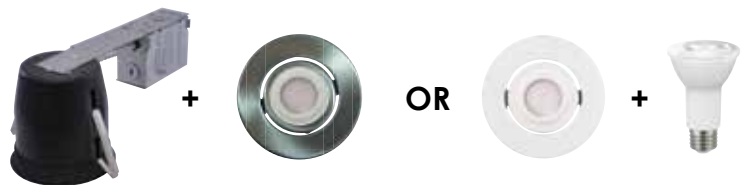

Order code	Description	Finish	Size (in.)	Case qty (master)
Kits				
64681	K/RF4/PAR20/GMB/BR.NKL/LED/ELUME	Brushed Nickel	4 1/4	6
64682	K/RF4/PAR20/GMB/WH/LED/ELUME	White	4 1/4	6



AIRTIGHT



DAMP



DIMMABLE



5 YEARS WARRANTY



UL US



ENERGY STAR