









01 LED Downlights

Residential

		Product highlights	Beam angle (°)	Colour temp. (K)
	Retro	<ul style="list-style-type: none"> • Retrofit only • E26 adaptor • Indoor / outdoor applications • 90+ CRI 	100	2 700 3 000 4 000
	Traditional	<ul style="list-style-type: none"> • 2 installation options • Surface mount 	113	2 700 3 000 4 000
	LPDL™	<ul style="list-style-type: none"> • Less than 1" thick • LED driver / jbox included • Widest variety of options • FT6 options for plenum applications 	120	2 700 3 000-2 200 3 000 4 000 5 000
	Presto	<ul style="list-style-type: none"> • Integrated LED driver / jbox • Regressed look • 4 metal trim finishes available 	108	2 700 3 000 4 000
	Gimbal	<ul style="list-style-type: none"> • Up to 24° tilt • Small 1 1/2" aperture • LED driver / jbox included • Interchangeable trims • Reproduces the look of a traditional downlight 	40	3 000-2 200 3 000 4 000
	Lumeina™	<ul style="list-style-type: none"> • Reproduces the look of an MR16 halogen lamp • Interchangeable trims • 3 beam options • LED driver / jbox included • 90+ CRI 	22 36 60	2 700 3 000 3 500 4 000

Commercial

	Commercial	<ul style="list-style-type: none"> • Retrofit only • Replaces HID and CFL 	52	3 500 4 000
	Veloce™	<ul style="list-style-type: none"> • High light output • 2 beam options • Interchangeable baffles (black or white) and reflector (silver) • LED driver / jbox included • 90+ CRI 	45 70	3 000 3 500 4 000

Watts (W)	Volts (VAC)	Size (in.)	Shape	Life L70 (hrs)	Finish	Lumen output (lm)
10 12	120	4 5 and 6	Round	50 000	White	4": 650 5"-6": 850
10 12.5	120	4 6	Round	40 000	White Black Grey	4": Up to 720 6": Up to 850
7 9 12	120	3 4 6	Round Square	50 000	White Black Brushed nickel	3": Up to 500 4": Up to 600 6": Up to 820
7 9	120	4 6	Round	40 000	White Black Silver Bronze	4": Up to 638 6": Up to 835
7	120	3 4	Round Square	Up to 36 000	White Black Brushed nickel	Up to 620
6 9	120	3 1/16 up to 4 7/16	Round Square	50 000	White White / Chrome Black / Chrome Silver / Chrome	6 W: 750 9 W: 950
18 27 40 54	120-277	6 8 10	Round	54 000	Stainless	18 W: 1 600 27 W: 2 400 40 W: 3 600 54 W: 4 900
13 18 26 38	120-277	4 6 8	Round	50 000	White with black or white baffle or silver reflector	V4 13 W: 960 to 1 160 V6 18 W: 1 860 to 2 030 V6 26 W: 2 500 to 2 750 V8 26 W: 2 490 to 2 800 V8 38 W: 3 500 to 3 950



LED Retro

These LED Retro downlights offer a simple and economical option in any traditional downlight retrofit application. Easily replace the original lamp and trim with this LED solution and save on energy consumption and maintenance costs. With an E26 socket adaptor, this luminaire will fit in most traditional 4", 5" and 6" housings, and will be installed in no time.

- Perfect for both indoor and outdoor applications
- High CRI of 90 for great light output
- Regressed look to reduce glare




4"




5" - 6"

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
4" Round											
66090	RDL4/10W/27K/WH/BAF/STD	10	120	2 700	681	90	50 000	100	White aluminum	50	20
66091	RDL4/10W/30K/WH/BAF/STD	10	120	3 000	712	90	50 000	100	White aluminum	50	20
66092	RDL4/10W/40K/WH/BAF/STD	10	120	4 000	713	90	50 000	100	White aluminum	50	20
5" - 6" Round											
66093 ¹	RDL6/12W/27K/WH/BAF/STD	12	120	2 700	852	90	50 000	100	White aluminum	65	10
66094 ¹	RDL6/12W/30K/WH/BAF/STD	12	120	3 000	877	90	50 000	100	White aluminum	65	10
66095 ¹	RDL6/12W/40K/WH/BAF/STD	12	120	4 000	892	90	50 000	100	White aluminum	65	10

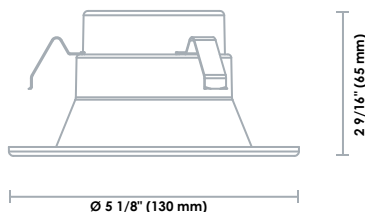


4"

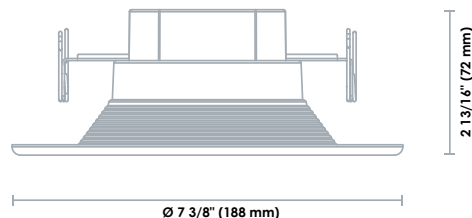

5" - 6"

 Lumen values are derived from photometric testing
 For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com
¹ 6" Retro downlight can be adjusted and installed in 5" or 6" traditional housings
² This product complies with UL1598C standard for LED luminaire Retrofit kits






LED Traditional

These dimmable LED downlight kits combine exceptional light output with the traditional downlight look. They are versatile and allow the user to easily convert most traditional recessed fixtures by installing them into a housing or installing them directly into a junction box.

- All mounting hardware is included for retrofit or new construction
- IC rated when used in an approved IC rated recessed housing

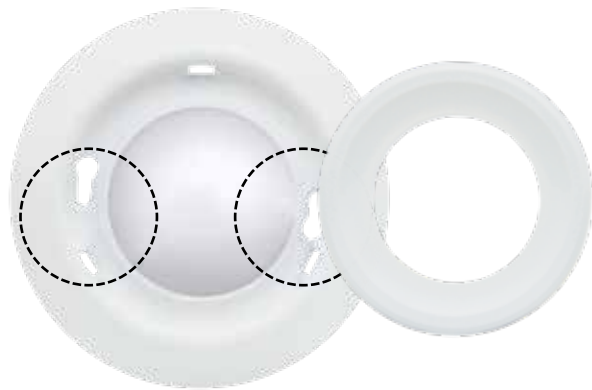

Easy installation using quick access keyhole design





Retrofit Installation



J-Box Installation



Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
4" Round											
63641	LED/DL4/10W/27K/RETRO/WH/STD	10	120	2 700	682	82	40 000	113	White	50	16
63642	LED/DL4/10W/27K/RETRO/BLK/STD	10	120	2 700	682	82	40 000	113	Black	50	16
63643	LED/DL4/10W/27K/RETRO/GRY/STD	10	120	2 700	682	82	40 000	113	Grey	50	16
63644	LED/DL4/10W/30K/RETRO/WH/STD	10	120	3 000	684	82	40 000	113	White	50	16
63645	LED/DL4/10W/30K/RETRO/BLK/STD	10	120	3 000	684	82	40 000	113	Black	50	16
63646	LED/DL4/10W/30K/RETRO/GRY/STD	10	120	3 000	684	82	40 000	113	Grey	50	16
63647	LED/DL4/10W/40K/RETRO/WH/STD	10	120	4 000	723	82	40 000	113	White	50	16
63648	LED/DL4/10W/40K/RETRO/BLK/STD	10	120	4 000	723	82	40 000	113	Black	50	16
63649	LED/DL4/10W/40K/RETRO/GRY/STD	10	120	4 000	723	82	40 000	113	Grey	50	16
6" Round											
63650	LED/DL6/12.5W/27K/RETRO/WH/STD	12.5	120	2 700	800	84	40 000	113	White	65	16
63653	LED/DL6/12.5W/30K/RETRO/WH/STD	12.5	120	3 000	809	84	40 000	113	White	65	16
63654	LED/DL6/12.5W/30K/RETRO/BLK/STD	12.5	120	3 000	809	84	40 000	113	Black	65	16
63655	LED/DL6/12.5W/30K/RETRO/GRY/STD	12.5	120	3 000	809	84	40 000	113	Grey	65	16
63656	LED/DL6/12.5W/40K/RETRO/WH/STD	12.5	120	4 000	853	84	40 000	113	White	65	16

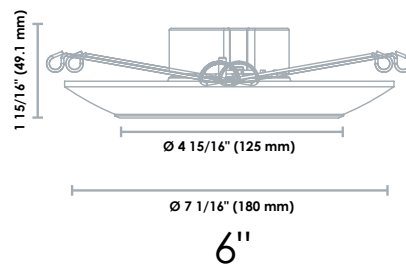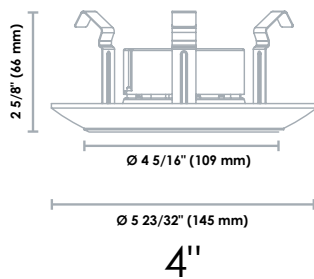


Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com



LED LPDL™

LPDL™ (Low Profile Downlight) gives you all the flexibility you need during installation, especially in confined areas or when facing constraints such as wood beams, ceiling joist or air ducts. The driver is mounted separately from the light source which allows the luminaire profile to be less than 1" thick!

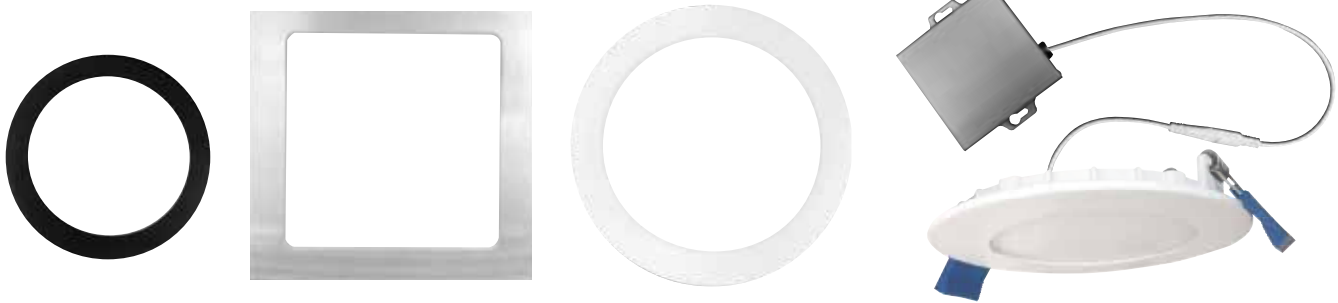

S1 - Small junction box

(Meets UL standard for branch connection)

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
3" Round											
65851	LPDL3/RND/7W/30K/WH/STD	7	120	3 000	480	80	50 000	110	White	50	24
65852	LPDL3/RND/7W/30K/BN/STD	7	120	3 000	480	80	50 000	110	Brushed nickel	50	24
65853	LPDL3/RND/7W/40K/WH/STD	7	120	4 000	500	80	50 000	110	White	50	24
65854	LPDL3/RND/7W/40K/BN/STD	7	120	4 000	500	80	50 000	110	Brushed nickel	50	24
3" Round Warm-Dim											
65858	LPDL3/RND/7W/30-22K/WH/W-DIM/STD	7	120	3 000-2 200	400	80	50 000	110	White	50	24
65859	LPDL3/RND/7W/30-22K/BN/W-DIM/STD	7	120	3 000-2 200	400	80	50 000	110	Brushed nickel	50	24
3" Square											
65855	LPDL3/SQR/7W/30K/WH/STD	7	120	3 000	430	80	50 000	110	White	50	24
65856	LPDL3/SQR/7W/30K/BN/STD	7	120	3 000	430	80	50 000	110	Brushed nickel	50	24
65857	LPDL3/SQR/7W/40K/WH/STD	7	120	4 000	450	80	50 000	110	White	50	24
4" Round											
63879	LPDL4/RND/9W/27K/WH/STD	9	120	2 700	520	80	50 000	120	White	50	24
63882	LPDL4/RND/9W/30K/WH/STD	9	120	3 000	550	80	50 000	120	White	50	24
63884	LPDL4/RND/9W/30K/BN/STD	9	120	3 000	550	80	50 000	120	Brushed nickel	50	24
63883	LPDL4/RND/9W/30K/BK/STD	9	120	3 000	550	80	50 000	120	Black	50	24
63885	LPDL4/RND/9W/40K/WH/STD	9	120	4 000	580	80	50 000	120	White	50	24
63887	LPDL4/RND/9W/40K/BN/STD	9	120	4 000	580	80	50 000	120	Brushed nickel	50	24
63886	LPDL4/RND/9W/40K/BK/STD	9	120	4 000	580	80	50 000	120	Black	50	24
4" Round Warm-Dim											
65364	LPDL4/RND/9W/30-22K/WH/W-DIM/STD	9	120	3 000-2 200	500	80	50 000	120	White	50	24
65365	LPDL4/RND/9W/30-22K/BN/W-DIM/STD	9	120	3 000-2 200	500	80	50 000	120	Brushed nickel	50	24
4" Square											
63891	LPDL4/SQR/9W/30K/WH/STD	9	120	3 000	530	80	50 000	120	White	50	24
63893	LPDL4/SQR/9W/30K/SLV/STD	9	120	3 000	530	80	50 000	120	Brushed nickel	50	24
6" Round											
63864	LPDL6/RND/12W/30K/WH/STD	12	120	3 000	780	80	50 000	120	White	60	24
63866	LPDL6/RND/12W/30K/BN/STD	12	120	3 000	780	80	50 000	120	Brushed nickel	60	24
63867	LPDL6/RND/12W/40K/WH/STD	12	120	4 000	800	80	50 000	120	White	60	24
63869	LPDL6/RND/12W/40K/BN/STD	12	120	4 000	800	80	50 000	120	Brushed nickel	60	24



AIRTIGHT



DAMP



DIMMABLE



IC RATED



QUICK CONNECT



WARM DIM



PRORATED WARRANTY



Intertek



ENERGY STAR

Lumen values are derived from photometric testing.
For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com

LED LPDL™



S2 - Large junction box

(Meets both UL and CEC standards for branch connection)

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
4" Round Warm-Dim											
65944	LPDL4/S2/RND/9W/30-22K/WH/W-DIM/STD	9	120	3 000-2 200	450	80	50 000	120	White	50	24
65945	LPDL4/S2/RND/9W/30-22K/BN/W-DIM/STD	9	120	3 000-2 200	450	80	50 000	120	Brushed nickel	50	24
4" Round Wet Location											
65724	LPDL4/RND/9W/30K/WH/WET/STD	9	120	3 000	550	80	50 000	120	White	50	24
66220	LPDL4/RND/9W/30K/BN/WET/STD	9	120	3 000	550	80	50 000	120	Brushed nickel	50	24
65725	LPDL4/RND/9W/40K/WH/WET/STD	9	120	4 000	580	80	50 000	120	White	50	24
66221	LPDL4/RND/9W/40K/BN/WET/STD	9	120	4 000	580	80	50 000	120	Brushed nickel	50	24
4" Round FT6 cable for plenum											
66960	LPDL4/S2/FT6/RND/9W/30K/WH/STD	9	120	3 000	550	80	50 000	120	White	50	24
66961	LPDL4/S2/FT6/RND/9W/40K/WH/STD	9	120	4 000	580	80	50 000	120	White	50	24
4" Round											
65936	LPDL4/S2/RND/9W/27K/WH/STD	9	120	2 700	520	80	50 000	120	White	50	24
65937	LPDL4/S2/RND/9W/30K/WH/STD	9	120	3 000	550	80	50 000	120	White	50	24
65938	LPDL4/S2/RND/9W/30K/BN/STD	9	120	3 000	550	80	50 000	120	Brushed nickel	50	24
65939	LPDL4/S2/RND/9W/30K/BLK/STD	9	120	3 000	550	80	50 000	120	Black	50	24
65940	LPDL4/S2/RND/9W/40K/WH/STD	9	120	4 000	580	80	50 000	120	White	50	24
65941	LPDL4/S2/RND/9W/40K/BN/STD	9	120	4 000	580	80	50 000	120	Brushed nickel	50	24
65942	LPDL4/S2/RND/9W/40K/BLK/STD	9	120	4 000	580	80	50 000	120	Black	50	24
65943	LPDL4/S2/RND/9W/50K/WH/STD	9	120	5 000	600	80	50 000	120	White	50	24
4" Square											
65860	LPDL4/SQR/S2/9W/30K/WH/STD	9	120	3 000	550	80	50 000	120	White	50	24
65861	LPDL4/SQR/S2/9W/30K/BN/STD	9	120	3 000	550	80	50 000	120	Brushed nickel	50	24
65862	LPDL4/SQR/S2/9W/40K/WH/STD	9	120	4 000	580	80	50 000	120	White	50	24
65863	LPDL4/SQR/S2/9W/40K/BN/STD	9	120	4 000	580	80	50 000	120	Brushed nickel	50	24
6" Round Wet Location											
65726	LPDL6/RND/12W/30K/WH/WET/STD	12	120	3 000	780	80	50 000	120	White	60	24
65727	LPDL6/RND/12W/40K/WH/WET/STD	12	120	4 000	800	80	50 000	120	White	60	24
6" Round FT6 cable for plenum											
66962	LPDL6/S2/FT6/RND/12W/30K/WH/STD	12	120	3 000	780	80	50 000	120	White	60	24
66963	LPDL6/S2/FT6/RND/12W/40K/WH/STD	12	120	4 000	800	80	50 000	120	White	60	24
6" Round											
65946	LPDL6/S2/RND/12W/30K/WH/STD	12	120	3 000	780	80	50 000	120	White	60	24
65949	LPDL6/S2/RND/12W/30K/BN/STD	12	120	3 000	780	80	50 000	120	Brushed nickel	60	24
65947	LPDL6/S2/RND/12W/40K/WH/STD	12	120	4 000	800	80	50 000	120	White	60	24
65950	LPDL6/S2/RND/12W/40K/BN/STD	12	120	4 000	800	80	50 000	120	Brushed nickel	60	24
65948	LPDL6/S2/RND/12W/50K/WH/STD	12	120	5 000	820	80	50 000	120	White	60	24
6" Square											
65864	LPDL6/SQR/S2/12W/30K/WH/STD	12	120	3 000	780	80	50 000	120	White	60	24



AIRTIGHT



DAMP



DIMMABLE



IC RATED



QUICK CONNECT



WARM DIM



WET



PRORATED WARRANTY




Intertek




ENERGY STAR

Dimensions

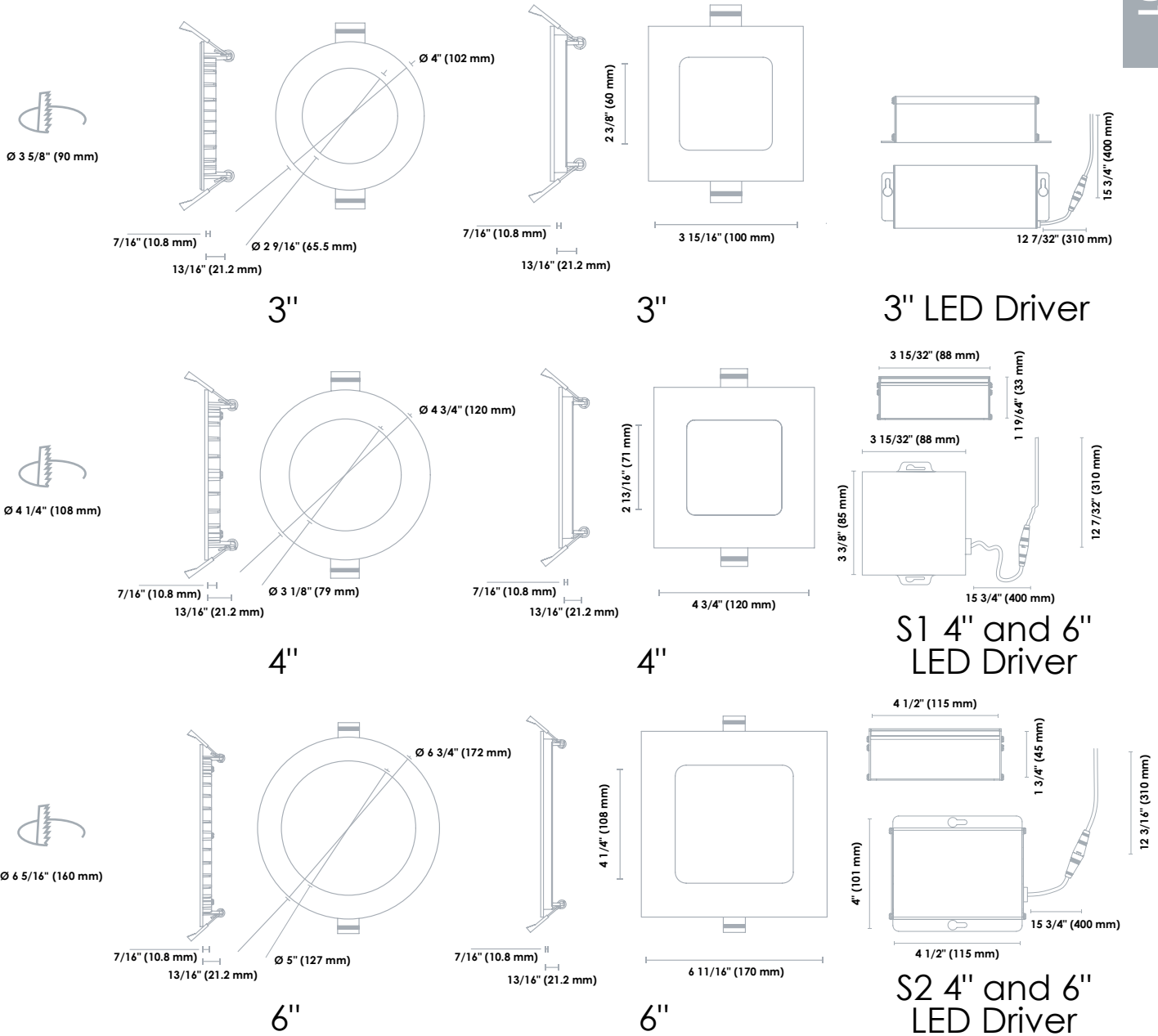

Accessories

Order Code	Description	Opening diameter (in.)	Type	Case qty (master)
66049	ACC/MPLATE/3.625IN/SQR/STD	3 ⁵ / ₈	Square mounting plate	96
66056	ACC/MPLATE/3.625IN/ADJ/STD	3 ⁵ / ₈	Adjustable mounting plate	96
66142	ACC/3/VAPOR BARRIER/STD	3 ⁵ / ₈	Vapor barrier extender	50
66820	ACC/MPLATE/3.625IN/HANG.BARS/STD	3 ⁵ / ₈	Mounting plate with hanger bars	25
66051	ACC/MPLATE/4.25IN/SQR/STD	4 ¹ / ₄	Square mounting plate	100
66058	ACC/MPLATE/4.25IN/ADJ/STD	4 ¹ / ₄	Adjustable mounting plate	50
66821	ACC/MPLATE/4.25IN/HANG.BARS/STD	4 ¹ / ₄	Mounting plate with hanger bars	25
66143	ACC/4/VAPOR BARRIER/STD	4 ¹ / ₄	Vapor barrier extender	50
66822	ACC/MPLATE/6.25IN/HANG.BARS/STD	6 ¹ / ₄	Mounting plate with hanger bars	25
64263	ACC/MPLATE/6.25IN/SQR/STD	6 ¹ / ₄	Square mounting plate	96
64921	ACC/MPLATE/6.25IN/ADJ/STD	6 ¹ / ₄	Adjustable mounting plate	24
66144	ACC/6/VAPOR BARRIER/STD	6 ⁷ / ₃₂	Vapor barrier extender	50
64264	LPDL/ACC/6FT/EXTCABLE/STD	-	6' extension cord	96
66964	LPDL/ACC/6FT/EXTCABLE/FT6/STD	-	6' FT6 extension cord	96

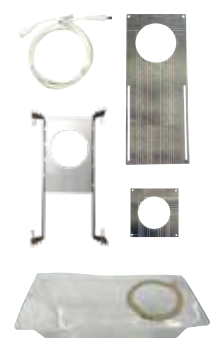

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com




LED Presto

Presto LED downlight is an all-in-one product that will fit seamlessly into all residential lighting applications. The base model is complete with a white baffle finish, but this line also offers trims made of stamped metal that will enhance the look of the luminaire, creating a sophisticated look tailored to your decor.



Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
4" Round											
64326	LED/PRESTO/DL4ID/7W/27K/STD	7	120	2 700	590	81	40 000	107	White baffle	50	6
64327	LED/PRESTO/DL4ID/7W/30K/STD	7	120	3 000	630	82	40 000	108	White baffle	50	6
64328	LED/PRESTO/DL4ID/7W/40K/STD	7	120	4 000	638	83	40 000	108	White baffle	50	6
6" Round											
64329	LED/PRESTO/DL6ID/9W/30K/STD	9	120	3 000	805	82	40 000	108	White baffle	65	6
64330	LED/PRESTO/DL6ID/9W/40K/STD	9	120	4 000	835	83	40 000	108	White baffle	65	6

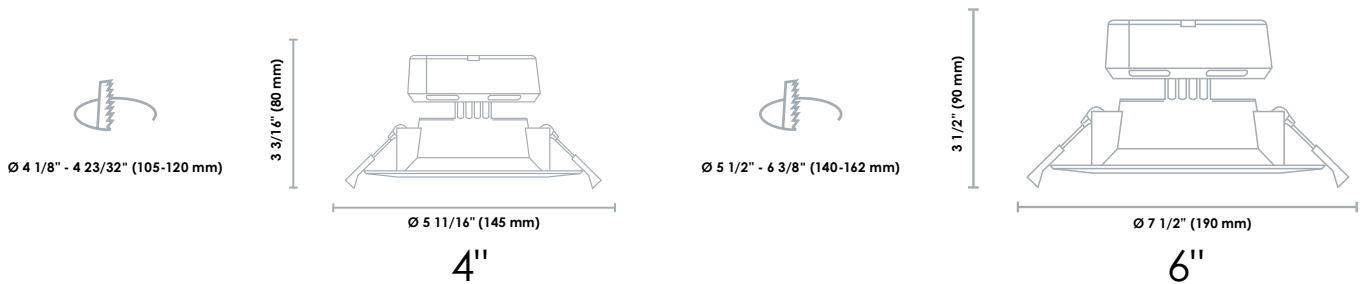


Accessories - Trims

Order code	Description	Finish	Type	Case qty (master)
4" Round				
64339	LED/PRESTO/ACC.TRIMS/DL4ID/WHT/STD	White	Smooth	120
64340	LED/PRESTO/ACC.TRIMS/DL4ID/BLK/STD	Black	Smooth	120
64341	LED/PRESTO/ACC.TRIMS/DL4ID/SLV/STD	Silver	Smooth	120
64342	LED/PRESTO/ACC.TRIMS/DL4ID/BRZ/STD	Bronze	Smooth	120
6" Round				
64343	LED/PRESTO/ACC.TRIMS/DL6ID/WHT/STD	White	Smooth	120
64346	LED/PRESTO/ACC.TRIMS/DL6ID/BLK/STD	Black	Smooth	120
64347	LED/PRESTO/ACC.TRIMS/DL6ID/SLV/STD	Silver	Smooth	120




Accessories

Order Code	Description	Opening diameter (in.)	Type	Case qty (master)
66051	ACC/MPLATE/4.25IN/SQR/STD	4 1/4	Square mounting plate	100
66058	ACC/MPLATE/4.25IN/ADJ/STD	4 1/4	Adjustable mounting plate	50
66821	ACC/MPLATE/4.25IN/HANG.BARS/STD	4 1/4	Mounting plate with hanger bars	25
66143	ACC/4/VAPOR BARRIER/STD	4 1/4	Vapor barrier extender	50
66822	ACC/MPLATE/6.25IN/HANG.BARS/STD	6 1/4	Mounting plate with hanger bars	25
64263	ACC/MPLATE/6.25IN/SQR/STD	6 1/4	Square mounting plate	96
64921	ACC/MPLATE/6.25IN/ADJ/STD	6 1/4	Adjustable mounting plate	24
66144	ACC/6/VAPOR BARRIER/STD	6 7/32	Vapor barrier extender	50

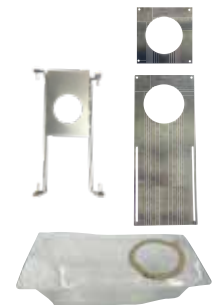

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com

LED Gimbal

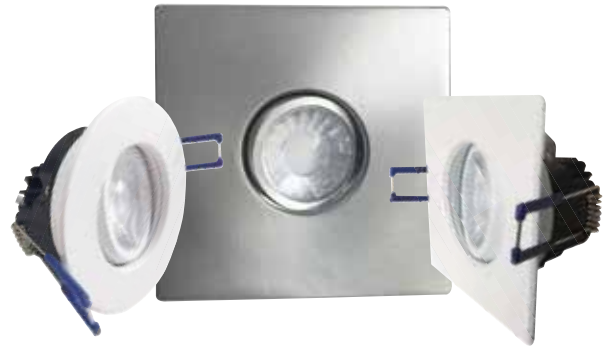

LED Gimbal Downlights are easy to install and allow you to direct the light where needed! The interchangeable trims offered in a variety of shapes, sizes and finishes, give you many options to choose from. Whether in new construction or in retrofit applications, the module and trim combination will fit any application!

- Small aperture designed for a sleek and glare free result
- Light output comparable to a PAR20 halogen lamp
- 24° tilt and 360° module rotation to light any direction




LED Modules and Drivers


Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	CBCP (cd)	Finish	Traditional equivalent (W)	Case qty (master)
Warm Dim Modules												
65981	LED/DL/GIMBAL/MOD/7W/30-22K/WH/STD	7	120	3 000-2 200	470	90	30 000	40	800	White	50	18
65982	LED/DL/GIMBAL/MOD/7W/30-22K/BN/STD	7	120	3 000-2 200	470	90	30 000	40	800	Brushed nickel	50	18
Modules												
65420	LED/DL/GIMBAL/MOD/7W/30K/WH/STD	7	120	3 000	600	80	36 000	40	1 100	White	50	18
65422	LED/DL/GIMBAL/MOD/7W/30K/BN/STD	7	120	3 000	600	80	36 000	40	1 100	Brushed nickel	50	18
65421	LED/DL/GIMBAL/MOD/7W/40K/WH/STD	7	120	4 000	620	80	36 000	40	1 200	White	50	18
65423	LED/DL/GIMBAL/MOD/7W/40K/BN/STD	7	120	4 000	620	80	36 000	40	1 200	Brushed nickel	50	18

Trims


Order code	Description	Finish	Type	Case qty (master)
3" Round				
65432	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/WH/STD	White	Flat	96
65433	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/BN/STD	Brushed nickel	Flat	96
66230	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/BK/STD	Black	Flat	96
65450	LED/DL/GIMBAL/3IN/TRIM/RND/CURVED/WH/STD	White	Curved	96
65451	LED/DL/GIMBAL/3IN/TRIM/RND/CURVED/BN/STD	Brushed nickel	Curved	96
3" Square				
65434	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/WH/STD	White	Flat	96
65435	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/BN/STD	Brushed nickel	Flat	96
66231	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/BK/STD	Black	Flat	96
4" Round				
65436	LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/WH/STD	White	Flat	96
65437	LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/BN/STD	Brushed nickel	Flat	96
66232	LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/BK/STD	Black	Flat	96
4" Square				
65438	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/WH/STD	White	Flat	96
65439	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BN/STD	Brushed nickel	Flat	96
66233	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BK/STD	Black	Flat	96

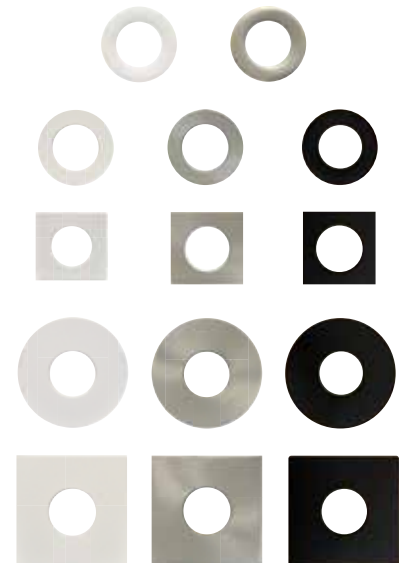

Dimensions

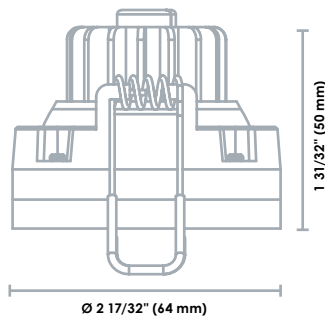


Module

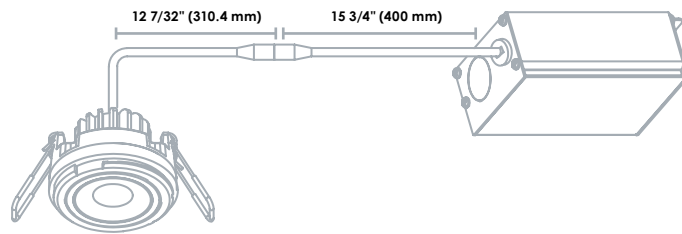


LED Module and Driver



Ø 2 3/4" (70 mm)

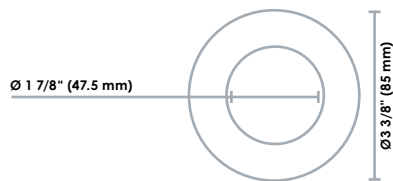


3" Trim

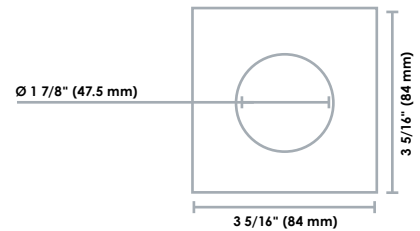


3" Trim



Ø 2 3/4" - 4 1/4" (70-108 mm)

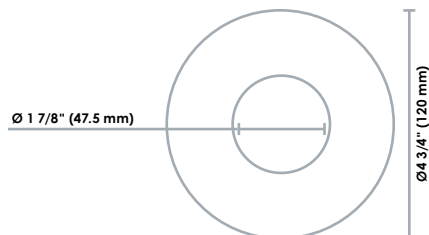

4" Trim

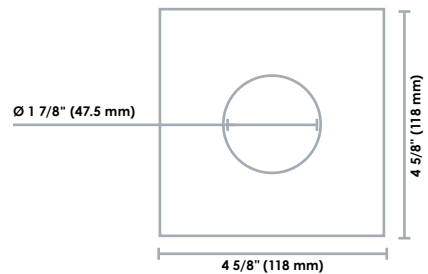

4" Trim

Accessories

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
66020	ACC/MPLATE/2.75IN/SQR/STD	2 3/4	Square mounting plate	96
66021	ACC/MPLATE/2.75IN/ADJ/STD	2 3/4	Adjustable mounting plate	24
66819	ACC/MPLATE/2.75IN/HANG.BARS/STD	2 3/4	Mounting plate with hanger bars	25
64264	LPDL/ACC/6FT/EXTCABLE/STD	-	6' extension cord	96
66142	ACC/3/VAPOR BARRIER/STD	3 5/8	Vapor barrier extender	50



AIRTIGHT



DAMP



DIMMABLE



IC RATED



QUICK CONNECT



WARM DIM



5 YEARS WARRANTY



ETL Intertek



ENERGY STAR

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com





LED Lumeina™

Lumeina™ Series is the perfect combination of state of the art technology and aesthetic design.

The quality of light of this series is comparable to that of a halogen lamp offering crisp, directional light which perfectly highlights surroundings. It offers a CRI of 90 and glare-control reflector design.

This small LED module provides higher lumen performance than an LED lamp and is very easy to install. Without the need of a housing, it is installed directly in the ceiling using torsion springs and most models are IC rated. The LED module is fitted with an external dimmable driver.

Lumeina offers style, discretion and flexibility with a wide selection of interchangeable trims and accessories.



LED Modules

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	CBCP (cd)	Traditional equivalent MR16 (W)	Case qty (master)
------------	-------------	-----------	-------------	------------------	-------------------	-----	----------------	----------------	-----------	---------------------------------	-------------------

IC (can be used in insulated ceiling)


66695	LUMEINA/MOD/IC/6W/27K/22/STD	6	120	2 700	750	90	50 000	22	2 998	50	20
66696	LUMEINA/MOD/IC/6W/27K/36/STD	6	120	2 700	750	90	50 000	36	1 731	50	20
66697	LUMEINA/MOD/IC/6W/27K/60/STD	6	120	2 700	750	90	50 000	60	1 039	50	20
64706	LUMEINA/MOD/IC/6W/30K/22/STD	6	120	3 000	750	90	50 000	22	3 051	50	20
64707	LUMEINA/MOD/IC/6W/30K/36/STD	6	120	3 000	750	90	50 000	36	1 763	50	20
64708	LUMEINA/MOD/IC/6W/30K/60/STD	6	120	3 000	750	90	50 000	60	1 078	50	20
66954	LUMEINA/MOD/IC/6W/35K/22/STD	6	120	3 500	750	92	50 000	22	3 533	50	20
66955	LUMEINA/MOD/IC/6W/35K/36/STD	6	120	3 500	750	92	50 000	36	1 843	50	20
66956	LUMEINA/MOD/IC/6W/35K/60/STD	6	120	3 500	750	92	50 000	60	1 190	50	20
66957	LUMEINA/MOD/IC/6W/40K/22/STD	6	120	4 000	750	92	50 000	22	3 558	50	20
66958	LUMEINA/MOD/IC/6W/40K/36/STD	6	120	4 000	750	91	50 000	36	1 867	50	20
66959	LUMEINA/MOD/IC/6W/40K/60/STD	6	120	4 000	750	91	50 000	60	1 121	50	20

Non-IC (not for use in insulated ceiling)


64709	LUMEINA/MOD/9W/30K/22/STD	9	120	3 000	950	90	50 000	22	3 524	50	20
64710	LUMEINA/MOD/9W/30K/36/STD	9	120	3 000	950	90	50 000	36	2 121	50	20
64711	LUMEINA/MOD/9W/30K/60/STD	9	120	3 000	950	90	50 000	60	1 305	50	20

LED Drivers

	System watts (W)	Max. load (W)	Input Volts (VAC)	Output volts (VDC)	Input current (mA)
Lumeina 6 W	9	9	120	30-38	200
Lumeina 9 W	12	12	120	30-38	260

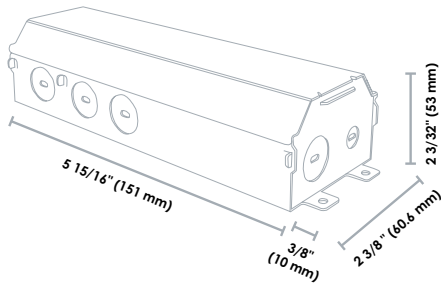

LED Driver
6 W
and 9 W

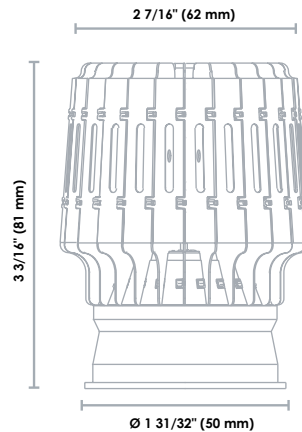

Lumeina™
module
6 W and 9 W

Accessories

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
66020	ACC/MPLATE/2.75IN/SQR/STD	2 3/4	Square mounting plate	96
66021	ACC/MPLATE/2.75IN/ADJ/STD	2 3/4	Adjustable mounting plate	24
66819	ACC/MPLATE/2.75IN/HANG.BARS/STD	2 3/4	Mounting plate with hanger bars	25
66046	ACC/MPLATE/3IN/SQR/STD	3	Square mounting plate	96
66142	ACC/3/VAPOR BARRIER/STD	3 5/8	Vapor barrier extender	50
66048	ACC/MPLATE/3.5IN/SQR/STD	3 1/2	Square mounting plate	96
66047	ACC/MPLATE/3.25IN/SQR/STD	3 1/4	Square mounting plate	96
66054	ACC/MPLATE/3.25IN/ADJ/STD	3 1/4	Adjustable mounting plate	24
62673	ACC/MPLATE/3.25IN/HANG.BARS/STD	3 1/4	Mounting plate with hanger bars	20
66050	ACC/MPLATE/3.75IN/SQR/STD	3 3/4	Square mounting plate	96
62771	ACC/MPLATE/3.75IN/HANG.BARS/STD	3 3/4	Mounting plate with hanger bars	20
66143	ACC/4/VAPOR BARRIER/STD	4 1/4	Vapor barrier extender	50
62672	ACC/INSULATED BOX/3_4.5/STD	3 to 4 1/2	Insulated box with hanger bars	4



Lumen values are derived from photometric testing. For a complete list of compatible dimmers, please visit www.standardpro.com. Lumeina 9 W can be used in insulated ceilings only when combined with the insulated box (62672).





64731



64733



64735



64741



64742



64732



64734



64736



64737



64743

Trims

Order code	Description	Type	Colour	Diameter		Cutting diameter		Compatible mounting plate	Compatible vapor barrier	Case qty (master)
				(in.)	(mm)	(in.)	(mm)			
IC (can be used in insulated ceiling)										
64731	LUMEINA/TRIM/GMB.REC/WH/STD	Gimbal	White	3 17/32	90	3	77	66046	66142	50
64733	LUMEINA/TRIM/GMB.BAF/WH/STD	Gimbal	White	4 1/8	105	3 1/2	89	66048	66143	50
64735	LUMEINA/TRIM/SQR_RND/GMB/WH/SM/STD	Gimbal	White	4 7/16	113	3 1/8	80	62673, 66047, 66054	66143	50
64741	LUMEINA/TRIM/GMB.CURVED/WH/STD	Gimbal	White	4 11/32	110	3 3/4	95	66050, 62771	66143	50
64742	LUMEINA/TRIM/SQR_RND/GMB/WH/LRG/STD	Gimbal	White	4 7/16	113	3 3/4	95	66050, 62771	66143	50
64732 ^{1,2}	LUMEINA/TRIM/SWR/WH/STD	Shower	White	3 17/32	90	3	77	66046	66142	50
64734	LUMEINA/TRIM/D.BAF/WH/STD	Deep baffle	White	3 15/16	100	3 1/2	89	66048	66143	50
64736	LUMEINA/TRIM/SQR_RND/REC/WH/STD	Recessed	White	3 5/32	80	2 3/4	70	66020, 66021, 66819	66142	50
64737	LUMEINA/TRIM/CURVED/WH/STD	Curved	White	3 1/16	78	2 3/4	70	66020, 66021, 66819	66142	50
Non-IC Accessory (not for use in insulated ceiling)										
64743	LUMEINA/TRIMEXT/STD	Trim extension	White	1 31/32	50	-	-	-	-	50



64738



64739



64740

Order code	Description	Type	Colour	Diameter		Cutting diameter		Compatible mounting plate	Compatible vapor barrier	Case qty (master)
			Trim / Baffle	(in.)	(mm)	(in.)	(mm)			

Non-IC (not for use in insulated ceiling)

64738	LUMEINA/TRIM/RFL_WH/STD	Reflector	White / Chrome	3 17/32	90	3	77	66046	66142	50
64739	LUMEINA/TRIM/RFL_SLV/STD	Reflector	Silver / Chrome	3 17/32	90	3	77	66046	66142	50
64740	LUMEINA/TRIM/RFL_BLK/STD	Reflector	Black / Chrome	3 17/32	90	3	77	66046	66142	50



AIRTIGHT



DRY

IP65
RATING5
YEARS
WARRANTY



LED Commercial


The commercial LCR downlight series is your best solution for an easy conversion of existing downlights to energy efficient LED. By using the LCR series to enhance your space, it provides a crisp light output while retaining a minimalist architectural look. A quick and simple retrofit solution for replacing existing CFL, HID, or incandescent luminaires without removing the existing frame.




Order code	Description	Watts	Volts	Colour temp.	Lumen output	CRI	Life L70 (hrs)	Beam angle (°)	Traditional equivalent (W)		Finish	Case qty (master)
		(W)	(VAC)	(K)	(lm)				CFL	HID		
6"												
64972	LCR/DL6/18W/35K/2/DD1/STD	18	120-277	3 500	1 611	80	54 000	52	36	-	Silver	1
64973	LCR/DL6/18W/40K/2/DD1/STD	18	120-277	4 000	1 624	80	54 000	52	36	-	Silver	1
64974	LCR/DL6/27W/35K/2/DD1/STD	27	120-277	3 500	2 348	80	54 000	52	57	-	Silver	1
64975	LCR/DL6/27W/40K/2/DD1/STD	27	120-277	4 000	2 366	80	54 000	52	57	-	Silver	1
8"												
64976	LCR/DL8/18W/35K/2/DD1/STD	18	120-277	3 500	1 653	80	54 000	52	36	-	Silver	1
64977	LCR/DL8/18W/40K/2/DD1/STD	18	120-277	4 000	1 678	80	54 000	52	36	-	Silver	1
64978	LCR/DL8/27W/35K/2/DD1/STD	27	120-277	3 500	2 433	80	54 000	52	57	-	Silver	1
64979	LCR/DL8/27W/40K/2/DD1/STD	27	120-277	4 000	2 471	80	54 000	52	57	-	Silver	1
64980	LCR/DL8/40W/40K/2/DD1/STD	40	120-277	4 000	3 587	80	54 000	52	-	100	Silver	1
10"												
64981	LCR/DL10/54W/40K/2/DD1/STD	54	120-277	4 000	4 884	80	54 000	52	-	150	Silver	1

Housing Compatibility

Model	Minimum housing dimensions (in.)	Maximum housing dimensions (in.)
6"	6	6 11/16
8"	7 25/32	8 7/8
10"	10	10 23/32

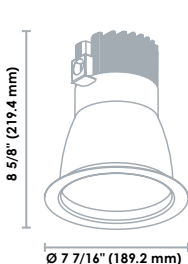


6"

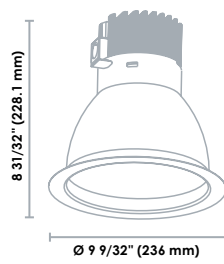

8"



10"

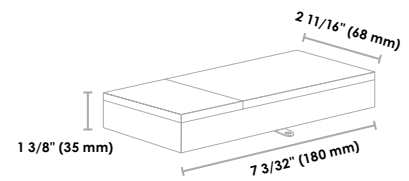

LED Driver

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com





LED Veloce™



The range of Veloce™ LED downlights is an ideal solution to replace fixtures in existing installations as well as for use in new construction. As it operates on a 1-10 V dimming system, this series is best suited for commercial applications.

This series is available in 4", 6", and 8" replacement options, and it does not require the use of a housing. The LED module is fitted with an external dimmable driver and is mounted into the ceiling using torsion springs.

- High light output
- Defined beam with the clear lens (45°) or diffused lighting with the frost lens (70°)
- Anti-glare reflector design
- Variety of interchangeable reflectors and baffles

LED Veloce™ 4



01

Order code	Description	Watts	Volts	Colour temp.	Lumen output	CRI	Life L70	Beam angle	CBCP	Baffle colour	Traditional equivalent (W)		Case qty
		(W)	(VAC)	(K)	(lm)		(hrs)	(°)	(cd)		CFL	HID	(master)
Clear Lens													
64744	VELOCE4/MOD/13W/30K/45/SLV/STD	13	120-277	3 000	1 160	90	50 000	45	1 648	Silver	26	20	4
64750	VELOCE4/MOD/13W/30K/45/BLK/STD	13	120-277	3 000	1 160	90	50 000	45	1 648	Black	26	20	4
64756	VELOCE4/MOD/13W/30K/45/WH/STD	13	120-277	3 000	1 160	90	50 000	45	1 648	White	26	20	4
64745	VELOCE4/MOD/13W/35K/45/SLV/STD	13	120-277	3 500	1 160	90	50 000	45	1 781	Silver	26	20	4
64751	VELOCE4/MOD/13W/35K/45/BLK/STD	13	120-277	3 500	1 160	90	50 000	45	1 781	Black	26	20	4
64757	VELOCE4/MOD/13W/35K/45/WH/STD	13	120-277	3 500	1 160	90	50 000	45	1 781	White	26	20	4
64746	VELOCE4/MOD/13W/40K/45/SLV/STD	13	120-277	4 000	1 160	90	50 000	45	1 756	Silver	26	20	4
64752	VELOCE4/MOD/13W/40K/45/BLK/STD	13	120-277	4 000	1 160	90	50 000	45	1 756	Black	26	20	4
64758	VELOCE4/MOD/13W/40K/45/WH/STD	13	120-277	4 000	1 160	90	50 000	45	1 756	White	26	20	4
Frost Lens													
64747	VELOCE4/MOD/F/13W/30K/70/SLV/STD	13	120-277	3 000	960	90	50 000	70	599	Silver	26	20	4
64753	VELOCE4/MOD/F/13W/30K/70/BLK/STD	13	120-277	3 000	960	90	50 000	70	599	Black	26	20	4
64759	VELOCE4/MOD/F/13W/30K/70/WH/STD	13	120-277	3 000	960	90	50 000	70	599	White	26	20	4
64748	VELOCE4/MOD/F/13W/35K/70/SLV/STD	13	120-277	3 500	960	90	50 000	70	624	Silver	26	20	4
64754	VELOCE4/MOD/F/13W/35K/70/BLK/STD	13	120-277	3 500	960	90	50 000	70	624	Black	26	20	4
64760	VELOCE4/MOD/F/13W/35K/70/WH/STD	13	120-277	3 500	960	90	50 000	70	624	White	26	20	4
64749	VELOCE4/MOD/F/13W/40K/70/SLV/STD	13	120-277	4 000	960	90	50 000	70	643	Silver	26	20	4
64755	VELOCE4/MOD/F/13W/40K/70/BLK/STD	13	120-277	4 000	960	90	50 000	70	643	Black	26	20	4
64761	VELOCE4/MOD/F/13W/40K/70/WH/STD	13	120-277	4 000	960	90	50 000	70	643	White	26	20	4

LED Driver


	System watts (W)	Max. load (W)	Input volts (VAC)	Output volts (VDC)	Input current (mA)
Veloce 4	16	18	120-277	30-42	350



Ø 3 17/32" (90 mm) up to
Ø 4 1/4" (100 mm)

Accessories

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
66051	ACC/MPLATE/4.25IN/SQR/STD	4 1/4	Mounting plate	100
66058	ACC/MPLATE/4.25IN/ADJ/STD	4 1/4	Adjustable mounting plate	50
62678	ACC/MPLATE/4.25IN/HANG.BARS/STD	4 1/4	Mounting plate with hanger bars	20
62672	ACC/INSULATED BOX/3_4.5/STD	3 to 4 1/2	Insulated box with hanger bars	4
66143	ACC/4/VAPOR BARRIER/STD	4 1/4	Vapor barrier extender	50

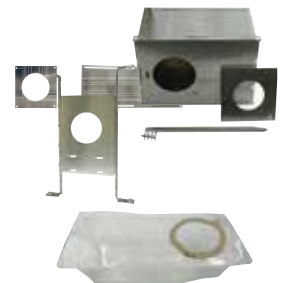

Lumen values are derived from photometric testing.
For a complete list of compatible dimmers, please visit www.standardpro.com

01 LED Veloce™ 6



Order code	Description	Watts	Volts	Colour temp.	Lumen output	CRI	Life L70	Beam angle	CBCP	Baffle colour	Traditional equivalent (W)		Case qty
		(W)	(VAC)	(K)	(lm)		(hrs)	(°)	(cd)		CFL	HID	(master)

Clear Lens

64762	VELOCE6/MOD/18W/35K/45/SLV/STD	18	120-277	3 500	2 030	90	50 000	45	2 328	Silver	2 x 26	30	4
64766	VELOCE6/MOD/18W/35K/45/BLK/STD	18	120-277	3 500	2 030	90	50 000	45	2 328	Black	2 x 26	30	4
64770	VELOCE6/MOD/18W/35K/45/WH/STD	18	120-277	3 500	2 030	90	50 000	45	2 328	White	2 x 26	30	4
64763	VELOCE6/MOD/18W/40K/45/SLV/STD	18	120-277	4 000	2 030	90	50 000	45	2 364	Silver	2 x 26	30	4
64767	VELOCE6/MOD/18W/40K/45/BLK/STD	18	120-277	4 000	2 030	90	50 000	45	2 364	Black	2 x 26	30	4
64771	VELOCE6/MOD/18W/40K/45/WH/STD	18	120-277	4 000	2 030	90	50 000	45	2 364	White	2 x 26	30	4
64774	VELOCE6/MOD/26W/35K/45/SLV/STD	26	120-277	3 500	2 750	90	50 000	45	3 121	Silver	2 x 32	50	4
64778	VELOCE6/MOD/26W/35K/45/BLK/STD	26	120-277	3 500	2 750	90	50 000	45	3 121	Black	2 x 32	50	4
64782	VELOCE6/MOD/26W/35K/45/WH/STD	26	120-277	3 500	2 750	90	50 000	45	3 121	White	2 x 32	50	4
64775	VELOCE6/MOD/26W/40K/45/SLV/STD	26	120-277	4 000	2 750	90	50 000	45	3 237	Silver	2 x 32	50	4
64779	VELOCE6/MOD/26W/40K/45/BLK/STD	26	120-277	4 000	2 750	90	50 000	45	3 237	Black	2 x 32	50	4
64783	VELOCE6/MOD/26W/40K/45/WH/STD	26	120-277	4 000	2 750	90	50 000	45	3 237	White	2 x 32	50	4

Frost Lens

64764	VELOCE6/MOD/F/18W/35K/70/SLV/STD	18	120-277	3 500	1 860	90	50 000	70	980	Silver	2 x 26	30	4
64768	VELOCE6/MOD/F/18W/35K/70/BLK/STD	18	120-277	3 500	1 860	90	50 000	70	980	Black	2 x 26	30	4
64772	VELOCE6/MOD/F/18W/35K/70/WH/STD	18	120-277	3 500	1 860	90	50 000	70	980	White	2 x 26	30	4
64765	VELOCE6/MOD/F/18W/40K/70/SLV/STD	18	120-277	4 000	1 860	90	50 000	70	959	Silver	2 x 26	30	4
64769	VELOCE6/MOD/F/18W/40K/70/BLK/STD	18	120-277	4 000	1 860	90	50 000	70	959	Black	2 x 26	30	4
64773	VELOCE6/MOD/F/18W/40K/70/WH/STD	18	120-277	4 000	1 860	90	50 000	70	959	White	2 x 26	30	4
64776	VELOCE6/MOD/F/26W/35K/70/SLV/STD	26	120-277	3 500	2 500	90	50 000	70	1 331	Silver	2 x 32	50	4
64780	VELOCE6/MOD/F/26W/35K/70/BLK/STD	26	120-277	3 500	2 500	90	50 000	70	1 331	Black	2 x 32	50	4
64784	VELOCE6/MOD/F/26W/35K/70/WH/STD	26	120-277	3 500	2 500	90	50 000	70	1 331	White	2 x 32	50	4
64777	VELOCE6/MOD/F/26W/40K/70/SLV/STD	26	120-277	4 000	2 500	90	50 000	70	1 407	Silver	2 x 32	50	4
64781	VELOCE6/MOD/F/26W/40K/70/BLK/STD	26	120-277	4 000	2 500	90	50 000	70	1 407	Black	2 x 32	50	4
64785	VELOCE6/MOD/F/26W/40K/70/WH/STD	26	120-277	4 000	2 500	90	50 000	70	1 407	White	2 x 32	50	4

LED Drivers


	System watts (W)	Max. load (W)	Input volts (VAC)	Output volts (VAC)	Input current (mA)
Veloce 6 (18 W)	22	36	120-277	30-42	500
Veloce 6 (26 W)	30	36	120-277	30-42	700



Ø 6" (150 mm) up to
Ø 6 5/8" (165 mm)

Accessories

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
66817	ACC/MPLATE/VELOCE6/HANG.BARS/STD	6	Mounting plate with hanger bars	8
64263	ACC/MPLATE/6.25IN/SQR/STD	6 1/4	Mounting plate	96
64921	ACC/MPLATE/6.25IN/ADJ/STD	6 1/4	Adjustable mounting plate	24
66144	ACC/6/VAPOR BARRIER/STD	6 7/32	Vapor barrier extender	50

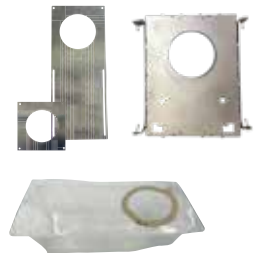

LED Veloce™ 8



Order code	Description	Watts	Volts	Colour temp.	Lumen output	CRI	Life L70	Beam angle	CBCP	Baffle colour	Traditional equivalent (W)		Case qty
		(W)	(VAC)	(K)	(lm)		(hrs)	(°)	(cd)		CFL	HID	(master)

Clear Lens

64786	VELOCE8/MOD/26W/35K/45/SLV/STD	26	120-277	3 500	2 800	90	50 000	45	2 517	Silver	2 x 32	50	4
64790	VELOCE8/MOD/26W/35K/45/BLK/STD	26	120-277	3 500	2 800	90	50 000	45	2 517	Black	2 x 32	50	4
64794	VELOCE8/MOD/26W/35K/45/WH/STD	26	120-277	3 500	2 800	90	50 000	45	2 517	White	2 x 32	50	4
64787	VELOCE8/MOD/26W/40K/45/SLV/STD	26	120-277	4 000	2 800	90	50 000	45	2 852	Silver	2 x 32	50	4
64791	VELOCE8/MOD/26W/40K/45/BLK/STD	26	120-277	4 000	2 800	90	50 000	45	2 852	Black	2 x 32	50	4
64795	VELOCE8/MOD/26W/40K/45/WH/STD	26	120-277	4 000	2 800	90	50 000	45	2 852	White	2 x 32	50	4
64798	VELOCE8/MOD/38W/40K/45/SLV/STD	38	120-277	4 000	3 950	90	50 000	45	4 092	Silver	2 x 42	70	4
64800	VELOCE8/MOD/38W/40K/45/BLK/STD	38	120-277	4 000	3 950	90	50 000	45	4 092	Black	2 x 42	70	4
64802	VELOCE8/MOD/38W/40K/45/WH/STD	38	120-277	4 000	3 950	90	50 000	45	4 092	White	2 x 42	70	4

Frost Lens

64788	VELOCE8/MOD/F/26W/35K/70/SLV/STD	26	120-277	3 500	2 490	90	50 000	70	1 468	Silver	2 x 32	50	4
64792	VELOCE8/MOD/F/26W/35K/70/BLK/STD	26	120-277	3 500	2 490	90	50 000	70	1 468	Black	2 x 32	50	4
64796	VELOCE8/MOD/F/26W/35K/70/WH/STD	26	120-277	3 500	2 490	90	50 000	70	1 468	White	2 x 32	50	4
64789	VELOCE8/MOD/F/26W/40K/70/SLV/STD	26	120-277	4 000	2 490	90	50 000	70	1 601	Silver	2 x 32	50	4
64793	VELOCE8/MOD/F/26W/40K/70/BLK/STD	26	120-277	4 000	2 490	90	50 000	70	1 601	Black	2 x 32	50	4
64797	VELOCE8/MOD/F/26W/40K/70/WH/STD	26	120-277	4 000	2 490	90	50 000	70	1 601	White	2 x 32	50	4
64799	VELOCE8/MOD/F/38W/40K/70/SLV/STD	38	120-277	4 000	3 500	90	50 000	70	2 282	Silver	2 x 42	70	4
64801	VELOCE8/MOD/F/38W/40K/70/BLK/STD	38	120-277	4 000	3 500	90	50 000	70	2 282	Black	2 x 42	70	4
64803	VELOCE8/MOD/F/38W/40K/70/WH/STD	38	120-277	4 000	3 500	90	50 000	70	2 282	White	2 x 42	70	4

LED Drivers

	System watts (W)	Max. load (W)	Input volts (VAC)	Output volts (VDC)	Input current (mA)
Veloce 8 (26 W)	30	36	120-277	30-42	700
Veloce 8 (36 W)	42	50	120-277	22-38	1 050




Ø 8 1/16" (205 mm) up to
Ø 8 11/16" (220 mm)

Accessory


Order code	Description	Opening diameter (in.)	Type	Case qty (master)
66818	ACC/MPLATE/VELOCE8/HANG.BARS/STD	8	Mounting plate with hanger bars	8




Veloce™ 4

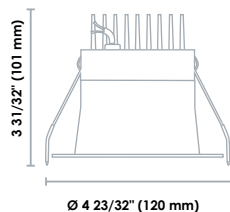


Veloce™ 6

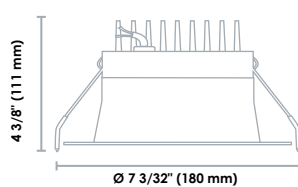

Veloce™ 8

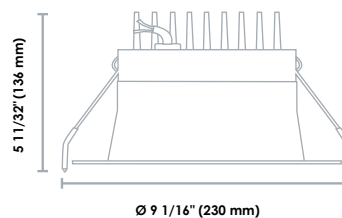

Veloce™ 4, 6 and 8 LED Driver

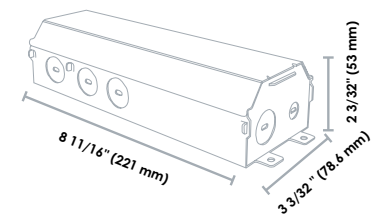

Lumen values are derived from photometric testing.
For a complete list of compatible dimmers, please visit www.standardpro.com



Traditional Recessed

We have taken our years of lighting expertise and incorporated it into our line of high quality recessed fixtures designed with ease of installation and versatile lighting options in mind. Recessed fixtures provide convenient unobtrusive general lighting for residential and commercial applications, and with STANDARD's extensive assortment of trims and housings, you can create an unparalleled look. Our wide varieties of trims suit all applications and complement every decor. Paired with Canada's largest selection of LED lamps you will be sure to find the best combination for all your lighting needs.

3" Housing



Order code	Description	Opening diameter (in.)	Volts (VAC)	Socket	Case qty (master)
Remodeler - IC / Non-IC					
63230 ¹	RF3in/REMOD/IC/GU10/STD	3	120	GU10	6

3" Trims


Compatible Lamps (MR16 GU10)



Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Recessed Die-Cast				
62700 ²	RF3/TRIM/DIECAST.REC/CHR/STD	Chrome	N/A	6/24
62701 ²	RF3/TRIM/DIECAST.REC/SAT.CHR/STD	Satin chrome	N/A	6/24
62699 ²	RF3/TRIM/DIECAST.REC/WH/STD	White	N/A	6/24
Gimbal				
62711 ²	RF3/TRIM/GMB/CHR/STD	Chrome	35	6/24
62715	RF3/TRIM/GMB/SAT.CHR/STD	Satin chrome	35	6/24
62703 ²	RF3/TRIM/GMB/WH/STD	White	35	6/24
62719 ²	RF3/TRIM/GMB/BLK/STD	Black	35	6/24
62707 ²	RF3/TRIM/GMB/ORB/STD	Oil rubbed bronze	35	6/24
Gimbal				
62710 ²	RF3/TRIM/SQR/GMB/CHR/STD	Chrome	35	6/24
62714 ²	RF3/TRIM/SQR/GMB/SAT.CHR/STD	Satin chrome	35	6/24
62702 ²	RF3/TRIM/SQR/GMB/WH/STD	White	35	6/24

Accessories

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
66047	ACC/MPLATE/3.25IN/SQR/STD	3 1/4	Square mounting plates	96
66054	ACC/MPLATE/3.25IN/ADJ/STD	3 1/4	Adjustable mounting plates	24
62673	ACC/MPLATE/3.25IN/HANG.BARS/STD	3 1/4	Mounting plates with hanger bars	20
66142	ACC/3/VAPOR BARRIER/STD	3 5/8	Vapor barrier extender	50

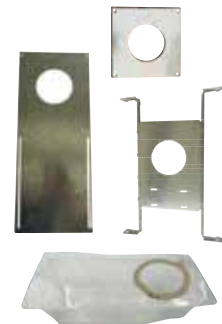

For complete warranty information, please visit www.standardpro.com

¹This housing is rated for both insulated ceilings (IC) and non-insulated ceilings (non-IC), however, only to be used with an LED lamp in an IC application.

²Safety glass included, only to be installed with an open style lamp. Not suitable for LED technology



4" Housings



Order code	Description	Opening diameter (in.)	Volts (VAC)	Socket	Case qty (master)
Remodeler					
62690	RF4in/REMOD/LOW.VOLT/GU5.3/STD	4	12	GU5.3	6
Remodeler - IC / Non-IC					
63231 ¹	RF4in/REMOD/IC/GU10/STD	4	120	GU10	6
63232 ¹	RF4in/REMOD/IC/E26/STD	4	120	E26	6
New Construction					
62685	RF4in/NC/NON-IC/LOW.VOLT/GU5.3/STD	4	12	GU5.3	6
New Construction - IC / Non-IC					
64335 ¹	RF4in/NC/IC_NON-IC/E26/STD	4	120	E26	4
64336 ¹	RF4in/NC/IC_NON-IC/GU10/STD	4	120	GU10	4
New Construction - IC Airtight					
62682	RF4in/NC/IC/LOW.VOLT/GU5.3/STD	4	12	GU5.3	4
62681	RF4in/NC/IC/GU10/STD	4	120	GU10	4
62680	RF4in/NC/IC/E26/STD	4	120	E26	4

4" Trims

Compatible Lamp (PAR20)


Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Gimbal				
62713	RF4/TRIM/GMB/CHR/PAR20/STD	Chrome	35	6/24
62717	RF4/TRIM/GMB/SAT.CHR/PAR20/STD	Satin chrome	35	6/24
62705	RF4/TRIM/GMB/WH/PAR20/STD	White	35	6/24
62721	RF4/TRIM/GMB/BLK/PAR20/STD	Black	35	6/24
62709	RF4/TRIM/GMB/ORB/PAR20/STD	Oil rubbed bronze	35	6/24
Slim Line				
62743	RF4/TRIM/SLML/CHR/PAR20/STD	Chrome	N/A	6/24
62744	RF4/TRIM/SLML/SAT.CHR/PAR20/STD	Satin chrome	N/A	6/24
62742	RF4/TRIM/SLML/WH/PAR20/STD	White	N/A	6/24
Recessed				
62752	RF4/TRIM/REC/SAT.CHR_ALU/PAR20/STD	Satin chrome / Aluminum	N/A	6/24
62753	RF4/TRIM/REC/SAT.CHR_BLK/PAR20/STD	Satin chrome / Black	N/A	6/24
62751	RF4/TRIM/REC/WH_BLK/PAR20/STD	White / Black	N/A	6/24
62750	RF4/TRIM/REC/WH_CHR/PAR20/STD	White / Chrome	N/A	6/24
62749	RF4/TRIM/REC/WH_WH/PAR20/STD	White / White	N/A	6/24
63393	RF4/TRIM/REC/BLK_BLK/PAR20/STD	Black / Black	N/A	6/24



For complete warranty information, please visit www.standardpro.com
¹ This housing is rated for both insulated ceilings (IC) and non-insulated ceilings (non-IC), however, only to be used with an LED lamp in an IC application

4" Shower Trims


Compatible Lamp (PAR20)

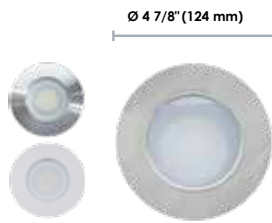


Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Shower				
62739 ¹	RF4/TRIM/SWR/CHR/PAR20/STD	Chrome	N/A	6/24
62741 ¹	RF4/TRIM/SWR/SAT.CHR/PAR20/STD	Satin chrome	N/A	6/24
62737 ¹	RF4/TRIM/SWR/WH/PAR20/STD	White	N/A	6/24

4" Trims


Compatible Lamps (MR16 GU10, GU5.3, E26, PAR16)

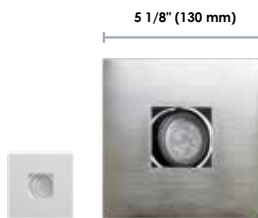

Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Gimbal				
62716 ²	RF4/TRIM/SQR/GMB/SAT.CHR/MR16/STD	Satin chrome	35	6/24
62704 ²	RF4/TRIM/SQR/GMB/WH/MR16/STD	White	35	6/24

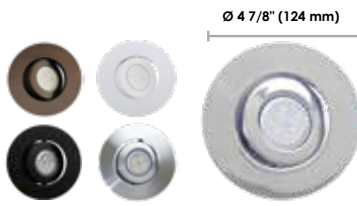

Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Gimbal				
62712 ²	RF4/TRIM/GMB/CHR/MR16/STD	Chrome	35	6/24
62718 ²	RF4/TRIM/GMB/SAT.CHR/MR16/STD	Satin chrome	35	6/24
62706 ²	RF4/TRIM/GMB/WH/MR16/STD	White	35	6/24
62720 ²	RF4/TRIM/GMB/BLK/MR16/STD	Black	35	6/24
62708 ²	RF4/TRIM/GMB/ORB/MR16/STD	Oil rubbed bronze	35	6/24

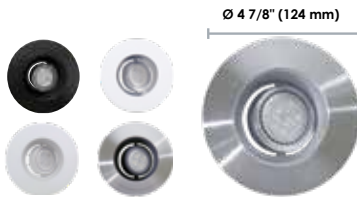

Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Recessed Gimbal				
62724 ²	RF4/TRIM/GMB.REC/SAT.CHR&AL/MR16/STD	Satin chrome / Satin aluminum	35	6/24
62725 ²	RF4/TRIM/GMB.REC/SAT.CHR_BLK/MR16/STD	Satin chrome / Black	35	6/24
62723 ²	RF4/TRIM/GMB.REC/WH_CHR/MR16/STD	White / Chrome	35	6/24
62722 ²	RF4/TRIM/GMB.REC/WH_WH/MR16/STD	White / White	35	6/24
63394 ²	RF4/TRIM/GMB.REC/BLK_BLK/MR16/STD	Black / Black	35	6/24



Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Wall Washer				
62755 ²	RF4/TRIM/SLIT/CHR/MR16/STD	Chrome	N/A	6/24
62756 ²	RF4/TRIM/SLIT/SAT.CHR/MR16/STD	Satin chrome	N/A	6/24
62754 ²	RF4/TRIM/SLIT/WH/MR16/STD	White	N/A	6/24



Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Retractable Elbow (MR16 GU53 lamps only)				
62758 ²	RF4/TRIM/RETRACT.ELB/CHR/MR16/STD	Chrome	80	6/24
62757 ²	RF4/TRIM/RETRACT.ELB/SAT.CHR/MR16/STD	Satin chrome	80	6/24
62759 ²	RF4/TRIM/RETRACT.ELB/WH/MR16/STD	White	80	6/24



DAMP



MAX. LAMP WATTAGE



EXTENDED WARRANTY



WARRANTY



UL LISTED


For complete warranty information, please visit www.standardpro.com

¹ Not recommended for use in steam showers or when directly exposed to water

² Safety glass included, only to be installed with an open lamp. Not suitable for LED technology

4" Shower Trims


Compatible Lamps (MR16 GU10, GU5.3, E26 and PAR16)

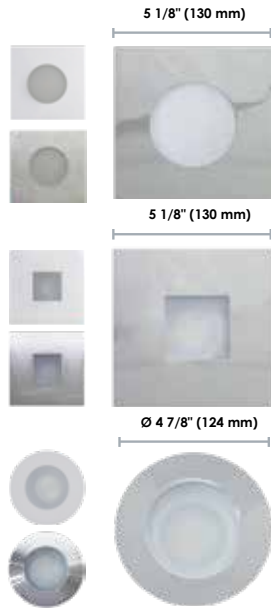

Order code	Description	Finish	Rotation angle (°)	Case qty (inner/master)
Shower				
62731 ¹	RF4/TRIM/SWR/SQR/CHR/MR16/STD	Chrome	N/A	6/24
62732 ¹	RF4/TRIM/SWR/SQR/SAT.CHR/MR16/STD	Satin chrome	N/A	6/24
62730 ¹	RF4/TRIM/SWR/SQR/WH/MR16/STD	White	N/A	6/24
Shower				
62734 ¹	RF4/TRIM/SWR/SQR_SQR/CHR/MR16/STD	Chrome	N/A	6/24
62735 ¹	RF4/TRIM/SWR/SQR_SQR/SAT.CHR/MR16/STD	Satin chrome	N/A	6/24
62733 ¹	RF4/TRIM/SWR/SQR_SQR/WH/MR16/STD	White	N/A	6/24
Shower				
62738 ¹	RF4/TRIM/SWR/CHR/MR16/STD	Chrome	N/A	6/24
62740 ¹	RF4/TRIM/SWR/SAT.CHR/MR16/STD	Satin chrome	N/A	6/24
62736 ¹	RF4/TRIM/SWR/WH/MR16/STD	White	N/A	6/24

Accessories

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
66051	ACC/MPLATE/4.25/SQR/STD	4 1/4	Square mounting plate	96
62677	ACC/MPLATE/4.25IN/ADJ/STD	4 1/4	Adjustable mounting plate	100
62678	ACC/MPLATE/4.25IN/HANG.BARS/STD	4 1/4	Mounting plate with hanger bars	25
62679	ACC/VAPOR BARRIER/STD	-	Vapor barrier extender	25
66143	ACC/4/VAPOR BARRIER/STD	4 1/4	Vapor barrier extender	50

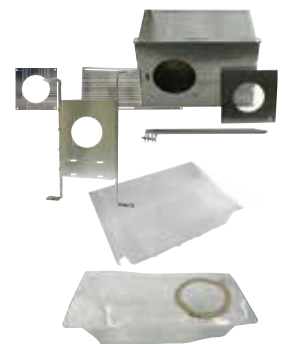

For complete warranty information, please visit www.standardpro.com
¹ Not recommended for use in steam showers or when directly exposed to water



5" Housings



Order code	Description	Opening diameter (in.)	Volts (VAC)	Socket	Case qty (master)
Remodeler - IC Airtight					
64365	RF5in/REM0D/IC/E26/STD	5	120	E26	6
New Construction - IC Airtight					
64366	RF5in/NC/IC/E26/STD	5	120	E26	6

5" Trims

Compatible Lamps (PAR30SN, PAR30LN)



Order code	Description	Finish	Rotation angle (°)	Case qty (master)
Cone - Airtight				
64390	RF5/TRIM/CONE/BLK/PAR30/STD	Black	N/A	24
64391	RF5/TRIM/CONE/BR.NKL/PAR30/STD	Brushed nickel	N/A	24
64392	RF5/TRIM/CONE/WH/PAR30/STD	White	N/A	24
Gimbal				
64393	RF5/TRIM/GMB/BLK/PAR30/STD	Black	30	24
64394	RF5/TRIM/GMB/BR.NKL/PAR30/STD	Brushed nickel	30	24
64395	RF5/TRIM/GMB/WH/PAR30/STD	White	30	24
Reflector				
65525	RF5/TRIM/CONE/RFL_WH/PAR30/STD	White/Chrome	N/A	24
Shower				
65524 ¹	RF5/TRIM/SWR/WH/PAR30/STD	White	N/A	24

Accessory

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
62679	ACC/VAPOR BARRIER/STD	-	Vapor barrier extender	25



DAMP



MAX LAMP WATTAGE



EXTENDED WARRANTY



1 YEAR WARRANTY



UL US

For complete warranty information, please visit www.standardpro.com
¹ Not recommended for use in steam showers or when directly exposed to water


6" Housings



Order code	Description	Opening diameter (in.)	Volts (VAC)	Socket	Case qty (master)
Remodeler - IC Airtight					
64367 ¹	RF6in/REM0D/IC/E26/STD	6	120	E26	6
New Construction - IC Airtight					
64368 ²	RF6in/NC/IC/E26/STD	6	120	E26	6

6" Trims


Compatible Lamp (PAR38)

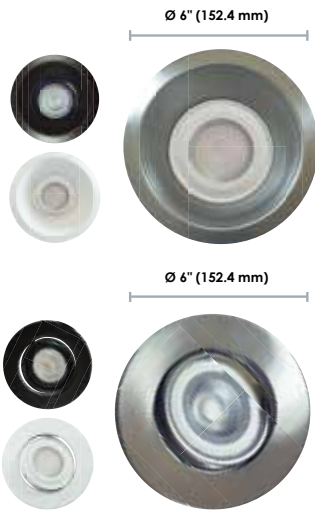

Order code	Description	Finish	Rotation angle (°)	Case qty (master)
Cone - Airtight				
64396	RF6/TRIM/CONE/BLK/PAR38/STD	Black	N/A	24
64397	RF6/TRIM/CONE/BR.NKL/PAR38/STD	Brushed nickel	N/A	24
64398	RF6/TRIM/CONE/WH/PAR38/STD	White	N/A	24
Gimbal				
64399	RF6/TRIM/GMB/BLK/PAR38/STD	Black	30	24
64400	RF6/TRIM/GMB/BR.NKL/PAR38/STD	Brushed nickel	30	24
64401	RF6/TRIM/GMB/WH/PAR38/STD	White	30	24

Accessories

Order code	Description	Opening diameter (in.)	Type	Case qty (master)
64921	ACC/MPLATE/6.25IN/ADJ/STD	6 1/4	Adjustable mounting plate	24
64263	ACC/MPLATE/6.25IN/SQR/STD	6 1/4	Square mounting plate	96
62679	ACC/VAPOR BARRIER/STD	-	Vapor barrier extender	25

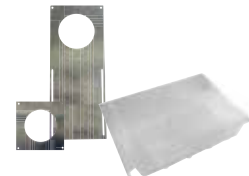

3 1/2" Outdoor Soffits


Compatible Lamps (PAR20¹, R20¹)



Order code	Description	Finish	Opening diameter (in.)	Volts (VAC)	Socket	Case qty (master)
Housings						
62691	RF3.5in/OUT.SOF/BLK/E26/STD	Black	3 1/2	120	E26	12
62692	RF3.5in/OUT.SOF/BRN/E26/STD	Brown	3 1/2	120	E26	12
62693	RF3.5in/OUT.SOF/CLAY/E26/STD	Clay	3 1/2	120	E26	12
62694	RF3.5in/OUT.SOF/WH/E26/STD	White	3 1/2	120	E26	12

Accessories

Order code	Description	Type	Finish	Opening diameter (in.)	Case qty (master)
62668	RF/ACC/BAF/3.5/BLK/OUT.SOF/STD	Baffle	Black	3 1/2	50
62669	RF/ACC/BAF/3.5/WH/OUT.SOF/STD	Baffle	White	3 1/2	50
62771	ACC/MPLATE/3.75IN/HANG.BARS/STD	Mounting plate with hanger bars	-	3 3/4	25
66050	ACC/MPLATE/3.75IN/SQR/STD	Square mounting plate	-	3 3/4	96

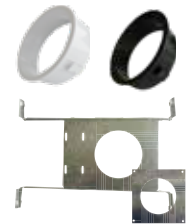

4 1/2" Outdoor Soffits

Compatible Lamps (BR30², PAR30³)



Order code	Description	Finish	Opening diameter (in.)	Volts (VAC)	Socket	Case qty (master)
Housings						
62695	RF4.5in/OUT.SOF/BLK/E26/STD	Black	4 1/2	120	E26	12
62696	RF4.5in/OUT.SOF/BRN/E26/STD	Brown	4 1/2	120	E26	12
62697	RF4.5in/OUT.SOF/CLAY/E26/STD	Clay	4 1/2	120	E26	12
62698	RF4.5in/OUT.SOF/WH/E26/STD	White	4 1/2	120	E26	12

Accessories

Order code	Description	Type	Finish	Opening diameter (in.)	Case qty (master)
62670	RF/ACC/BAF/4.5/BLK/OUT.SOF/STD	Baffle	Black	4 1/2	50
62671	RF/ACC/BAF/4.5/WH/OUT.SOF/STD	Baffle	White	4 1/2	50
62772	ACC/MPLATE/4.75IN/HANG.BARS/STD	Mounting plate with hanger bars	-	4 3/4	25
66052	ACC/MPLATE/4.75IN/SQR/STD	Square mounting plate	-	4 3/4	96



Remodeler Kits

Lamp colour matches the trim colour



Order code	Description	Size (in.)	Finish	Case qty (master)
63166	K/RF3/GU10/GMB/WH/LED/STD	3	White	6
63483	K/RF3/GU10/GMB/SAT.CHR/LED/STD	3	Satin Chrome	6
63474	K/RF4/PAR20/GMB/WH/LED/STD	4	White	6
63475	K/RF4/PAR20/GMB/SAT.CHR/LED/STD	4	Satin Chrome	6
63476	K/RF4/GU10/GMB/WH/LED/STD	4	White	6
63477	K/RF4/GU10/GMB/SAT.CHR/LED/STD	4	Satin Chrome	6

Shower Kits

Designed to handle humid environments



Order code	Description	Size (in.)	Finish	Case qty (master)
64480	K/RF4/P16/SWR/CHR/LED/STD	4	Chrome	6
64481	K/RF4/P16/SWR/WH/LED/STD	4	White	6
64482	K/RF4/P16/SWR/SAT.CHR/LED/STD	4	Satin Chrome	6

New Construction Kit



Order code	Description	Size (in.)	Finish	Case qty (master)
64497	K/RF4/NC/PAR20/GMB/WH/LED/STD	4	White	1

Included in the box

- Galvanized steel housing
- Trim with a unique design for smooth and secure fitting
- High quality LED lamp – stable light output and long life
- Connectors, cable clamps
- Cutting template



DAMP



DIMMABLE



3 YEARS WARRANTY



5 YEARS WARRANTY



UL US



ENERGY STAR

For a complete list of ENERGY STAR qualified lamps, please visit www.standardpro.com
For complete warranty information, please visit www.standardpro.com