


**Data sheet | Item number: 216-264**

Ferrule; Sleeve for 1.5 mm<sup>2</sup> / AWG 16; insulated; electro-tin plated;  
electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; black



[www.wago.com/216-264](http://www.wago.com/216-264)

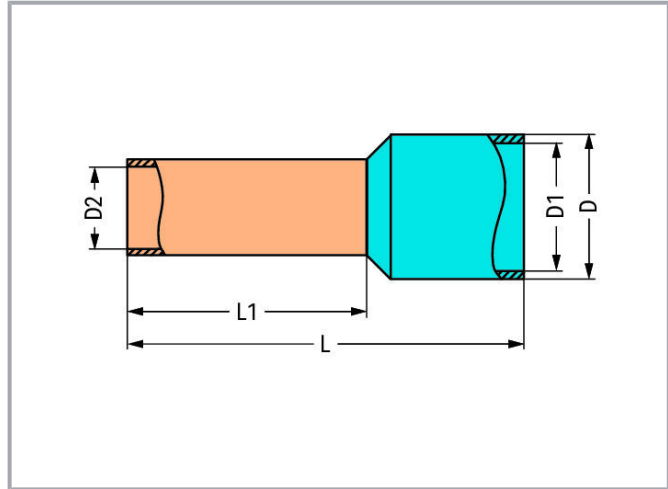

 Picture differs from the item.

Color: 

Subject to changes. Please also observe the further product documentation!

WAGO GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.



## Data

### Technical data

Main product function	Ferrule
Sleeve cross-section (AWG)	16 AWG
Sleeve for	1.5 mm <sup>2</sup>

### Connection data

Strip length	14 mm / 0.55 inch
--------------	-------------------

### Physical data

Length	18 mm
Length 1	12 mm
Diameter	4 mm
Diameter 1	3.5 mm
Diameter 2	1.7 mm

### Mechanical data

Suitable	2002 to 2006 Series
----------	---------------------

### Material data

Color	black
Fire load	0.001 MJ
Weight	0.1 g

### Commercial data

Product Group	2 (Terminal Block Accessories)
PU (SPU)	1000 Stück
Packaging type	box
Country of origin VKOrg Germany	DE
GTIN	4044918604291
Customs tariff number VKOrg Germany	85369010000

Subject to changes. Please also observe the further product documentation!

WAGO GmbH & Co. KG  
 Hansastr. 27  
 32423 Minden  
 Phone: +49571 887-0 | Fax: +49571 887-169  
 Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
 We are always happy to take your call at +49 (571) 887-44222.



## Downloads Documentation

### Bid Text

 
216-264 X81 - Datei	Feb 19, 2019	xml 2.9 kB	Download
216-264 doc - Datei	Sep 11, 2017	doc 24.1 kB	Download

## Environmental Product Compliance

### Compliance Search

Environmental Product Compliance 216-264 Ferrule; Sleeve for 1.5 mm <sup>2</sup> / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; black	URL	Download
--	-----	----------

## Installation Notes



A perfect gas-tight crimp – both electrically and mechanically reliable

Subject to changes. Please also observe the further product documentation!