



BURNDY Catalog Number
UPC Number
Description
Status

YSP39T
7818100013499
750 CU HV SPLICE
Active

Web Use
BURNDY Product Line

Strip Length
Barrell Style
Barrel Type

Dimensional

2-1/8
Tapered
Standard

General

Uninsulated high voltage Cu -code
compression splice, Tapered end,
750 kcmil, 600V-35KV, Tin plated,
24 Index


Physical

Tin - Electro Plated
Y
24
Copper

Approvals / Certifications

Y
Y
Compliant
N
N

Product Description

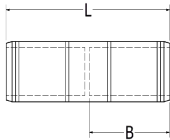

Type of Plating
Plated (Yes or No)
Index Number
Product Material

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
Monday - Friday
Phone: 800-346-4175