




BURNDY Catalog Number
UPC Number
Description
Status

GD2129
 7818102604322
 2/0SOL-250, 3 1/2 IPS,
 Active

Web Use
 BURNDY Product Line

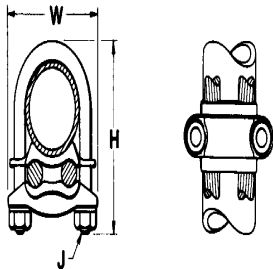

Dimensional	
Width (in)	5.31
Height (in)	6.25
Size (Hex) or Size (Bolt)	3/8
Size (Hex) or Size (Bolt) - in	0.38
Width (Fraction)	5-3/8
Height (Fraction) (in)	6-1/4
General	
Product Description	Mechanical Grounding Connector, 2 Parallel Cables to Rod or Pipe, 2/0 AWG (Sol.) - 250 kcmil, 3-1/2" to 4" Rod, 3-1/2" Pipe
Conductor(s)	
Copper Tube Size (SCH40) - Range	3-1/2
Rod Size (Range)	N/A
Copper Solid Size (Range)	2/0-4/0
Copper Stranded (Range)	2/0-250
Physical	
Installation Torque	240
Type of Plating	Unplated
Plated (Yes or No)	N
Product Material	Copper Alloy
Approvals / Certifications	
UL Listed	Y
CSA Certified	N
ROHS Compatible	Exempt
UL Recognized	N
CULUS	N
Industry Standards	UL467
Rated for Direct Burial	Y
Documentation	

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175