




**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

GD2226  
 7818102604633  
 4SOL-2/0STR, 4IPS, 2 CO  
 Active

**Web Use**  
 BURNDY Product Line

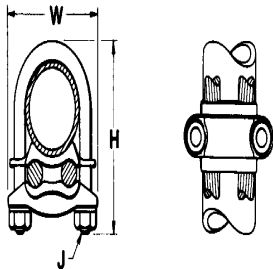

Dimensional	
Width (in)	5.81
Height (in)	6.38
Size (Hex) or Size (Bolt)	3/8
Size (Hex) or Size (Bolt) - in	0.38
Width (Fraction)	5-7/8
Height (Fraction) (in)	6-3/8
General	
Product Description	Mechanical Grounding Connector, 2 Parallel Cables to Rod or Pipe, 4 AWG ( Sol.) - 2/0 AWG (Str.), 4" to 4-1/2" Rod, 4" Pipe
Conductor(s)	
Copper Tube Size (SCH40) - Range	4
Rod Size (Range)	N/A
Copper Solid Size (Range)	4-2/0
Copper Stranded (Range)	4-2/0
Physical	
Installation Torque	240
Type of Plating	Unplated
Plated (Yes or No)	N
Product Material	Copper Alloy
Approvals / Certifications	
UL Listed	Y
ROHS Compatible	Exempt
Industry Standards	UL467
Rated for Direct Burial	Y
Documentation	

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175