


## CT18075C

by Burndy  
Catalog ID: CT18075C

Natural Nylon 6/6 Cable Tie, 0.75" Max. Bundle Dia, 18 Lbs, 4" Long, 0.10" Wide, Installation Tool: TWT1, MK7, CTT50.

- Standard Cable Tie
- Features: Cable Ties for General Use Available in Black or Natural, One piece injection molded, Installation Tool: TWT1, MK7 Tool

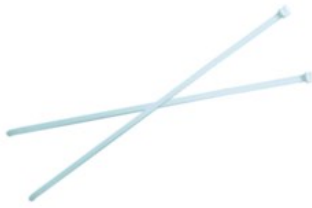

## Product Details

### General

|                                       |                     |
|---------------------------------------|---------------------|
| Application                           | For General Purpose |
| Color                                 | Natural             |
| Material                              | Nylon 6/6           |
| Military Specification                | MS3367              |
| Operating Temperature Celcius Max     | 85 °C               |
| Operating Temperature Celcius Min     | -40 °C              |
| Rating - Minimum Tensile Strength lbs | 18                  |
| Sub Brand                             | UNIRAP,CABLE TIE    |
| Tool Type                             | Mini                |
| Trade Name                            | UNIRAP™             |
| Type                                  | Mini                |
| UPC                                   | 781810331323        |

### Dimensions

|                                      |         |
|--------------------------------------|---------|
| Dimension - Bundle Diameter Max inch | 0.75    |
| Dimension - L Length Overall mm      | 104 mm  |
| Dimension - Length Overall inch      | 4.10 in |
| Dimension - Width inch               | 0.10 in |
| Dimension - Width mm                 | 2.5 mm  |

### Certifications and Compliance

|                                    |                               |
|------------------------------------|-------------------------------|
| Certification - 94V0 Rated         | N                             |
| Certification - CSA Approved       | No                            |
| Certification - ETL                | No                            |
| Certification - UL Recognized      | No                            |
| Certification - UV Rated           | No                            |
| Certification - cULus              | No                            |
| Industry Standard(s)               | Military Specified (Mil-Spec) |
| Military Spec Number               | MS3367-4-9                    |
| Standards - Industry Standards Met | Military Specified (Mil-Spec) |
| Standards - RoHS Compliance Status | CM                            |

|           |     |
|-----------|-----|
| UL Listed | Yes |
|-----------|-----|

**Logistics**

|                       |         |
|-----------------------|---------|
| Carton Quantity       | 1000 EA |
| Minimum Pack Quantity | 100     |

**For further technical assistance, please contact us**

**BURNDY Headquarters**  
47 East Industrial Park Drive  
Manchester, New Hampshire 03109

**Customer Service Hours:**  
8 AM - 8 PM Eastern Monday-Friday  
Emergency Service 24-hours/365 Days  
Phone: 1-800-346-4175  
1-603-647-5299 (International)