


**Catalog Number:** WMG-PC1  
**Product ID:** 7TAD105290R0000  
**UPC Number:** 78621076998  
**EAN Number:** 05415022461527  
**Status:** Active



Stainless Steel Wire Mesh Grip for Use with 1/2 Inch Cord Fittings, UL, CSA, Grip Range 0.187 to 0.250 Inch

- Prevents severe cord bends and pullouts.
- Used with aluminum and/or steel fittings.
- Provides high gripping strength for adequate cable support and strain relief without damage to the cable sheath.

Actual

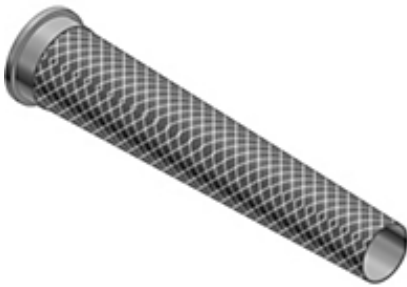

Representative

### North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Brand Name	T&B
Type	Wiremesh Grips
Special Features	Prevents Severe Cord Bends and Pullouts
Application	Provides High Gripping Strength for Adequate Cable Support and Strain Relief Without Damage to the Cable Sheath
Standard	UL E13938, CSA
Conductor Range	0.187 to 0.250 Inch
Material	Stainless Steel
Environmental Conditions	Ordinary Locations

### Packaging

Inner Quantity	5
Inner Dimensions (inches)	3.3x2.8x2.3
Outer Quantity	25
Outer Dimensions (inches)	15x3.5x2.6
Weight Uom	4.38 lbs. per 100

### Documents / Support Tools

Technical Drawing / Data Sheet	TDS000055
Technical Drawing / Data Sheet Canada	Available on Website
Instruction Sheet	TA00083-TB2

### Header

3D Model	Available on Website
----------	----------------------

**For further technical assistance, please contact us...**

ABB Installation Products - USA  
 860 Ridge Lake Blvd.  
 Memphis, TN 38120  
[www.tnb.com](http://www.tnb.com)

ABB Installation Products Technical Support  
 MS 3B-50  
 860 Ridge Lake Blvd.  
 Memphis, TN 38120

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289  
 Fax: (901) 252-1321  
 Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)