


Surge suppressor, varistor, 48 ... 127 V AC, 70 ... 150 V DC, for motor contactors Size S0

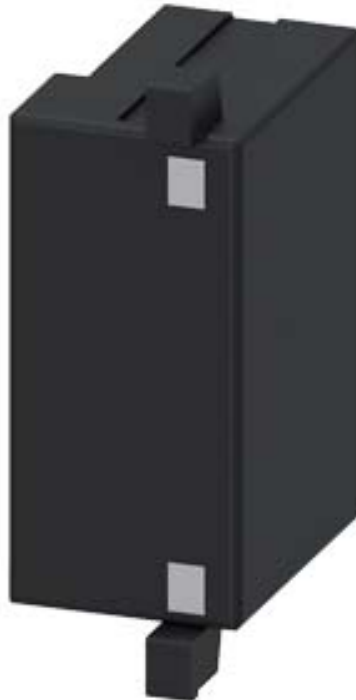

General technical data:

Product brand name		SIRIUS
Product designation		surge suppressor
Size of contactor		S0
Design of the surge suppressor		with varistor
Ambient temperature		
• during storage	°C	-40 ... +80
• during operation	°C	-25 ... +60

Control circuit/ Control:

Type of voltage of the control supply voltage		AC/DC
Control supply voltage frequency		
• 1 rated value	Hz	50
• 2 rated value	Hz	60
Control supply voltage 1		
• at DC		
— Initial rated value	V	70
— Final rated value	V	150
• at AC		

— at 50 Hz Initial rated value	V	48
— at 50 Hz Final rated value	V	127
— at 60 Hz Final rated value	V	127
— at 60 Hz Initial rated value	V	48

Installation/ mounting/ dimensions:

Mounting position		any
Mounting type		clip-on
Width	mm	30
Height	mm	19
Depth	mm	12

Certificates/ approvals:

Certificate of suitability CE / UL / CSA / CCC

General Product Approval

EMC

Declaration of Conformity



CSA



UR



RCM



EG-Konf.

[Miscellaneous](#)

Test Certificates

Shipping Approval

[Special Test Certificate](#)

[Type Test Certificates/Test Report](#)



BUREAU VERITAS



PRS



RINA



RMRS

other

Railway

[Confirmation](#)

[Vibration and Shock](#)



VDE

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrymall>

Cax online generator



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RT2926-1BC00>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RT2926-1BC00>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RT2926-1BC00&lang=en

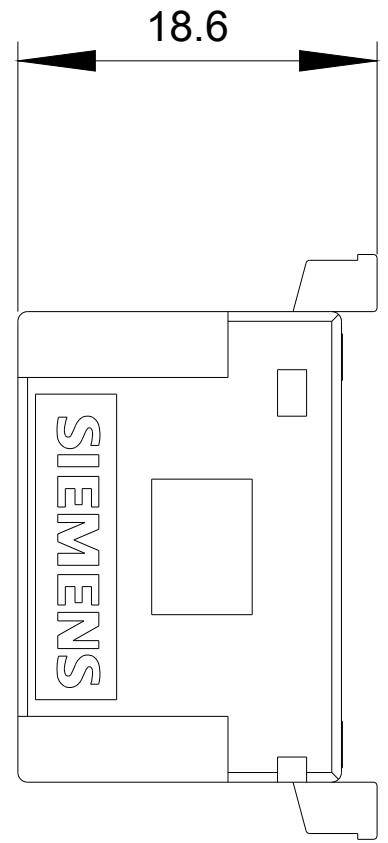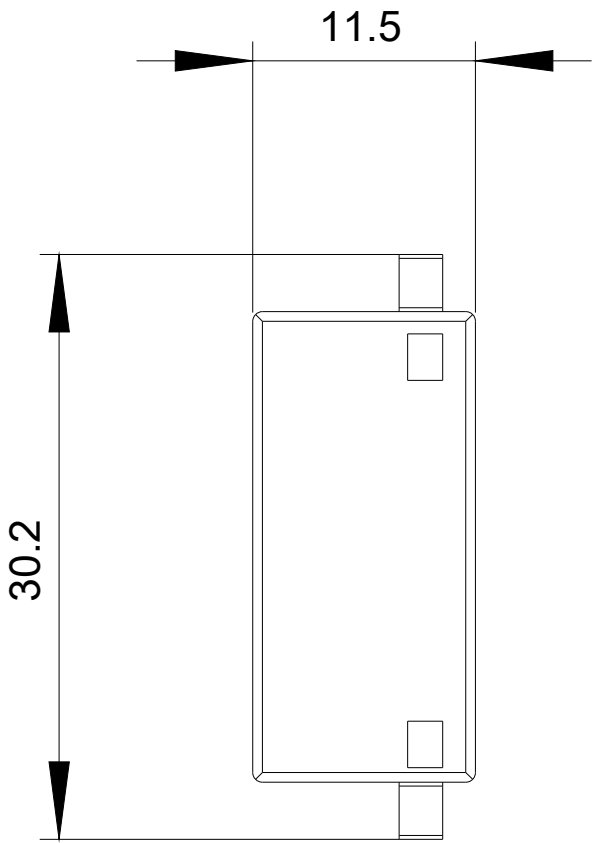

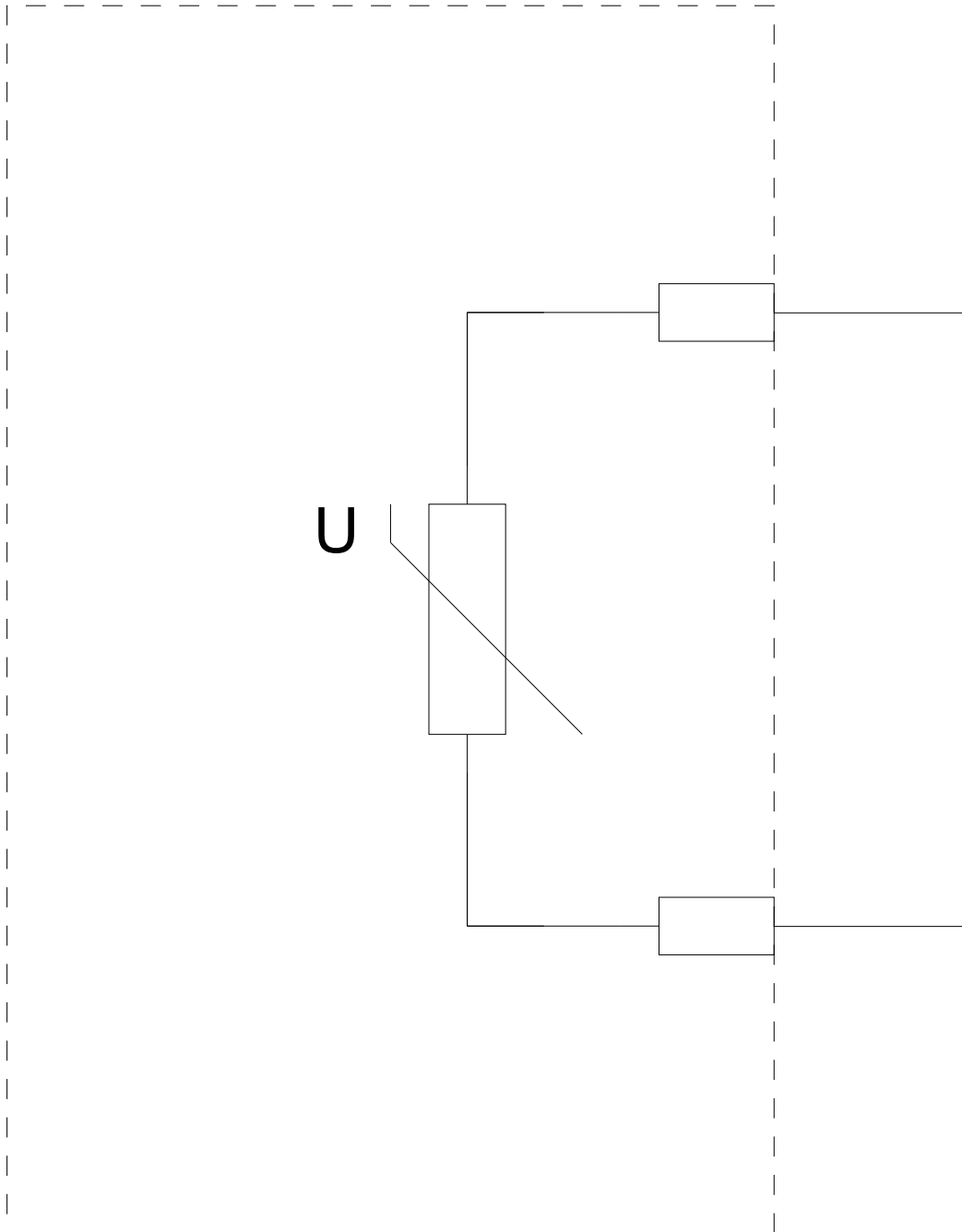

last modified:

01/08/2020