
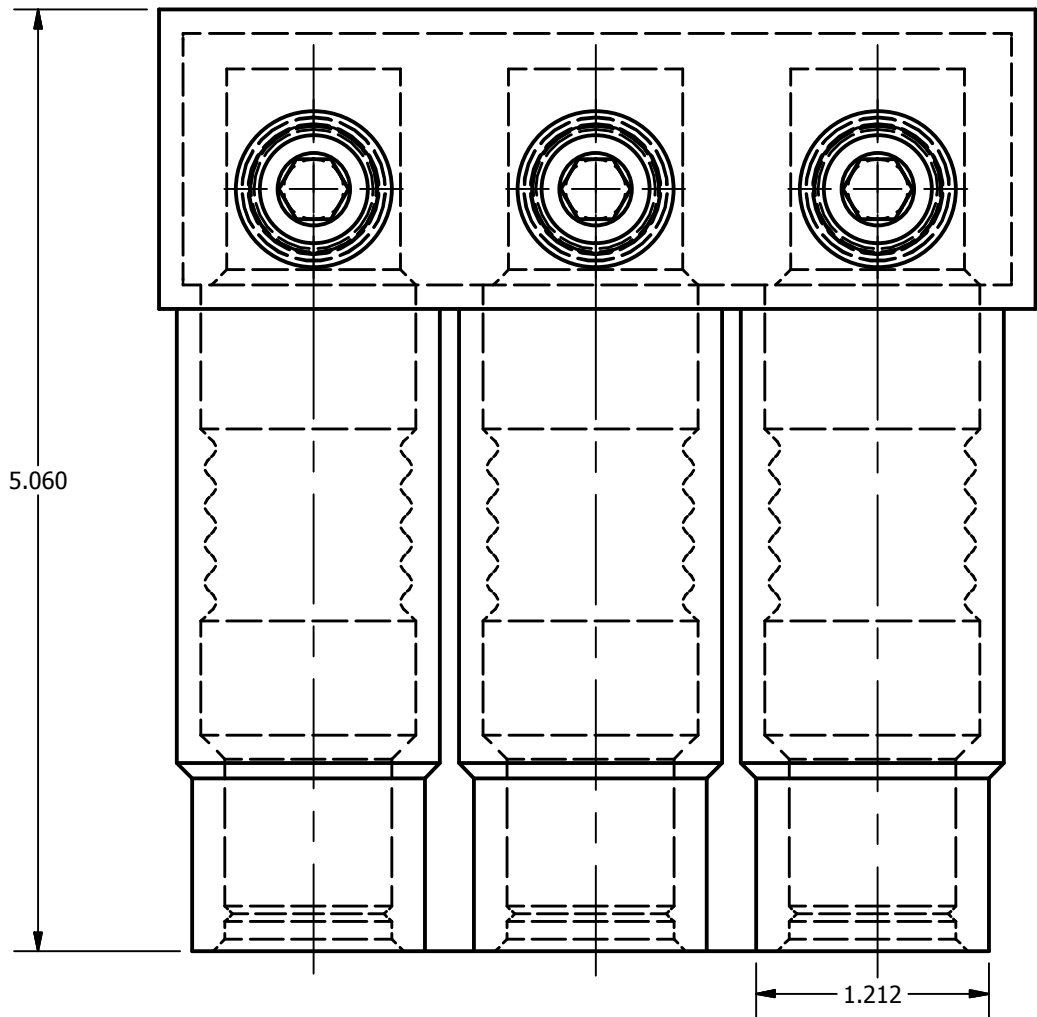


|                             |                |                          |  |
|-----------------------------|----------------|--------------------------|--|
| SCREW: SEE CHART            | MATERIAL: NONE | REV: R                   | <br>800-776-9775 www.ilSCO.com |
| CAT. NO.: SEE CHART PAGE 2  | PLATING: NONE  | DRAWN BY: CLH SCALE: 1:1 |  |
| INFORMATION SHEET: FORM 137 | MARKING: NONE  | DATE: 10/13/2008 SIZE: B |  |
|                             |                |                          | DWG NO: <b>M7481</b>   |
|                             |                |                          | SHEET: 1 OF 1  |



| CATALOG NUMBER | L      | OUTLETS | SCREW     |
|----------------|--------|---------|-----------|
| PED3-500 SS    | 4.314  | 3       | E1412C00T |
| PED4-500 SS    | 5.782  | 4       | E1412C00T |
| PED5-500 SS    | 7.250  | 5       | E1412C00T |
| PED6-500 SS    | 8.719  | 6       | E1412C00T |
| PED8-500 SS    | 11.657 | 8       | E1412C00T |
| PED4-500 SSD   | 5.782  | 4       | E6090C00T |
| PED5-500 SSD   | 7.250  | 5       | E6090C00T |
| PED6-500 SSD   | 8.719  | 6       | E6090C00T |
| PED8-500 SSD   | 11.657 | 8       | E6090C00T |
| PED6-500SSA    | 8.719  | 6       | E1412C00V |
| PED8-500 SSDA  | 11.657 | 8       | E6090C00V |
| PED4-500 SSA   | 5.782  | 4       | E1412C00V |
| PED6-500SSA    | 8.719  | 6       | E1412C00V |
| PED6-500SSAP   | 8.719  | 6       | E1412C00V |
| PED8-500 SSA   | 11.657 | 8       | E1412C00V |
| PED6-500 SSDA  | 8.719  | 6       | E6090C00V |
| PED6-500SS-ORP | 8.719  | 6       | E1412C00T |

