

# OMSSL-LED-101

Motion Activated LED Security Light

Catalog Number:

Project Name:

Note:

Type:

## 20W Dual-Head Sensor Floodlight




### APPLICATIONS:

The Oracle LED motion Security lighting is now just a motion away. Providing increased safety, security, and peace of mind, it can be easily installed quickly and safely. It saves additional energy by utilizing the dusk-to-dawn feature, supplying full light protection when motion is detected.


### FEATURES:

- Dual adjustable light heads, flexible and cover a wide area
- Precision die-cast aluminum housing
- 360° rotation lens hood
- Low power consumption, equivalent to 120W halogen light
- Motion activated and manual on-off override
- Adjustable detection range and time settings
- Easy and fast installation

### DIMENSION:

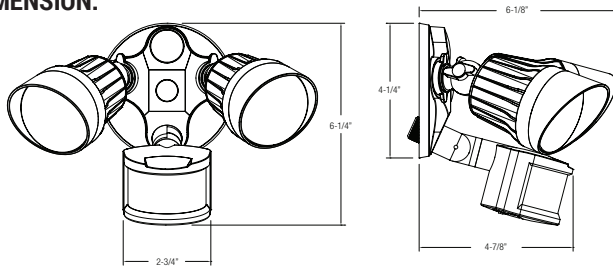

### PHOTOMETRICS:

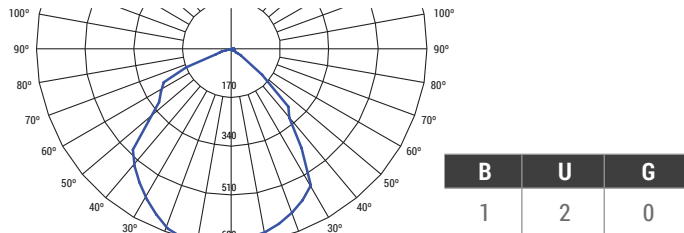

### SPECIFICATIONS: LUMENS

1800 lumens

### WATTAGE

20W

### CCT

30K, 40K, 50K

### CRI

80

### COLOR CONSISTENCY LIGHT

7-step MacAdam Ellipse binning

### EFFICIENCY

90 lumens/watt

### BEAM ANGLE

100°

### VOLTAGE

120V

### POWER FREQUENCY

50/60 Hz

### DETECTION DISTANCE TIME

Max. 70 ft (adjustable)

### SETTING APPLICABLE

From 10 sec to 5 min

### ENVIRONMENT WORKING

Dry/Damp/Wet location

### TEMPERATURE

14°F - 104°F



### Ordering Guide > Example: OMSSL-LED-101-1800L-120-30K-WH

OMSSL-LED-101				
SERIES	PERFORMANCE	VOLTAGE	CCT	FINISH
OMSSL-LED-101	1800L - 900 lumens/head	120 - 120V	30K - 3000K 40K - 4000K 50K - 5000K	WH - White BZ - Bronze

\*\* DesignLights Consortium® (DLC) qualified product. Not all versions of this product may be DLC qualified. Please check the DLC Qualified Products List at [www.designlights.org](http://www.designlights.org) to confirm which versions are qualified.



Submittal form is available @ [www.oraclelighting.com](http://www.oraclelighting.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

Issued-B1118-Rev. 1