




TOOL-FREE 1.5MM WIRE ROPE HANGER KIT, Y-TOGGLE END-FITTING - 9.9' LONG - 44LB

CATALOG NUMBER

SLK15Y300L3



CERTIFICATIONS

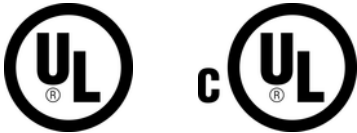

FEATURES

Complete system includes wire, locking device and two pre-assembled toggle end fittings

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

PRODUCT ATTRIBUTES

Material: Steel;Zinc Alloy;Polypropylene

Finish: Electrogalvanized

Static Load Safety Factor: 5:1

Complies With: SMACNA HVAC-DCS

Wire Rope Diameter: 1.5 mm

Wire Rope Length: 9.9'

Wire Rope "Y" Length: 11.8"

B: 0.200"

A: 1.540"

Static Load: 44 lb


Height: 2.150"

Width: 3/4"

Thickness: 1/2"

Angle: 90° Max

DIAGRAMS

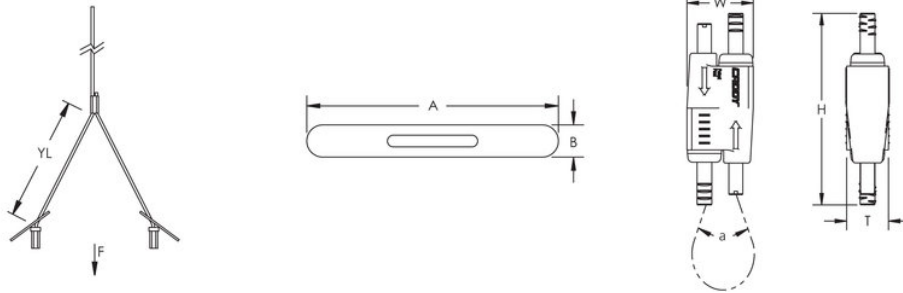

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.