



# A-Shape LED

## 8.8A19/PER/927/P/E26/DIM 6/1FB T20

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

### Product data

General information	
Cap-Base	E26 [ Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000X
Technical Type	8.8-60W

Light technical	
Color Code	927
Beam Angle (Nom)	250 °
Luminous Flux (Nom)	800 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and electrical	
Input Frequency	60 Hz
Power (Nom)	8.8 W
Lamp Current (Nom)	80 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s

Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V

Temperature	
T-Case Maximum (Nom)	90 °C

Controls and dimming	
Dimmable	Yes

Mechanical and housing	
Bulb Finish	Frosted
Bulb Shape	A19 (A19)


Approval and application	
Energy Consumption kWh/1000 h	- kWh

Product data	
Order product name	8.8A19/PER/927/P/E26/DIM 6/1FB T20
EAN/UPC - Product	046677550431
Order code	929002036104
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929002036104

# A-Shape LED

Net Weight (Piece) 0.060 kg


## Dimensional drawing

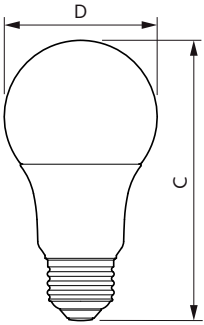


8.8A19/PER/927/P/E26/DIM 6/1FB T20

Product	D	C
8.8A19/PER/927/P/E26/DIM 6/1FB T20	62.5 mm	111.5 mm


## Photometric data

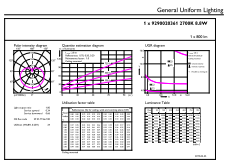

60W E26 A19 927 Frosted

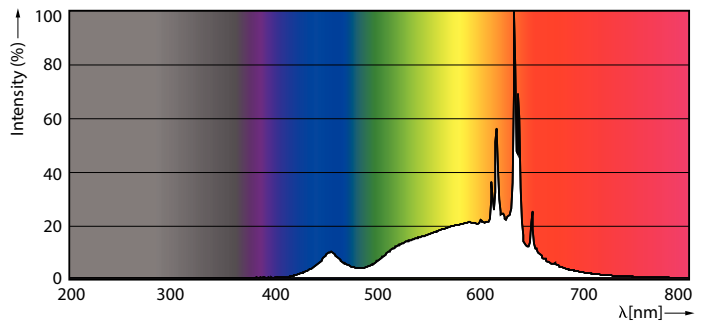

60W E26 A19 927 Frosted

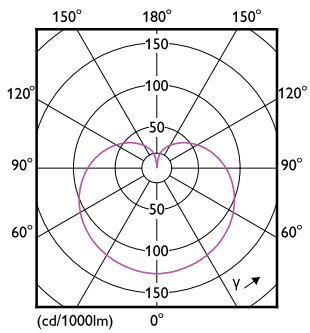

40 60 75 100W E26 A19 A21 Frosted

# A-Shape LED

## Lifetime



15K LED

15K LMP

