



# LED Corn Cobs

## 18CC/LED/830/ND E26 G2 BB 6/1

Philips Corn Cob LED replacement lamps are perfect LED replacement for a variety of outdoor applications. High intensity illumination, which means you get added visibility for applications like streets, public areas, and much more for a fraction of the energy used by conventional HID.

### Product data


General information	
Cap-Base	E26 [ Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
Technical Type	18-70W
Light technical	
Color Code	830 [ CCT of 3000K]
Luminous Flux (Nom)	2300 lm
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	127.00 lm/W
Color Consistency	ANSI 3000K quadrangle
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	18 W
Lamp Current (Nom)	200 mA
Wattage Equivalent	70 W
Starting Time (Nom)	1 s

Warm Up Time to 60% Light (Nom)	1 s
UL Type	Type B - bypass the ballast
Power Factor (Nom)	0.9
Voltage (Nom)	100-277 V
Temperature	
T-Case Maximum (Nom)	60 °C
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Clear
Bulb Shape	Corn cob
Approval and application	
Energy Consumption kWh/1000 h	18 kWh
Product data	
Order product name	18CC/LED/830/ND E26 G2 BB 6/1
EAN/UPC - Product	046677559632
Order code	929002395204
Numerator - Quantity Per Pack	1

LED Corn Cobs

Numerator - Packs per outer box	6
Material Nr. (12NC)	929002395204
Net Weight (Piece)	0.252 kg


Dimensional drawing

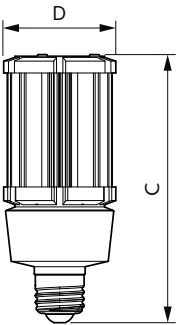


18CC/LED/830/ND E26 G2 BB 6/1

Product	D	C
18CC/LED/830/ND E26 G2 BB 6/1	60 mm	145 mm

Photometric data

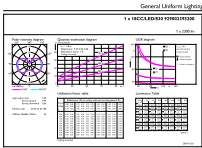


General Uniform Lighted

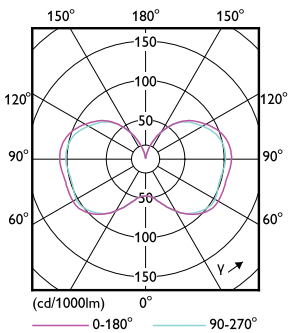

LEDTForce 18W Corncob E26

LEDTForce 18W Corncob E26 830

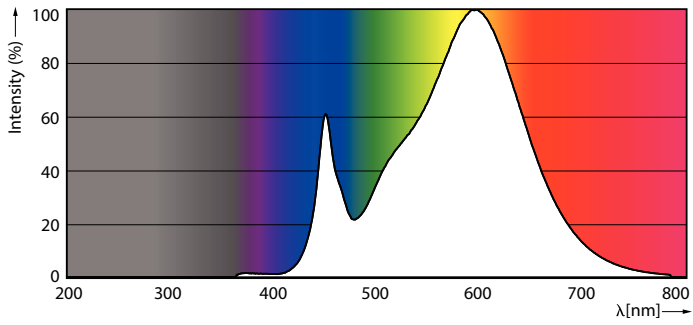


LEDTForce 18W Corncob E26 830

LED Corn Cobs

Lifetime



50K

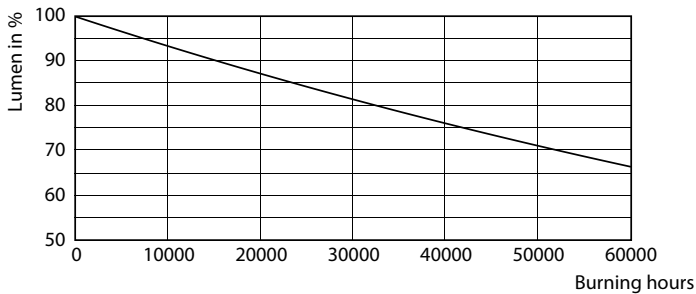

50K

