

# LED Corn Cobs

## 27CC/LED/850/ND E26 G2 BB 6/1

Philips Corn Cob LED replacement lamps are perfect LED replacement for a variety of outdoor applications. High intensity illumination, which means you get added visibility for applications like streets, public areas, and much more for a fraction of the energy used by conventional HID.

### Product data


General information	
Cap-Base	E26 [ Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
Technical Type	27-100W
Light technical	
Color Code	850 [ CCT of 5000K]
Luminous Flux (Nom)	3800 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	140.00 lm/W
Color Consistency	ANSI 5000K quadrangle
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	27 W
Lamp Current (Nom)	300 mA
Wattage Equivalent	100 W
Starting Time (Nom)	1 s

Warm Up Time to 60% Light (Nom)	1 s
UL Type	Type B - bypass the ballast
Power Factor (Nom)	0.9
Voltage (Nom)	100-277 V
Temperature	
T-Case Maximum (Nom)	60 °C
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Clear
Bulb Shape	Corn cob
Approval and application	
Energy Consumption kWh/1000 h	27 kWh
Product data	
Order product name	27CC/LED/850/ND E26 G2 BB 6/1
EAN/UPC - Product	046677559687
Order code	929002395704
Numerator - Quantity Per Pack	1

# LED Corn Cobs

Numerator - Packs per outer box	6
Material Nr. (12NC)	929002395704
Net Weight (Piece)	0.302 kg



## Dimensional drawing

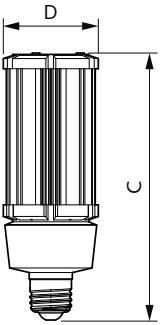

27CC/LED/850/ND E26 G2 BB 6/1


Product	D	C
27CC/LED/850/ND E26 G2 BB 6/1	60 mm	170 mm

## Photometric data

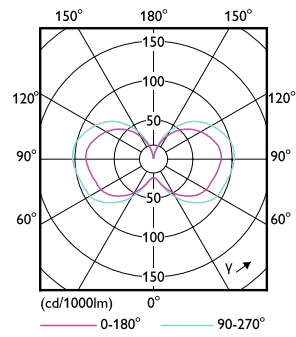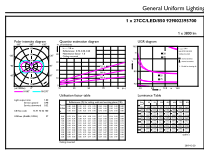

LEDTForce 27W Corncob E26 850



LEDTForce 27W Corncob E26

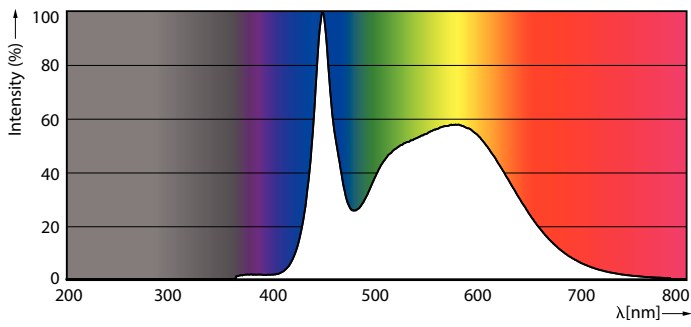

LEDTForce 27W Corncob E26 850

# LED Corn Cobs

## Lifetime

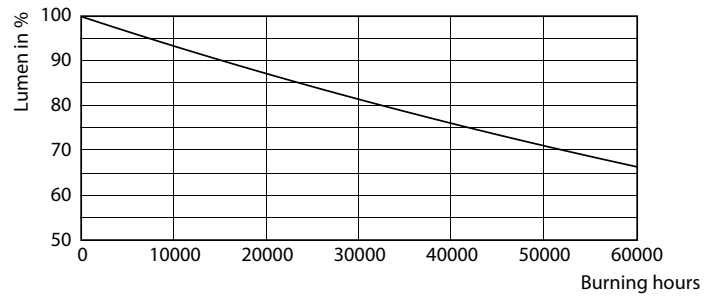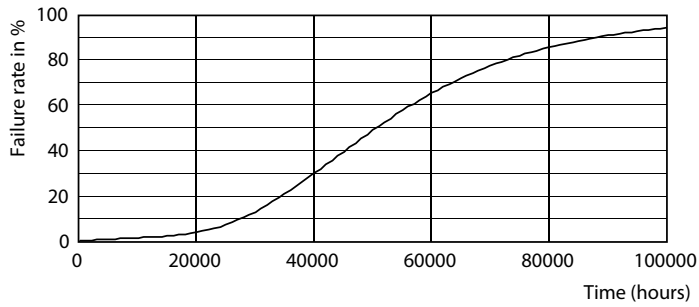

50K

50K

