



# LED Corn Cobs

## 36CC/LED/830/ND EX39 G2 BB 6/1

Philips Corn Cob LED replacement lamps are perfect LED replacement for a variety of outdoor applications. High intensity illumination, which means you get added visibility for applications like streets, public areas, and much more for a fraction of the energy used by conventional HID.

### Product data

General information	
Cap-Base	EX39 [ Exclusionary Mogul Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
Technical Type	36-150W
Light technical	
Color Code	830 [ CCT of 3000K]
Luminous Flux (Nom)	5000 lm
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	138.00 lm/W
Color Consistency	ANSI 3000K quadrangle
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	36 W
Lamp Current (Nom)	400 mA
Wattage Equivalent	100-150 W
Starting Time (Nom)	1 s


Warm Up Time to 60% Light (Nom)	1 s
UL Type	Type B - bypass the ballast
Power Factor (Nom)	0.9
Voltage (Nom)	100-277 V
Temperature	
T-Case Maximum (Nom)	60 °C
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Plastic
Bulb Shape	Corncob
Approval and application	
Energy Consumption kWh/1000 h	36 kWh
Product data	
Order product name	36CC/LED/830/ND EX39 G2 BB 6/1
EAN/UPC - Product	046677559724
Order code	929002396104

# LED Corn Cobs

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929002396104

Net Weight (Piece)	0.644 kg
--------------------	----------


## Dimensional drawing

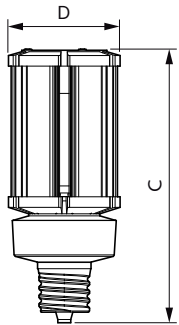


36CC/LED/830/ND EX39 G2 BB 6/1

Product	D	C
36CC/LED/830/ND EX39 G2 BB 6/1	85 mm	213 mm


## Photometric data

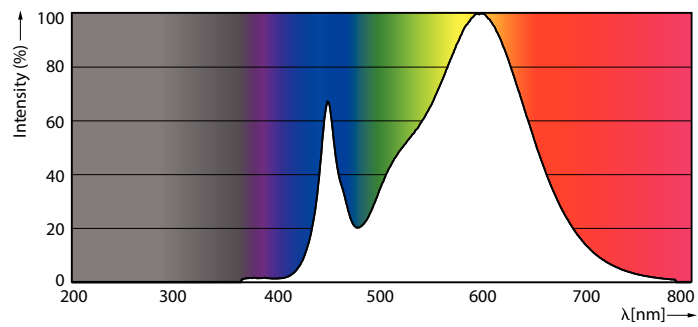

LEDTForce 36W Corncob 830

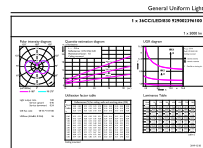



LEDTForce 36W Corncob EX39 830

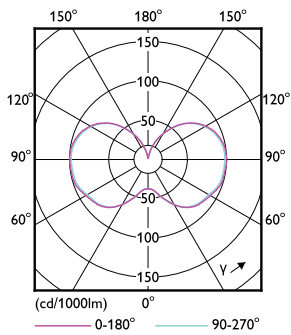

LEDTForce 36W Corncob E26

# LED Corn Cobs

## Lifetime

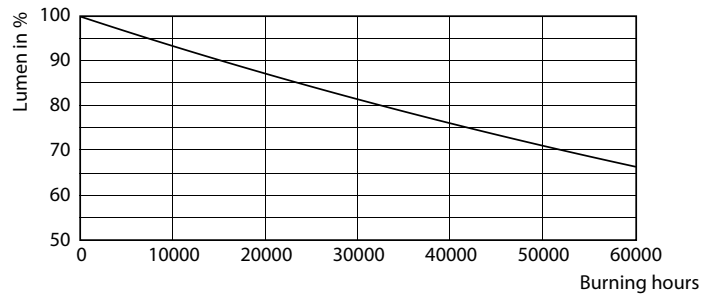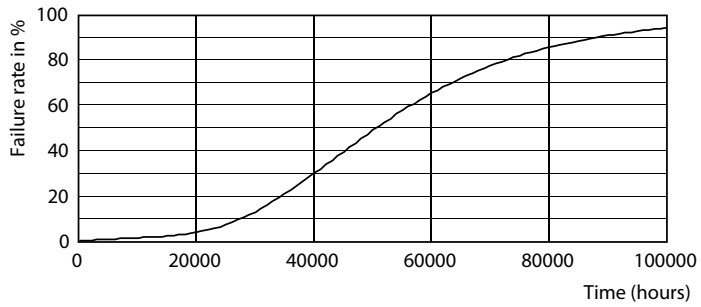

50K

50K

